




## 7.3. Changing the Minimum Display


The minimum display can be changed.

The minimum display currently selected is indicated by “R” followed by the number in the LCD.

1. In the weighing mode, press and hold the **Range** key. The unit and the minimum display indicator blink.

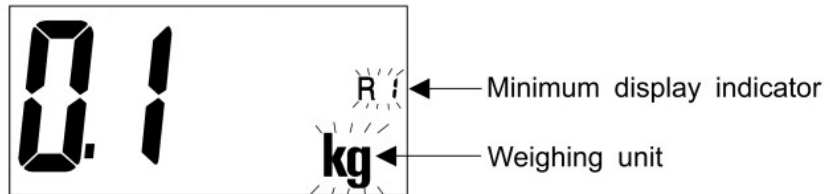

2. Release the **Range** key. Press the **Range** key again to select a minimum display.  
Each time the **Range** key is pressed, the minimum display changes as shown below:

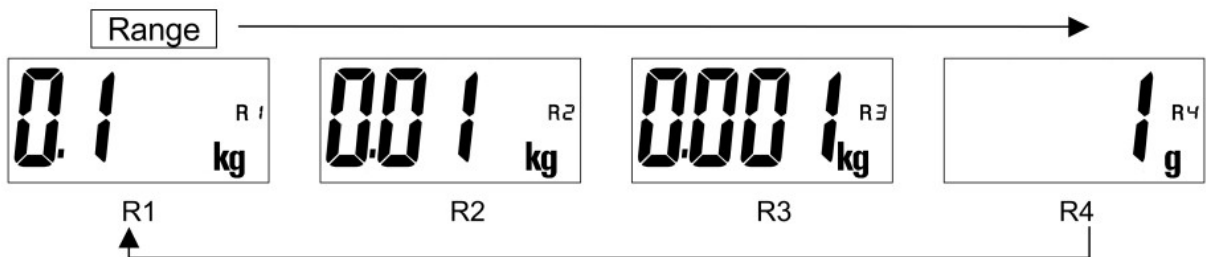

3. Press the **Re-Zero/AT** key to confirm.  
When no key operation is performed for a certain period, the minimum display currently displayed is confirmed automatically.

R1 ~ R4: Minimum display indicator

Model		SA-30K	SA-60K	SA-150K
Minimum display (d)	R1	0.1 kg	0.1 kg	0.1 kg
	R2	0.01 kg	0.01 kg	0.01 kg
	R3	0.001 kg (0 ~ 3 kg) 0.01 kg (3 ~ 30 kg)	0.001 kg (0 ~ 3 kg) 0.01 kg (3 ~ 60 kg)	0.001 kg (0 ~ 3 kg) 0.01 kg (3 ~ 150 kg)
	R4	1 g (0 ~ 3000 g) 0.01 kg (3 ~ 30 kg)	1 g (0 ~ 3000 g) 0.01 kg (3 ~ 60 kg)	1 g (0 ~ 3000 g) 0.01 kg (3 ~ 150 kg)