

TRANSFORMERS

SW type

複巻
一次、二次間シールド付(E)


SLA type

複巻
一次、二次間シールド付(E)


SLB type

複巻
一次、二次間シールド付(E)

BL型/ラグ端子式

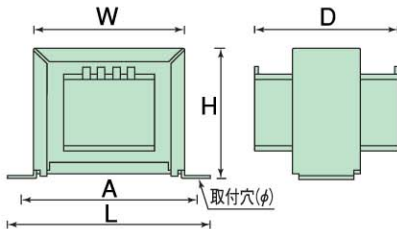

SL型/ラグ端子式

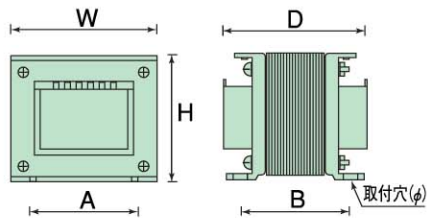

形式	仕様		絶縁種別	形状	端子ネジ	寸法 mm						重量 (kg)	取付穴 (φ)
	一次電圧	二次電圧				電流/容量	W	H	D	A	B		
12V type													
SW-1201	100V 0 E	12V 12V 6V 6V 0 0	0.1A×2	A	BL	50	43	42	61		73	0.27	4×7
SW-1202			0.2A×2	A	BL	50	43	44	60		71	0.3	4×6
SW-1203			0.3A×2	A	BL	60	52	48	72		84	0.46	4×7.5
SW-1205			0.5A×2	A	BL	60	52	52	72		84	0.58	4.5×8
SW-1210			1A×2	A	BL	70	60	62	81		92	0.91	4.5×6
SW-1220			2A×2	A	BL	80	70	65	93		105	1.2	4.5×6.5
15V type													
SW-15005	100V 0 E	15V 15V 12V 12V 0 0	0.05A×2	A	BL	43	36	35	51		61	0.15	4×6
SW-1501			0.1A×2	A	BL	50	43	42	61		73	0.27	4×7
SW-1502			0.2A×2	A	BL	50	43	44	60		71	0.3	4×6
SW-1503			0.3A×2	A	BL	60	52	48	72		84	0.46	4×7.5
SW-1505			0.5A×2	A	BL	70	60	54	80		91	0.68	4.5×6
SW-1510			1A×2	A	BL	70	60	67	80		91	1.05	4.5×6
18V type													
SW-18005	100V 0 E	18V 18V 0 0	0.05A×2	A	BL	43	36	35	51		61	0.15	4×6
SW-1801			0.1A×2	A	BL	50	43	44	60		73	0.3	4×6
SW-1802			0.2A×2	A	BL	60	52	48	72		84	0.46	4×7.5
SW-1803			0.3A×2	A	BL	60	52	52	72		84	0.58	4.5×8
SW-1805			0.5A×2	A	BL	70	60	54	80		91	0.68	4.5×6
SW-1810			1A×2	A	BL	70	60	67	80		91	1.02	4.5×6
100V.120V type													
SLA-03	100V 0 E	100V 0	3VA	A	BL	43	36	35	51		61	0.15	4×6
SLA-05			5VA	A	BL	50	43	42	61		73	0.27	4×6
SLA-10			10VA	A	BL	60	52	48	72		84	0.46	4×7.5
SLA-20		120V 110V 100V 0	20VA	A	BL	70	60	58	80		91	0.8	4×6.5
SLA-30			30VA	A	BL	70	60	67	80		91	1.05	4.5×6
SLA-40			40VA	A	BL	80	70	65	93		105	1.2	4.5×6.5
SLA-50	E-0-100V -110V-120V	100V 0	55VA	A	SL	76	67	85	55	70		1.6	4.5×10
SLA-100			100VA	A	SL	105	86	92	66	65		2.9	5.5×10
240V type													
SLB-50	E-0-200V -220V-240V	0-200V -220V-240V	55VA	A	SL	76	67	85	55	70		1.6	4.5×10
SLB-100			100VA	A	SL	105	86	92	66	65		2.9	5.5×10