


TRANSFORMERS


SPA type

複巻
一次、二次間シールド付(E)

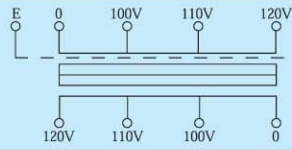


SPB type

複巻
一次、二次間シールド付(E)

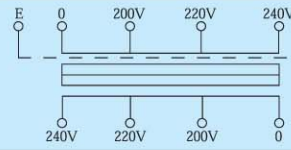


NYSA type

複巻
一次、二次間シールド付(E)

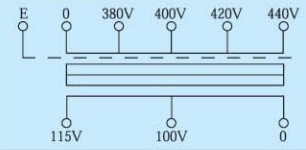

P型/端子台式

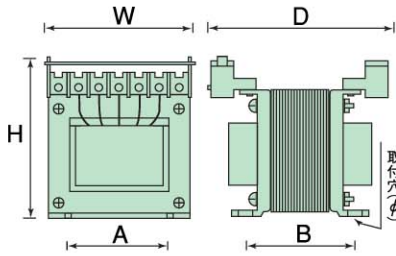

形式	仕様			絶縁種別	形状	端子ネジ	寸法 mm						重量 (kg)	取付穴 (φ)
	一次電圧	二次電圧	容量				W	H	D	A	B	L		

120V type

SPA-50	120V 110V 100V 0 E	120V 110V 100V 0	55VA	A	P	M4	85	88	99	55	70		1.7	4.5×10
SPA-100			100VA	A	P	M4	105	107	104	66	65		3.0	5.5×10
SPA-150			150VA	A	P	M4	105	113	109	75	70		3.8	5.5×10
SPA-200			200VA	A	P	M4	105	113	119	75	80		4.5	5.5×10
SPA-300			300VA	A	P	M4	120	120	120	80	81		5.4	7×11
SPA-500			500VA	A	P	M5	153	156	145	111	92		8.5	6.5×10
SPA-750			750VA	A	P	M5	153	156	155	111	102		10.6	6.5×10
SPA-1K			1kVA	A	P	M5	153	156	175	111	122		12.9	6.5×10
SPA-1.5K			1.5kVA	A	P	M5	144	215	195	90	150		21.0	7×20
SPA-2K			2kVA	A	P	M5	144	215	215	90	170		24.6	7×20
SPA-3K			3kVA	A	P	M5	150	220	235	90	180		30.0	7×20
☆ SPA-4K	4kVA	A	P	M8	250	255	200	180	150		38.0	8×27		
☆ SPA-5K	5kVA	A	P	M8	250	255	210	180	165		45.0	8×27		

240V type

SPB-50	240V 220V 200V 0 E	240V 220V 200V 0	55VA	A	P	M4	85	88	99	55	70		1.7	4.5×10
SPB-100			100VA	A	P	M4	105	107	104	66	65		3.0	5.5×10
SPB-150			150VA	A	P	M4	105	113	109	75	70		3.8	5.5×10
SPB-200			200VA	A	P	M4	105	113	119	75	80		4.5	5.5×10
SPB-300			300VA	A	P	M4	120	120	120	80	81		5.4	7×11
SPB-500			500VA	A	P	M5	153	156	145	111	92		8.5	6.5×10
SPB-750			750VA	A	P	M5	153	156	155	111	102		10.6	6.5×10
SPB-1K			1kVA	A	P	M5	153	156	175	111	122		12.9	6.5×10
SPB-1.5K			1.5kVA	A	P	M5	144	215	195	90	150		21.0	7×20
SPB-2K			2kVA	A	P	M5	144	215	215	90	170		24.6	7×20
SPB-3K			3kVA	A	P	M5	150	220	235	90	180		30.0	7×20
☆ SPB-4K	4kVA	A	P	M8	250	255	200	180	150		38.0	8×27		
☆ SPB-5K	5kVA	A	P	M8	250	255	220	180	170		46.7	8×27		

115V type

NYSA-50	440V 420V 400V 380V 0 E	115V 100V 0	50VA	A	P	M4	88	88	99	55	70		1.7	4.5×10
NYSA-100			100VA	A	P	M4	105	107	104	66	65		3.0	5.5×10
NYSA-150			150VA	A	P	M4	105	113	109	75	70		3.8	5.5×10
NYSA-200			200VA	A	P	M4	105	113	119	75	80		4.5	5.5×10
NYSA-300			300VA	A	P	M4	120	120	120	80	81		5.4	7×11
NYSA-500			500VA	A	P	M5	153	156	145	111	92		8.5	6.5×10
NYSA-750			750VA	A	P	M5	153	156	155	111	102		10.6	6.5×10
NYSA-1K			1kVA	A	P	M5	153	156	175	111	122		12.9	6.5×10
NYSA-1.5K			1.5kVA	A	P	M5	144	215	195	90	150		21.0	7×20
NYSA-2K			2kVA	A	P	M5	144	215	215	90	170		24.6	7×20
NYSA-3K			3kVA	A	P	M5	150	220	235	90	180		30.0	7×20

☆印は受注生産品です。