



TRANSFORMERS

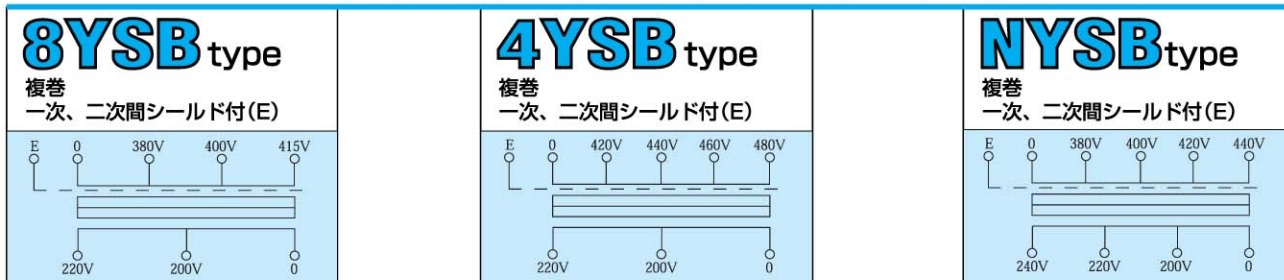

P型/端子台式

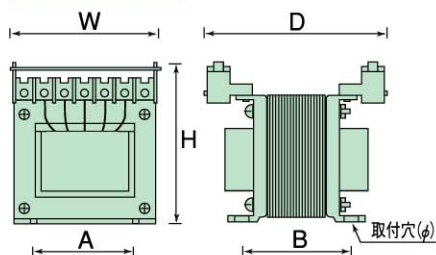

形式	仕様			絶縁種別	形状	端子ネジ	寸法 mm						重量 (kg)	取付穴 (φ)
	一次電圧	二次電圧	容量				W	H	D	A	B	L		

8YSB type

8YSB-50	415V 400V 380V 0 E	220V 200V 0	50VA	A	P	M4	88	88	99	55	70		1.7	4.5×10
8YSB-100			100VA	A	P	M4	105	107	104	66	65		3.0	5.5×10
8YSB-150			150VA	A	P	M4	105	113	109	75	70		3.8	5.5×10
8YSB-200			200VA	A	P	M4	105	113	119	75	80		4.5	5.5×10
8YSB-300			300VA	A	P	M4	120	120	120	80	81		5.4	7×11
8YSB-500			500VA	A	P	M5	153	156	145	111	92		8.5	6.5×10
8YSB-750			750VA	A	P	M5	153	156	155	111	102		10.6	6.5×10
8YSB-1K			1kVA	A	P	M5	153	156	175	111	122		12.9	6.5×10
8YSB-1.5K			1.5kVA	A	P	M5	144	215	195	90	150		21.0	7×20
8YSB-2K			2kVA	A	P	M5	144	215	215	90	170		24.6	7×20
8YSB-3K			3kVA	A	P	M5	150	220	230	90	175		28.5	7×20

4YSB type

4YSB-50	480V 460V 440V 420V 0 E	220V 200V 0	50VA	A	P	M4	88	88	99	55	70		1.7	4.5×10
4YSB-100			100VA	A	P	M4	105	107	104	66	65		3.0	5.5×10
4YSB-150			150VA	A	P	M4	105	113	109	75	70		3.8	5.5×10
4YSB-200			200VA	A	P	M4	105	113	119	75	80		4.5	5.5×10
4YSB-300			300VA	A	P	M5	135	141	142	97	82		6.5	6.5×11
4YSB-500			500VA	A	P	M5	153	156	145	111	92		8.5	6.5×10
4YSB-750			750VA	A	P	M5	153	156	165	111	112		11.6	6.5×10
4YSB-1K			1kVA	A	P	M5	153	156	185	111	132		14.5	6.5×10
4YSB-1.5K			1.5kVA	A	P	M5	144	215	215	90	170		24.6	7×20
4YSB-2K			2kVA	A	P	M5	144	215	225	90	180		26.5	7×20
4YSB-3K			3kVA	A	P	M5	150	220	235	90	180		30.0	7×20

NYSB type

NYSB-50	440V 420V 400V 380V 0 E	240V 220V 200V 0	50VA	A	P	M4	88	88	99	55	70		1.7	4.5×10
NYSB-100			100VA	A	P	M4	105	107	104	66	65		3.0	5.5×10
NYSB-150			150VA	A	P	M4	105	113	109	75	70		3.8	5.5×10
☆ NYSB-200			200VA	A	P	M4	105	113	119	75	80		4.5	5.5×10
☆ NYSB-300			300VA	A	P	M4	120	120	120	80	81		5.4	7×11
NYSB-500			500VA	A	P	M5	153	156	145	111	92		8.5	6.5×10
NYSB-750			750VA	A	P	M5	153	156	155	111	102		10.6	6.5×10
NYSB-1K			1kVA	A	P	M5	153	156	175	111	122		12.9	6.5×10
☆ NYSB-1.5K			1.5kVA	A	P	M5	144	215	195	90	150		21.0	7×20
☆ NYSB-2K			2kVA	A	P	M5	144	215	215	90	170		24.6	7×20
☆ NYSB-3K			3kVA	A	P	M5	150	220	235	90	180		30.0	7×20

☆印は受注生産品です。