



# TRANSFORMERS

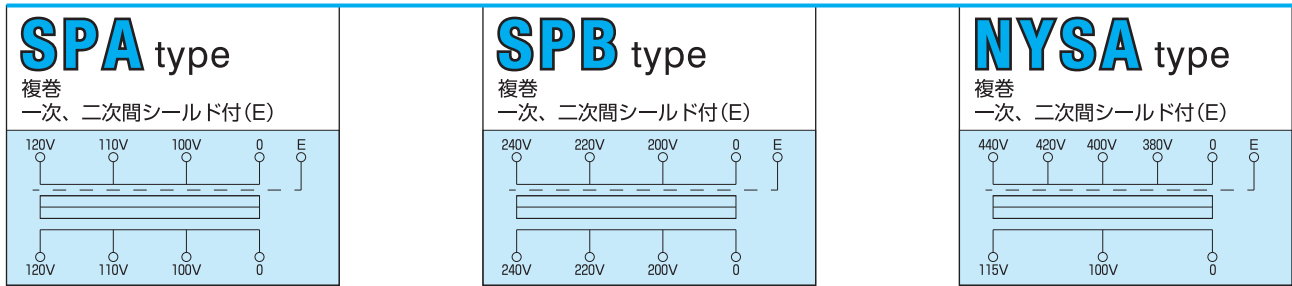

## P型/端子台式

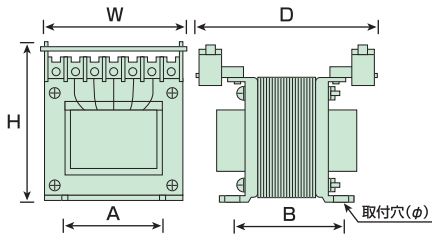

形式	仕様			絶縁種別	形状	端子ネジ	寸法 mm						重量 (kg)	取付穴 (φ)
	一次電圧	二次電圧	容量				W	H	D	A	B	L		

### 120V type

SPA-50	120V   110V   100V   0   E	120V   110V   100V   0	55VA	A	P	M4	85	88	99	55	70		1.7	4.5 × 10
SPA-100			100VA	A	P	M4	105	107	104	66	65		3.0	5.5 × 10
SPA-150			150VA	A	P	M4	105	113	109	75	70		3.8	5.5 × 10
SPA-200			200VA	A	P	M4	105	113	119	75	80		4.5	5.5 × 10
SPA-300			300VA	A	P	M4	120	120	120	80	81		5.4	7 × 11
SPA-500			500VA	A	P	M5	153	156	145	111	92		8.5	6.5 × 10
SPA-750			750VA	A	P	M5	153	156	155	111	102		10.6	6.5 × 10
SPA-1K			1kVA	A	P	M5	153	156	175	111	122		12.9	6.5 × 10
SPA-1.5K			1.5kVA	A	P	M5	144	215	195	90	150		21.0	7 × 20
SPA-2K			2kVA	A	P	M5	144	215	215	90	170		24.6	7 × 20
SPA-3K			3kVA	A	P	M5	150	220	235	90	180		30.0	7 × 20
☆ SPA-4K			4kVA	A	P	M8	250	255	200	180	150		38.0	8 × 27
☆ SPA-5K			5kVA	A	P	M8	250	255	210	180	165		45.0	8 × 27

### 240V type

SPB-50	240V   220V   200V   0   E	240V   220V   200V   0	55VA	A	P	M4	85	88	99	55	70		1.7	4.5 × 10
SPB-100			100VA	A	P	M4	105	107	104	66	65		3.0	5.5 × 10
SPB-150			150VA	A	P	M4	105	113	109	75	70		3.8	5.5 × 10
SPB-200			200VA	A	P	M4	105	113	119	75	80		4.5	5.5 × 10
SPB-300			300VA	A	P	M4	120	120	120	80	81		5.4	7 × 11
SPB-500			500VA	A	P	M5	153	156	145	111	92		8.5	6.5 × 10
SPB-750			750VA	A	P	M5	153	156	155	111	102		10.6	6.5 × 10
SPB-1K			1kVA	A	P	M5	153	156	175	111	122		12.9	6.5 × 10
SPB-1.5K			1.5kVA	A	P	M5	144	215	195	90	150		21.0	7 × 20
SPB-2K			2kVA	A	P	M5	144	215	215	90	170		24.6	7 × 20
SPB-3K			3kVA	A	P	M5	150	220	235	90	180		30.0	7 × 20
☆ SPB-4K			4kVA	A	P	M8	250	255	200	180	150		38.0	8 × 27
☆ SPB-5K			5kVA	A	P	M8	250	255	220	180	170		46.7	8 × 27

### 115V type

NYSA-50	440V   420V   400V   380V   0   E	115V   100V   0	50VA	A	P	M4	88	88	99	55	70		1.7	4.5 × 10
NYSA-100			100VA	A	P	M4	105	107	104	66	65		3.0	5.5 × 10
NYSA-150			150VA	A	P	M4	105	113	109	75	70		3.8	5.5 × 10
NYSA-200			200VA	A	P	M4	105	113	119	75	80		4.5	5.5 × 10
NYSA-300			300VA	A	P	M4	120	120	120	80	81		5.4	7 × 11
NYSA-500			500VA	A	P	M5	153	156	145	111	92		8.5	6.5 × 10
NYSA-750			750VA	A	P	M5	153	156	155	111	102		10.6	6.5 × 10
NYSA-1K			1kVA	A	P	M5	153	156	175	111	122		12.9	6.5 × 10
NYSA-1.5K			1.5kVA	A	P	M5	144	215	195	90	150		21.0	7 × 20
NYSA-2K			2kVA	A	P	M5	144	215	215	90	170		24.6	7 × 20
☆ NYSA-3K			3kVA	A	P	M5	150	225	235	90	180		30.0	7 × 20