


U-fixings

A10609 U-band for TN pipe

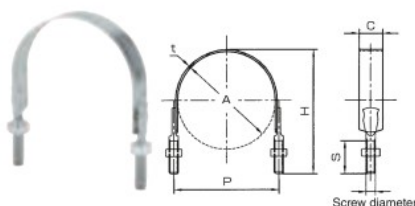

U-band for fireproof double-layer pipe (FDP)

Part number A10609 U-band for TN pipe


Units (mm)

Size code	Size	Applicable pipe outer diameter	Screw diameter	t	C	P	H	S
0017	40	61 · 63 · 65	M10	2.0	25	74	95	35
0021	50	73 · 75 · 77	M10	2.0	25	86	100	35
0036	65	89 · 91 · 93	M10	2.0	25	102	118	35
0055	75	102 · 104 · 106	M10	2.0	25	116	132	35
0060	100	129 · 131 · 133	M10	2.0	25	142	163	35
0074	125	155 · 158 · 161	W $\frac{1}{2}$	3.2	32	180	190	55
0089	150	182 · 185 · 188	W $\frac{1}{2}$	3.2	32	205	220	55
0125	200	236	W $\frac{1}{2}$	3.2	32	255	279	55

*For TNF type, specify A15375 U-band for TNF pipe.

A10629 Stainless steel U-band for TN pipe

Made to order

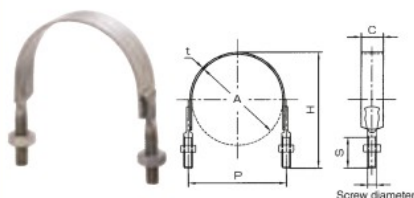


U-band for fireproof double-layer pipe (FDP)

Part number A10629 Stainless steel U-band for TN pipe

Units (mm)

Size code	Size	Applicable pipe outer diameter	Screw diameter	t	C	P	H	S
0010	40	61 · 63 · 65	W $\frac{3}{8}$	2.0	25	79	93	35
0024	50	73 · 75 · 77	W $\frac{3}{8}$	2.0	25	92	107	35
0039	65	89 · 91 · 93	W $\frac{3}{8}$	2.0	25	105	124	35
0043	75	102 · 104 · 106	W $\frac{3}{8}$	2.0	25	115	137	35
0058	100	129 · 131 · 133	W $\frac{3}{8}$	2.0	25	145	164	35
0062	125	155 · 158 · 161	W $\frac{1}{2}$	3.0	32	180	202	55
0077	150	182 · 185 · 188	W $\frac{1}{2}$	3.0	32	206	230	55

A22724 U-band for SP pipe

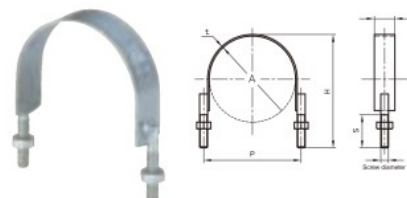


U-band for spiral duct

Part number A22724 U-band for SP pipe

Units (mm)

Size code	Size	Applicable pipe outer diameter	Screw diameter	t	C	P	H	S
0011	SP- 75	80	W $\frac{3}{8}$	1.6	32	93	110	40
0026	SP-100	103	W $\frac{3}{8}$	1.6	32	116	133	40
0045	SP-125	128	W $\frac{3}{8}$	1.6	32	141	158	40
0050	SP-150	153	W $\frac{3}{8}$	1.6	32	166	183	40
0064	SP-175	178	W $\frac{3}{8}$	1.6	32	191	208	40
0079	SP-200	203	W $\frac{3}{8}$	1.6	32	216	234	40
0083	SP-225	228	W $\frac{3}{8}$	1.6	32	241	259	40
0098	SP-250	253	W $\frac{3}{8}$	1.6	32	266	285	40
0115	SP-275	278	W $\frac{3}{8}$	1.6	32	291	313	40
0120	SP-300	303	W $\frac{3}{8}$	1.6	32	316	332	40

A22725 Stainless steel U-band for SP pipe

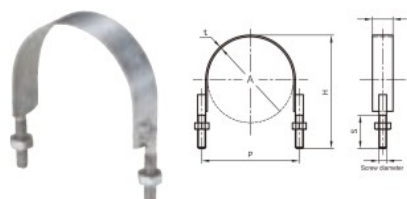

U-band for spiral duct

Part number A22725 Stainless steel U-band for SP pipe

Units (mm)

Size code	Size	Applicable pipe outer diameter	Screw diameter	t	C	P	H	S
0019	SP- 75	80	W $\frac{3}{8}$	1.5	32	93	110	40
0023	SP-100	103	W $\frac{3}{8}$	1.5	32	116	133	40
0038	SP-125	128	W $\frac{3}{8}$	1.5	32	141	158	40
0042	SP-150	153	W $\frac{3}{8}$	1.5	32	166	183	40
0057	SP-175	178	W $\frac{3}{8}$	1.5	32	191	208	40
0061	SP-200	203	W $\frac{3}{8}$	1.5	32	216	234	40
0076	SP-225	228	W $\frac{3}{8}$	1.5	32	241	259	40
0095	SP-250	253	W $\frac{3}{8}$	1.5	32	266	285	40
0108	SP-275	278	W $\frac{3}{8}$	1.5	32	291	313	40
0112	SP-300	303	W $\frac{3}{8}$	1.5	32	316	332	40

