


BY ホースジョイント型


エアークックに

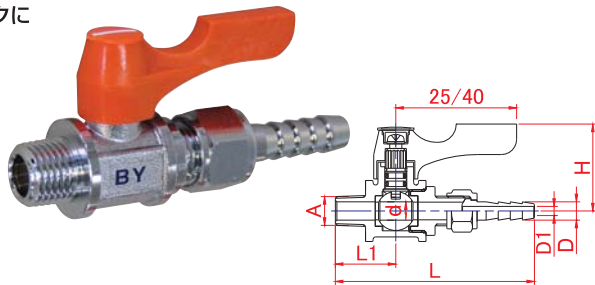

品番	φd	A (R)	φD	φD1	L1	L	H(約)
BY-1106	6	1/8	6	3	20	66	29
BY-1208	6	1/4	8	4.5	20	75	29
BY-1209	6	1/4	9	5	20	75	29
BY-1310	6	3/8	10.5	7	20	76	29
BY-2414	8	1/2	14	10	26.5	95.5	31

BC ワンタッチ接続型


ナイロン、
ウレタンチューブに

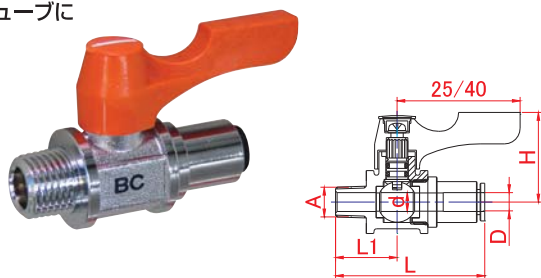

品番	φd	A (R)	φD	L1	L	H(約)
BC-1106	6	1/8	6	20	48.5	29
BC-1108	6	1/8	8	20	49	29
BC-1206	6	1/4	6	20	48.5	29
BC-1208	6	1/4	8	20	49	29
BC-1210	6	1/4	10	20	53	29
BC-1308	6	3/8	8	20	49	29
BC-1310	6	3/8	10	20	53	29
BC-2310	8	3/8	10	26.5	62.5	31

BD ピークック型


ドレン抜きに

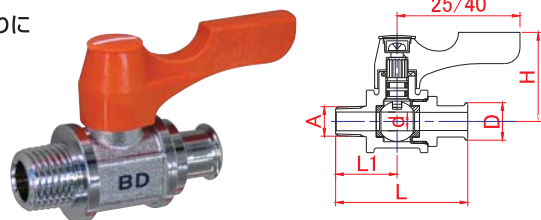

品番	φd	A (R)	φD	L1	L	H(約)
BD-1100	6	1/8	12	20	43	29
BD-1200	6	1/4	12	20	43	29
BD-1300	6	3/8	12	20	43	29
BD-2400	8	1/2	16	26.5	53	31

BL 外ネジ・ドレン型


油缶の取出しなどに

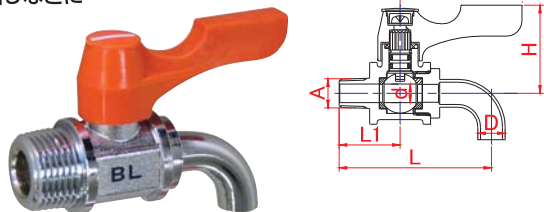

品番	φd	A (R)	φD	L1	L	H(約)
BL-1100	6	1/8	9	20	50	29
BL-1200	6	1/4	9	20	50	29
BL-1300	6	3/8	9	20	50	29
BL-2400	8	1/2	12.7	26.5	67	31

BR 銅管用リング型

油・空圧機器に

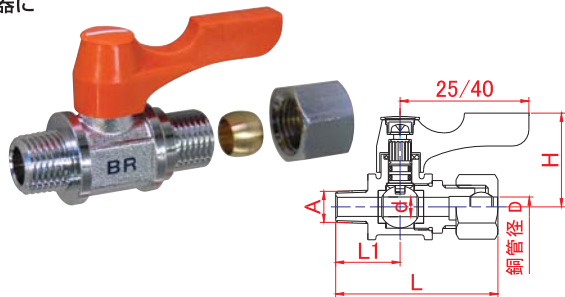

品番	φd	A (R)	φD	L1	L	H(約)
BR-1106	6	1/8	6	20	50	29
BR-1206	6	1/4	6	20	50	29
BR-1202	6	1/4	6.35	20	50	29
BR-1208	6	1/4	8	20	50	29
BR-1308	6	3/8	8	20	51	29
BR-1303	6	3/8	9.53	20	53	29
BR-1310	6	3/8	10	20	53	29
BR-2303	8	3/8	9.53	26.5	64.5	31
BR-2310	8	3/8	10	26.5	64.5	31
BR-2410	8	1/2	10	26.5	64.5	31
BR-2412	8	1/2	12	26.5	67.5	31
BR-2404	8	1/2	12.7	26.5	67.5	31