


BD ピークック型


ドレン抜取りに

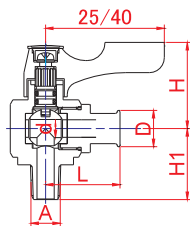

品番	φd	A (R)	φD	L	H1	H (約)
BD-3100	6	1/8	12	24	24	29
BD-3200	6	1/4	12	24	24	29
BD-3300	6	3/8	12	24	24	29

BH ホースニップル一体型



あらゆるホースに

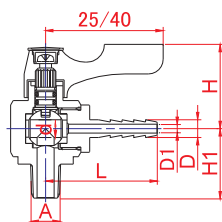

品番	φd	A (R)	φD	φD1	L	H1	H (約)
BH-3106	6	1/8	6	3	38	24	29
BH-3107	6	1/8	7	4	38	24	29
BH-3208	6	1/4	8	5	40	24	29
BH-3209	6	1/4	9	6	40	24	29
BH-3309	6	3/8	9	6	40	24	29
BH-3310	6	3/8	10.5	6	42	24	29

BY ホースジョイント型


エアークックに

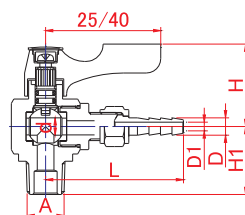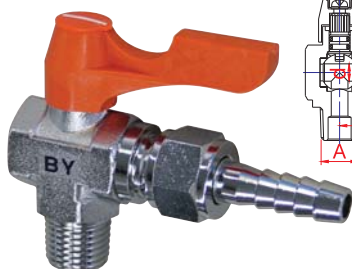

品番	φd	A (R)	φD	φD1	L	H1	H (約)
BY-3208	6	1/4	8	4.5	57	24	29
BY-3209	6	1/4	9	5	57	24	29
BY-3310	6	3/8	10.5	7	58	24	29

BC ワンタッチ接続型


ナイロン、ウレタンチューブに

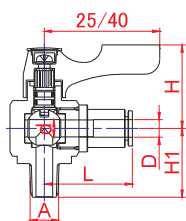

品番	φd	A (R)	φD	L	H1	H (約)
BC-3106	6	1/8	6	30.5	24	29
BC-3108	6	1/8	8	31	24	29
BC-3206	6	1/4	6	31	24	29
BC-3208	6	1/4	8	31	24	29
BC-3210	6	1/4	10	35	24	29
BC-3308	6	3/8	8	31	24	29
BC-3310	6	3/8	10	35	24	29

BR 銅管用リング型

油・空圧機器に

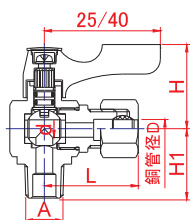

品番	φd	A (R)	φD	L	H1	H (約)
BR-3106	6	1/8	6	32	24	29
BR-3206	6	1/4	6	32	24	29
BR-3202	6	1/4	6.35	32	24	29
BR-3208	6	1/4	8	33	24	29
BR-3308	6	3/8	8	33	24	29
BR-3303	6	3/8	9.53	35	24	29
BR-3310	6	3/8	10	35	24	29