


## BF 銅管用フレアー型

油・空圧機器に

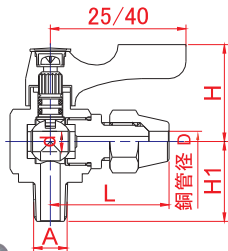


品番	φd	A (R)	φD	L	H1	H(約)
BF-3106	6	1/8	6	35	24	29
BF-3206	6	1/4	6	35	24	29
BF-3202	6	1/4	6.35	35	24	29
BF-3208	6	1/4	8	35	24	29
BF-3303	6	3/8	9.53	37	24	29
BF-3310	6	3/8	10	37	24	29

## BU ウレタンチューブ接続型

エア用ハンドツールに


RoHS対応

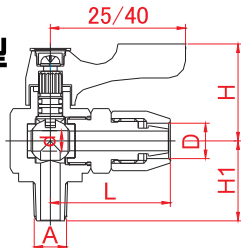

品番	φd	A (R)	D (適用チューブサイズ)	L	H1	H(約)
BU-3165	6	1/8	φ6.5 × φ10	36	24	29
BU-3185	6	1/8	φ8.5 × φ12.5	38	24	29
BU-3265	6	1/4	φ6.5 × φ10	36	24	29
BU-3285	6	1/4	φ8.5 × φ12.5	38	24	29
BU-3365	6	3/8	φ6.5 × φ10	36	24	29
BU-3385	6	3/8	φ8.5 × φ12.5	38	24	29

## BC 切替用、ワンタッチ接続型


ナイロン、ウレタンチューブに

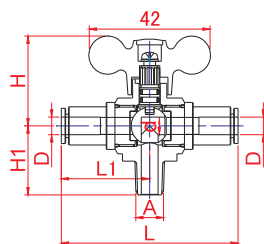

品番	φd	A (R)	φD	L1	L	H1	H(約)
BC-5166	6	1/8	6	30.5	61	24	31
BC-5288	6	1/4	8	32	62	24	31
BC-5310	6	3/8	10	35	70	24	31

## BR 切替用、銅管用リング型


油・空圧機器に

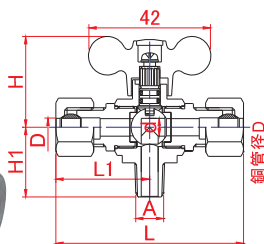

品番	φd	A (R)	φD	L1	L	H1	H(約)
BR-5166	6	1/8	6	32	64	24	31
BR-5288	6	1/4	8	33	66	24	31
BR-5310	6	3/8	10	35	70	24	31

## BH 切替用、ホースニップル一体型

あらゆるホースに

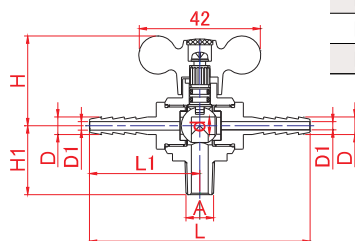

品番	φd	A (R)	φD	φD1	L1	L	H1	H(約)
BH-5166	6	1/8	6	3	38	76	24	31
BH-5288	6	1/4	8	5	40	80	24	31
BH-5299	6	1/4	9	6	40	80	24	31
BH-5310	6	3/8	10.5	6	42	84	24	31