
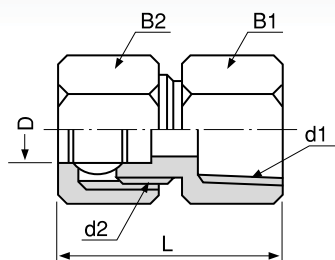


内ネジ・リングジョイント



C3604BD

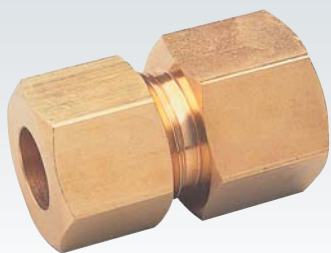

品番	取付ネジ	適用管外径	寸法 (mm)			
	d1	ϕD	B1	B2	d2	L(約)
RF-1104	PT1/8	4	14	12	PF1/8	26
RF-1105	PT1/8	5	14	12	PF1/8	26
RF-1106	PT1/8	6	14	12	PF1/8	27
RF-1108	PT1/8	8	14	17	PF1/4	31
RF-1206	PT1/4	6	17	17	PF1/4	32
RF-1202	PT1/4	6.35	17	17	PF1/4	32
RF-1208	PT1/4	8	17	17	PF1/4	33
RF-1203	PT1/4	9.53	17	21	PF3/8	35
RF-1210	PT1/4	10	17	21	PF3/8	35
RF-1306	PT3/8	6	21	17	PF1/4	35
RF-1302	PT3/8	6.35	21	17	PF1/4	35
RF-1308	PT3/8	8	21	17	PF1/4	36
RF-1303	PT3/8	9.53	21	21	PF3/8	38
RF-1310	PT3/8	10	21	21	PF3/8	38
RF-1312	PT3/8	12	22	24	PF1/2	41
RF-1304	PT3/8	12.7	22	24	PF1/2	42
RF-1406	PT1/2	6	26	17	PF1/4	37
RF-1402	PT1/2	6.35	26	17	PF1/4	37
RF-1408	PT1/2	8	26	17	PF1/4	38
RF-1403	PT1/2	9.53	26	21	PF3/8	40
RF-1410	PT1/2	10	26	21	PF3/8	40
RF-1412	PT1/2	12	26	24	PF1/2	44
RF-1404	PT1/2	12.7	26	24	PF1/2	45
RF-1415	PT1/2	15	28	27	PF5/8	45
RF-1405	PT1/2	15.88	28	27	PF5/8	46

両口リングジョイント

C3604BD

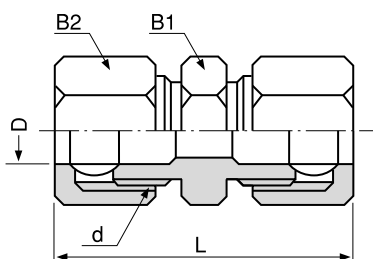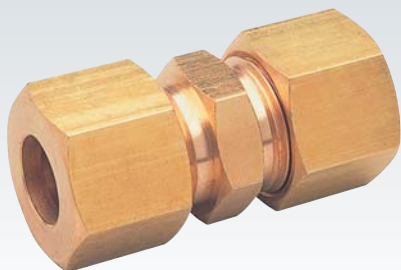

品番	適用管外径	寸法 (mm)			
	ϕD	B1	B2	d	L(約)
RS-2104	4	12	12	PF1/8	30
RS-2105	5	12	12	PF1/8	31
RS-2106	6	12	12	PF1/8	32
RS-2206	6	14	17	PF1/4	40
RS-2202	6.35	14	17	PF1/4	40
RS-2208	8	14	17	PF1/4	42
RS-2303	9.53	17	21	PF3/8	45
RS-2310	10	17	21	PF3/8	46
RS-2412	12	22	24	PF1/2	56
RS-2404	12.7	22	24	PF1/2	57
RS-2515	15	24	27	PF5/8	57
RS-2505	15.88	24	27	PF5/8	58
RS-2606	19.05	27	30	PF3/4	65