


# フレージョイント



C3604BD

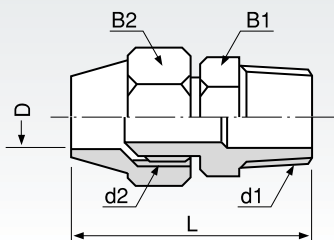

品番	取付ネジ	適用管外径	寸法 (mm)			
	d1	$\phi D$	B1	B2	d2	L(約)
FS-1106	PT1/8	6	12	16	UNF7/16×20	34
FS-1102	PT1/8	6.35	12	16	UNF7/16×20	34
FS-1108	PT1/8	8	14	17	UNF1/2×20	34
FS-1103	PT1/8	9.53	17	21	UNF5/8×18	36
FS-1110	PT1/8	10	17	21	UNF5/8×18	36
FS-1206	PT1/4	6	14	16	UNF7/16×20	37
FS-1202	PT1/4	6.35	14	16	UNF7/16×20	37
FS-1208	PT1/4	8	14	17	UNF1/2×20	37
FS-1203	PT1/4	9.53	17	21	UNF5/8×18	38
FS-1210	PT1/4	10	17	21	UNF5/8×18	38
FS-1212	PT1/4	12	22	24	UNF3/4×16	43
FS-1204	PT1/4	12.7	22	24	UNF3/4×16	43
FS-1306	PT3/8	6	17	16	UNF7/16×20	39
FS-1302	PT3/8	6.35	17	16	UNF7/16×20	39
FS-1308	PT3/8	8	17	17	UNF1/2×20	39
FS-1303	PT3/8	9.53	17	21	UNF5/8×18	40
FS-1310	PT3/8	10	17	21	UNF5/8×18	40
FS-1312	PT3/8	12	22	24	UNF3/4×16	45
FS-1304	PT3/8	12.7	22	24	UNF3/4×16	45
FS-1315	PT3/8	15	24	27	UNF7/8×14	49
FS-1305	PT3/8	15.88	24	27	UNF7/8×14	49
FS-1406	PT1/2	6	22	16	UNF7/16×20	42
FS-1402	PT1/2	6.35	22	16	UNF7/16×20	42
FS-1408	PT1/2	8	22	17	UNF1/2×20	42
FS-1403	PT1/2	9.53	22	21	UNF5/8×18	43
FS-1410	PT1/2	10	22	21	UNF5/8×18	43
FS-1412	PT1/2	12	22	24	UNF3/4×16	47
FS-1404	PT1/2	12.7	22	24	UNF3/4×16	47
FS-1415	PT1/2	15	24	27	UNF7/8×14	51
FS-1405	PT1/2	15.88	24	27	UNF7/8×14	51
FS-1615	PT3/4	15	28	27	UNF7/8×14	54
FS-1605	PT3/4	15.88	28	27	UNF7/8×14	54
FS-1606	PT3/4	19.05	28	32	UNS1 <sup>1</sup> / <sub>16</sub> ×14	59

# 両口フレージョイント

C3604BD

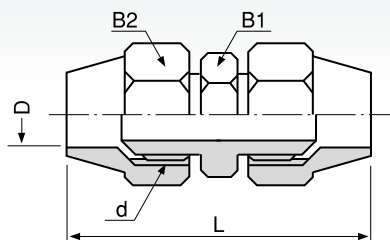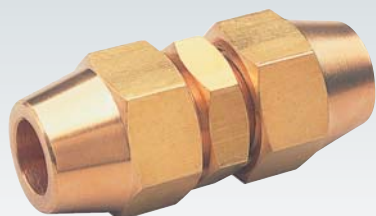

品番	適用管外径	寸法 (mm)			
	$\phi D$	B1	B2	d	L(約)
FS-2006	6	12	16	UNF7/16×20	46
FS-2022	6.35	12	16	UNF7/16×20	46
FS-2008	8	14	17	UNF1/2×20	46
FS-2033	9.53	17	21	UNF5/8×18	51
FS-2010	10	17	21	UNF5/8×18	51
FS-2012	12	22	24	UNF3/4×16	59
FS-2044	12.7	22	24	UNF3/4×16	59
FS-2015	15	24	27	UNF7/8×14	67
FS-2055	15.88	24	27	UNF7/8×14	67
FS-2066	19.05	28	32	UNS1 <sup>1</sup> / <sub>16</sub> ×14	79