


異径両口 フレアジョイント



C3604BD

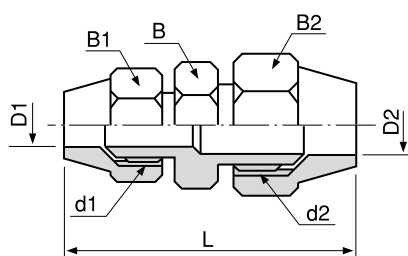

品番	適用管外径		寸法 (mm)					
	ϕ D1	ϕ D2	B	B1	B2	d1	d2	L(約)
FE-0602	6	6.35	12	16	16	UNF7/16×20	UNF7/16×20	46
FE-0608	6	8	14	16	17	UNF7/16×20	UNF1/2×20	46
FE-0603	6	9.53	17	16	21	UNF7/16×20	UNF5/8×18	49
FE-0610	6	10	17	16	21	UNF7/16×20	UNF5/8×18	49
FE-0208	6.35	8	14	16	17	UNF7/16×20	UNF1/2×20	46
FE-0203	6.35	9.53	17	16	21	UNF7/16×20	UNF5/8×18	49
FE-0210	6.35	10	17	16	21	UNF7/16×20	UNF5/8×18	49
FE-0803	8	9.53	17	17	21	UNF1/2×20	UNF5/8×18	49
FE-0810	8	10	17	17	21	UNF1/2×20	UNF5/8×18	49
FE-0310	9.53	10	17	21	21	UNF5/8×18	UNF5/8×18	51
FE-0312	9.53	12	22	21	24	UNF5/8×18	UNF3/4×16	55
FE-0304	9.53	12.7	22	21	24	UNF5/8×18	UNF3/4×16	55
FE-0315	9.53	15	24	21	27	UNF5/8×18	UNF7/8×14	59
FE-0305	9.53	15.88	24	21	27	UNF5/8×18	UNF7/8×14	59
FE-1012	10	12	22	21	24	UNF5/8×18	UNF3/4×16	55
FE-1004	10	12.7	22	21	24	UNF5/8×18	UNF3/4×16	55
FE-1015	10	15	24	21	27	UNF5/8×18	UNF7/8×14	59
FE-1005	10	15.88	24	21	27	UNF5/8×18	UNF7/8×14	59
FE-1204	12	12.7	22	24	24	UNF3/4×16	UNF3/4×16	59
FE-1215	12	15	24	24	27	UNF3/4×16	UNF7/8×14	63
FE-1205	12	15.88	24	24	27	UNF3/4×16	UNF7/8×14	63
FE-0415	12.7	15	24	24	27	UNF3/4×16	UNF7/8×14	63
FE-0405	12.7	15.88	24	24	27	UNF3/4×16	UNF7/8×14	63

内ネジ フレアジョイント

C3604BD

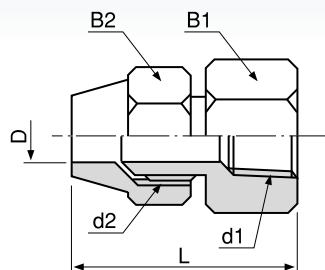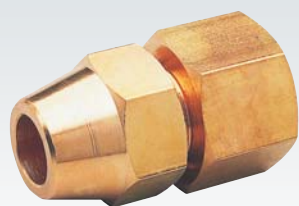

品番	取付ネジ	適用管外径	寸法 (mm)			
	d1		ϕ D	B1	B2	d2
FF-1106	PT1/8	6	14	16	UNF7/16×20	34
FF-1102	PT1/8	6.35	14	16	UNF7/16×20	34
FF-1108	PT1/8	8	14	17	UNF1/2×20	34
FF-1206	PT1/4	6	17	16	UNF7/16×20	37
FF-1202	PT1/4	6.35	17	16	UNF7/16×20	37
FF-1208	PT1/4	8	17	17	UNF1/2×20	37
FF-1203	PT1/4	9.53	17	21	UNF5/8×18	37
FF-1210	PT1/4	10	17	21	UNF5/8×18	37
FF-1306	PT3/8	6	21	16	UNF7/16×20	39
FF-1302	PT3/8	6.35	21	16	UNF7/16×20	39
FF-1308	PT3/8	8	21	17	UNF1/2×20	39
FF-1303	PT3/8	9.53	21	21	UNF5/8×18	39
FF-1310	PT3/8	10	21	21	UNF5/8×18	39
FF-1312	PT3/8	12	21	24	UNF3/4×16	43
FF-1304	PT3/8	12.7	21	24	UNF3/4×16	43
FF-1408	PT1/2	8	26	17	UNF1/2×20	41
FF-1403	PT1/2	9.53	26	21	UNF5/8×18	42
FF-1410	PT1/2	10	26	21	UNF5/8×18	42
FF-1412	PT1/2	12	26	24	UNF3/4×16	45
FF-1404	PT1/2	12.7	26	24	UNF3/4×16	45
FF-1415	PT1/2	15	26	27	UNF7/8×14	49
FF-1405	PT1/2	15.88	26	27	UNF7/8×14	49