
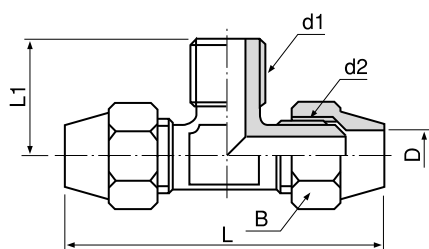


二方フレアーチーズ

C3604BD


C3771BD

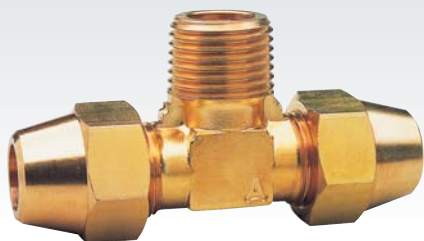

品番	取付ネジ	適用管外径	寸法 (mm)			
	d1	ϕD	B	d2	L1	L(約)
FT-2106	PT1/8	6	16	UNF7/16×20	19	58
FT-2102	PT1/8	6.35	16	UNF7/16×20	19	58
FT-2108	PT1/8	8	17	UNF1/2×20	19	58
FT-2206	PT1/4	6	16	UNF7/16×20	22	58
FT-2202	PT1/4	6.35	16	UNF7/16×20	22	58
FT-2208	PT1/4	8	17	UNF1/2×20	22	58
FT-2203	PT1/4	9.53	21	UNF5/8×18	24	64
FT-2210	PT1/4	10	21	UNF5/8×18	24	64
FT-2306	PT3/8	6	16	UNF7/16×20	25	64
FT-2302	PT3/8	6.35	16	UNF7/16×20	25	64
FT-2308	PT3/8	8	17	UNF1/2×20	25	64
FT-2303	PT3/8	9.53	21	UNF5/8×18	25	64
FT-2310	PT3/8	10	21	UNF5/8×18	25	64
FT-2312	PT3/8	12	24	UNF3/4×16	28	80
FT-2304	PT3/8	12.7	24	UNF3/4×16	28	80
FT-2403	PT1/2	9.53	21	UNF5/8×18	29	74
FT-2410	PT1/2	10	21	UNF5/8×18	29	74
FT-2412	PT1/2	12	24	UNF3/4×16	29	80
FT-2404	PT1/2	12.7	24	UNF3/4×16	29	80
FT-2415	PT1/2	15	27	UNF7/8×14	32	96
FT-2405	PT1/2	15.88	27	UNF7/8×14	32	96
FT-2606	PT3/4	19.05	32	UNS11/16×14	34	103

フレアーナット

C3604BD

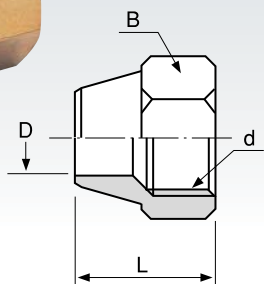


品番	適用管外径	寸法 (mm)		
	ϕD	d	B	L
FN-1016	6	PF1/8	12	14
FN-1006	6	UNF7/16×20	16	17.5
※FN-1022	6.35	UNF7/16×20	16	17.5
FN-1008	8	UNF1/2×20	17	18
※FN-1033	9.53	UNF5/8×18	21	21
FN-1010	10	UNF5/8×18	21	21
FN-1012	12	UNF3/4×16	24	24
※FN-1044	12.7	UNF3/4×16	24	24
FN-1015	15	UNF7/8×14	27	28
※FN-1055	15.88	UNF7/8×14	27	28
FN-1066	19.05	UNS11/16×14	32	32

※は六角カドにVミソ入

フレアーキャップ

C3604BD

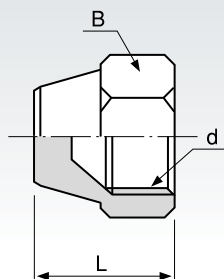

品番	寸法 (mm)		
	d	B	L
FN-0006	UNF7/16×20	16	17.5
FN-0008	UNF1/2×20	17	18
FN-0010	UNF5/8×18	21	21
FN-0012	UNF3/4×16	24	24
FN-0015	UNF7/8×14	27	28
FN-0066	UNS11/16×14	32	32