


Machine table clamps



Base unit BAS0



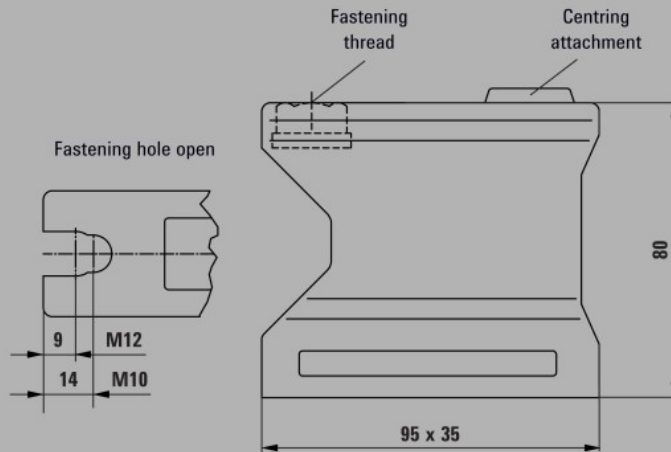

№	Clamping height	Fastening thread	For socket head screw DIN 912	kg	qty.	V3
	mm					
BAS0	80	M 10	M10 / M12	0.45	1	



- 80 mm extension
- Stackable
- Fastening hole open, including cheese head screw
- Suitable for all BESSEY BAS clamps

Table of dimensions BAS

	Clamping height "a"	Opening opt. "a1"	Throat depth "b"	Distance "b1"	Clamping arm "r"	Housing height "H"	Socket head screws	Fastening hole	Clamping force max. N
	mm	mm	mm	mm	mm	mm	DIN 912		
BAS-C9-4 	88	42	40	36.5	75	78	M10 / M12	open 	16,000
BAS-C10-6 	97	42	60	36.5	94	78	M10 / M12		12,000
BSP-C10-6 	97	42	60	36.5	94	78	M10 / M12		12,000
BAS-CB9-4 	88	42	40	36.5	75	78	M10 / M12	closed 	16,000
BAS-CB10-6 	97	42	60	36.5	94	78	M10 / M12		12,000
BSP-CB10-6 	97	42	60	36.5	94	78	M10 / M12		12,000
BAS0	80	-	-	-	-	80	M10 / M12	open	-