


ダブルプレス

T

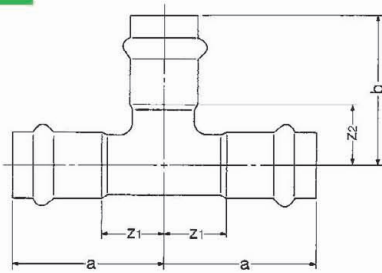


ティー

呼び径 (Su)	a	b	z1	z2	単価	ケース入数
13	45	45	17	17	1,870	S60
20	54	54	22	22	2,230	M70
20×13	54	49	22	21	2,870	M80
25	63	63	27	27	2,750	M40
25×13	63	60	27	32	3,530	M50
25×20	63	59	27	27	3,530	M50
30	113	113	60	60	4,390	M15
30×13	113	74	60	46	5,280	M20
30×20	113	78	60	46	5,280	M20
30×25	113	82	60	46	5,280	M20
40	121	121	60	60	5,830	M10
40×13	121	76	60	48	7,030	M10
40×20	121	80	60	48	7,030	M10
40×25	121	84	60	48	7,030	M10
40×30	121	113	60	60	7,030	M10
50	119	119	51	51	6,510	M8
50×13	119	80	51	52	7,470	M10
50×20	119	84	51	52	7,470	M10
50×25	119	94	51	58	7,470	M10
50×30	119	123	51	70	7,470	M10
50×40	119	121	51	60	7,470	M8
60	141	141	63	63	8,590	M3
60×20	131	92	53	60	9,270	M5
60×25	131	96	53	60	9,270	M5
60×30	141	123	63	70	9,270	M5
60×40	141	131	63	70	9,270	M4
60×50	141	129	63	61	9,270	M3

BS


※補修時やり取り用

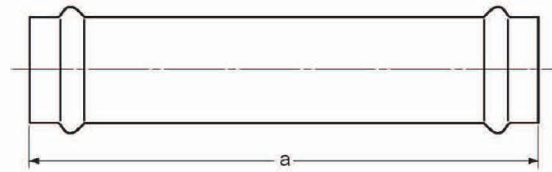

ベアソケット

呼び径 (Su)	a	単価	ケース入数
13	130	1,460	S80
20	145	1,920	M80
25	153	2,360	M40
30	128	2,810	S20
40	144	3,480	M25
50	158	4,540	M20
60	182	6,620	M8


R

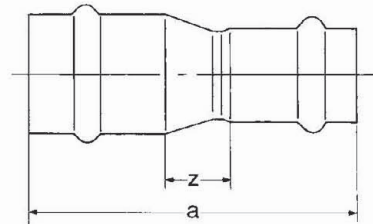

レジューサ

呼び径 (Su)	a	z	単価	ケース入数
20×13	75	15	1,240	S70
25×13	85	21	1,680	S60
25×20	84	16	1,680	S60
30×13	126	45	2,080	S30
30×20	125	40	2,080	S30
30×25	116	27	2,080	S30
40×13	144	55	2,570	M40
40×20	143	50	2,570	M40
40×25	147	50	2,570	M40
40×30	150	36	2,570	M20
50×20	177	77	5,380	M30
50×25	159	55	3,220	M30
50×30	176	55	3,220	M25
50×40	163	34	3,220	M20
60×20	204	94	6,450	M15
60×25	209	95	6,450	M10
60×30	196	65	4,600	M10
60×40	204	65	4,600	M10
60×50	187	41	4,600	M10

S

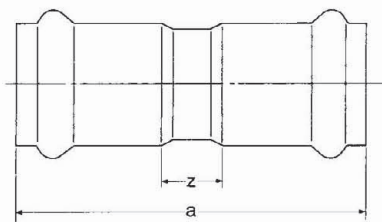

ソケット

呼び径 (Su)	a	z	単価	ケース入数
13	67	11	940	S100
20	76	12	1,240	S80
25	84	12	1,530	S50
30	128	22	1,820	S20
40	144	22	2,260	M25
50	158	22	2,940	M20
60	182	26	4,260	M9

ケースの大きさは SS:特小(190×170×140mm) S:小(320×200×140mm) M:中(380×320×140mm) L:大(380×320×270mm)