


BENKAN 鋼板製キャップ

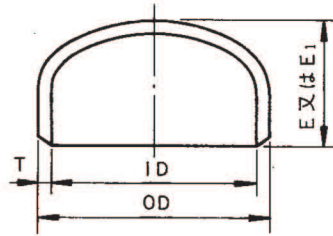

キャップ

径の呼び		外径 OD	FSGP		Sch40		Sch80		背から端面 までの距離		限界 厚さ	概略重量 (kg)		
A	B		内径 ID	厚さ T	内径 ID	厚さ T	内径 ID	厚さ T	E	E ₁		FSGP	Sch40	Sch80
15	1/2	21.7	16.1	2.8	16.1	2.8	14.3	3.7	25.4	—	—	0.039	0.039	0.051
20	3/4	27.2	21.6	2.8	21.4	2.9	19.4	3.9	25.4	—	—	0.048	0.050	0.067
25	1	34.0	27.6	3.2	27.2	3.4	25.0	4.5	38.1	—	—	0.103	0.109	0.144
32	1 1/4	42.7	35.7	3.5	35.5	3.6	32.9	4.9	38.1	—	—	0.141	0.145	0.197
40	1 1/2	48.6	41.6	3.5	41.2	3.7	38.4	5.1	38.1	—	—	0.162	0.171	0.236
50	2	60.5	52.9	3.8	52.7	3.9	49.5	5.5	38.1	44.5	5.5	0.228	0.234	0.330
65	2 1/2	76.3	67.9	4.2	65.9	5.2	62.3	7.0	38.1	50.8	7.0	0.339	0.420	0.565
80	3	89.1	80.7	4.2	78.1	5.5	73.9	7.6	50.8	63.5	7.6	0.507	0.664	0.917
90	3 1/2	101.6	93.2	4.2	90.2	5.7	85.4	8.1	63.5	76.2	8.1	0.706	0.958	1.36
100	4	114.3	105.3	4.5	102.3	6.0	97.1	8.6	63.5	76.2	8.6	0.877	1.17	1.68
125	5	139.8	130.8	4.5	126.6	6.6	120.8	9.5	76.2	88.9	9.5	1.29	1.90	2.73
150	6	165.2	155.2	5.0	151.0	7.1	143.2	11.0	88.9	101.6	11.0	1.99	2.83	4.38
200	8	216.3	204.7	5.8	199.9	8.2	190.9	12.7	101.6	127.0	12.7	3.61	5.11	7.91
250	10	267.4	254.2	6.6	248.8	9.3	237.2	15.1	127.0	152.4	12.7	6.33	8.92	16.4
300	12	318.5	304.7	6.9	297.9	10.3	283.7	17.4	152.4	177.8	12.7	9.43	14.1	26.4
350	14	355.6	339.8	7.9	333.4	11.1	317.6	19.0	165.1	190.5	12.7	13.2	18.6	34.9
400	16	406.4	390.6	7.9	381.0	12.7	363.6	21.4	177.8	203.2	12.7	16.6	26.7	49.0
450	18	457.2	441.4	7.9	428.6	14.3	409.6	23.8	203.2	228.6	12.7	21.2	41.5	69.0
500	20	508.0	492.2	7.9	477.8	15.1	455.6	26.2	228.6	254.0	12.7	26.4	54.0	93.7
550	22	558.8	—	—	527.0	15.9	501.6	28.6	254.0	254.0	12.7	—	64.8	116.5
600	24	609.6	—	—	574.6	17.5	547.6	31.0	266.7	304.8	12.7	—	90.2	159.7
650	26	660.4	—	—	622.6	18.9	592.4	34.0	266.7	—	—	—	100	180

☆ 概略重量は基準寸法による計算値であり、炭素鋼の比重 7.85g/cm³ を使用しています。