


Laiket—Dimensions

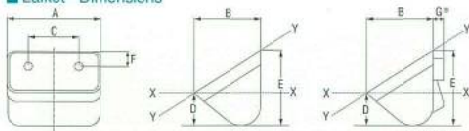

Laiket (nylon)—Specifications

(Unit: mm)

Style	Model	Hole section rear surface	A	B	C	D	E	F	Hole dia.	No. of holes	Capacity (cm ³) X-X	Capacity (cm ³) Y-Y	Mounting button	Color	
														Standard	Heat-resistant
Standard	3II	Concave	77	54	41	31	72	18	7.0	2	80	130	M6	White/black	Light yellow
	3FI	Flat	88	72	47	42	83	19	7.0	2	155	245	M6	Black	Light yellow
	4II	Flat	98	73	53	45	84	21	7.0	2	176	270	M6	White/black	Light yellow
	4FI	Concave	107	75	63	47	88	22	7.0	2	212	330	M6	Black	Light yellow
	5II	Flat	120	84	78	45	98	26	7.5	2	250	400	M6	White/black	Light yellow
	6II	Flat	146	102	92	52	116	28	7.5	2	450	760	M6	White/black	Light yellow
	8II	Flat	196	132	138	65	150	33	9.0	2	940	1,800	M8	White/black	—
	10II	Flat	246	155	50-70-50	84	180	44	9.0	4	1,750	3,150	M8	White/black	Light yellow
	2III	Concave	300	155	70-70-70	78	182	46	9.0	4	1,995	4,000	M8	White/black	—
	14II	Concave	349	182	90-90-90	80	189	38	9.0	4	3,300	5,500	M8	White	—
Nifty	N-4I	Flat	94	83	48	47	82	25	6.5	2	200	305	M6	Black	—
	N-5I	Flat	111	100	62	52	100	25	6.5	2	315	535	M6	Black	—
	N-6I	Concave	146	113	93	59	116	28	8.0	2	560	900	M6	White/black	—
	N-7I	Concave	171	133	113	71	134	34	9.0	2	900	1,500	M8	White/black	—
	N-8I	Concave	203	152	130	88	152	38	9.0	2	1,570	2,250	M8	Black	—
	N-10I	Concave	252	183	50-70-50	106	180	43	9.0	4	2,500	3,800	M8	White/black	—
Keep	K-7II	Concave	302	176	68-72-68	97	181	40	9.5	4	2,800	4,500	M8	White/black	—
	K-9I	Flat	171	113	113	57	135	33	9.0	2	610	1,180	M8	White/black	—
Shallow	A-4II	Flat	231	137	82-82	71	128	33	9.0	3	1,250	1,950	M8	Black	—
	A-4III	Flat	107.5	63	57.5	27	59	15.5	7.0	2	84	170	M6	Black	—
	MG-6I	Flat	145	108	92	34	121	27	7.5	2	280	800	M6	Black	—
Columbus	MG-8I	Flat	195	131	138	49	152	33	9.0	2	650	1,700	M8	Black	—
	C-9I	Concave	241	134	79-79	95	167	37	9.0	3	1,800	2,750	M8	Black	—
Shortcut	C-11I	Concave	291	134	67-67-67	95	165	37	9.0	4	2,190	3,340	M8	Black	—
	SC-112I	Convex	112	75	63	48	75	19.5	7.0	2	230	320	M6	Black	—
	SC-125I	Convex	125	84	78	45	70	13.5	7.0	2	270	370	M6	Black	—
Induction	SC-150I	Convex	151	101	92	55	85	19.5	7.0	2	430	620	M6	Black	—
	Y-4I	Flat	92	54	55	30	60	13	7.0	2	88	145	M6	Black	—
	Y-6II	Flat	165	90	56	65	105	35	10.0	2	520	665	M8	Black	—
	Y-8I	Convex	184	126	113	119	167	96	10.0	2	1,270	1,690	M8	White	—

G: 8mm (Shortcut style), 10mm (Induction style, Y-8I)


Note: Due to the nature of nylon, dimensional changes may occur after absorbing water.

Laiket (specialty polyethylene)—Specifications

(Unit: mm)

Style	Model	Hole section rear surface	A	B	C	D	E	F	Hole dia.	No. of holes	Capacity (cm ³) X-X	Capacity (cm ³) Y-Y	Mounting button	Color
Standard	3II	Concave	76.5	52.5	41	31	71	17	7.0	2	80	130	M6	White
	4II	Flat	96	72	53	43	82	21	7.0	2	176	270	M6	White
	6II	Flat	146	100	92	53	114	28	7.5	2	450	760	M6	White

Pivoted bucket—Dimensions

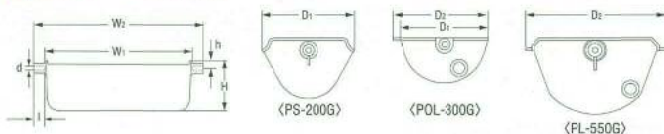

Pivoted bucket (nylon)—Specifications

(Unit: mm)

Model	(Side) Boss for reverse rotation	W1	W2	D1	D2	H	h	l	d	Capacity(ℓ)	Color
PS-200G	Not	205	240	157	—	101	20	18	9.4	1.5	Light yellow
POL-300G	Presence	306	352	143	160	75	10	20	9.5	2.3	Light yellow
PL-550G	Presence	546	600	—	237	131	20	26.5	10	9	Light yellow

Note: Due to the nature of nylon, dimensional changes may occur after absorbing water.