


C: 最小曲げ半径 (固定)
D: 最小曲げ半径 (可動)
E: 最大圧力 (MPa ゲージ)

◆フレキシブル配管

ステンレス鋼AISI 316L


NW10	12.2	250	30	100	0.05	C105-11-285
NW16	17.2	250	30	130	0.05	C105-12-285
NW25	26.2	250	50	210	0.05	C105-14-285
NW40	41.2	250	80	260	0.05	C105-16-285
NW50	52.2	250	100	320	0.05	C105-17-285
NW10	12.2	500	30	100	0.05	C105-11-286
NW16	17.2	500	30	130	0.05	C105-12-286
NW25	26.2	500	50	210	0.05	C105-14-286
NW40	41.2	500	80	260	0.05	C105-16-286
NW50	52.2	500	100	320	0.05	C105-17-286
NW10	12.2	750	30	100	0.05	C105-11-300
NW16	17.2	750	30	130	0.05	C105-12-300
NW25	26.2	750	50	210	0.05	C105-14-300
NW40	41.2	750	80	260	0.05	C105-16-300
NW50	52.2	750	100	320	0.05	C105-17-300
NW10	12.2	1000	30	100	0.05	C105-11-287
NW16	17.2	1000	30	130	0.05	C105-12-287
NW25	26.2	1000	50	210	0.05	C105-14-287
NW40	41.2	1000	80	260	0.05	C105-16-287
NW50	52.2	1000	100	320	0.05	C105-17-287

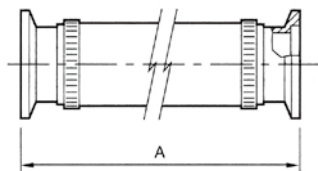

◆PVCチューブ(両端NWフランジ)


ステンレス鋼AISI 316L

NW10	500	C105-11-055
NW16	500	C105-12-055
NW25	500	C105-14-055
NW40	500	C105-16-055
NW50	500	C105-17-055
NW10	1000	C105-11-155
NW16	1000	C105-12-155
NW25	1000	C105-14-155
NW40	1000	C105-16-155
NW50	1000	C105-17-155

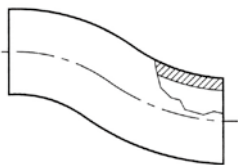


◆PVCチューブ(長さ1m)

内径 ³ / ₄ インチチューブ	H021-00-016
内径1インチチューブ	H021-00-017
内径1 ¹ / ₂ インチチューブ	H021-00-018
内径2インチチューブ	H021-00-019

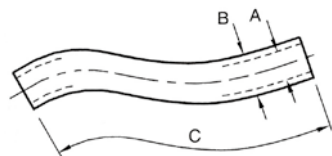

◆ゴムホース(ネオプレン)

5 mm×19 mm	5	19	1000	H021-00-002
7 mm×17 mm	7	17	1000	H021-00-003
9 mm×25 mm	9	25	1000	H021-00-004
12 mm×28 mm	12	28	1000	H021-00-005
20 mm×34 mm	20	34	1000	H021-00-006
補強ホース	25	32	305	C066-00-025

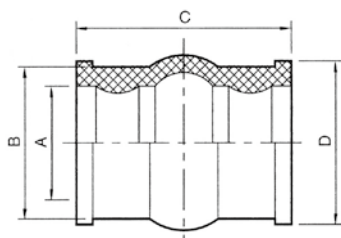

◆モールドスリーブ

ネオプレン

NW10	13	21	38	23	C265-01-002
NW25	27	36	55	38	C265-01-004