

SL-50~53

POCKET LOUPE

- SL-50**
 ● 10x/20mm diam.
 ● 83mm length
 ● 50mm (case)

- SL-51**
 ● 8x/25mm dia.&
 15x/13mm dia.
 ● 150mm length
 ● 84mm (case)

- SL-52**
 ● Combination of 3x, 4x & 5x lens for max. 10x magnification
 ● 19mm diam. lens
 ● 83mm length
 ● 50mm (case)

- SL-53**
 ● Sharp and very distinct images with no color distortion
 ● Ideal for jewelry appraisal
 ● 18x/17mm diam.
 ● 63mm length
 ● 40mm (case)



SL-55~57

INSPECTION LOUPE

- Focus adjustment by sliding lens sleeve
 ● Built-in scale (detachable)




- 10x
 ● 10mm diam. view
 ● Scale L

- 15x
 ● 6mm diam. view
 ● Scale S

- 22x
 ● 4mm diam. view
 ● Scale S

BUILT-IN SCALE

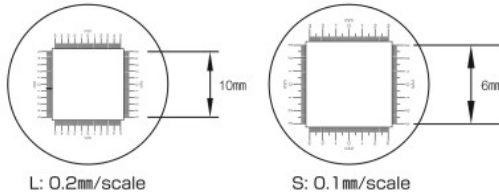


SL-12

INSPECTION LOUPE

- Inspection loupe equipped with crosshairs
 ● Wide type light-through cylinder for bright and clear view



- x10 Glass Lens
 ● Lens diameter : 30mm
 ● Crosshairs 0.1mm x 240
 ● Ext. Size : dia.38 x 50(H)
 ● with carrying pouch

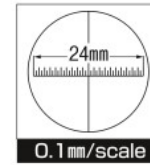


Item No.	SL-50	SL-51	SL-52	SL-53	SL-12	SL-55	SL-56	SL-57
Magnification	x10	x8 & x15	x3, 4 & 5	x18	x10	x10	x15	x22
Lens Material	Glass	Glass	White Glass	White Glass	White Glass	White Glass	White Glass	White Glass
Lens Structure	1+1	1+1	single	5-fold	1+1	1+1	1+1	1+1

※ 1+1 Structure : 1 pce. of eyepiece and 1 pce. of objective lens
 ※ 1+2 Structure : Achromatic Lens - combination of different refractive lens minimizes chromatic aberration.
 ※ 5-fold lens : superior to achromatic lens in aspect of no aberration and creates clearer image.

SL-64

FOLDABLE MAGNIFIER

- x 3.5 Magnification acrylic lens
 ● Lens diameter: 40mm
 ● Foldable arm, flexible design
 ● Magnet attachment
 ● with carrying case

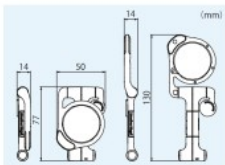

Self-standing for handsfree



Collapsible to fit carrying case

SL-72

UTILITY LOUPE

- 3X 65mm diam. lens consists of aberration-free white lens.
 ● Versatile use with chrome-plated frame and wooden shaft.
 ● O.A. length: 175mm



SL-32 · 33

LED POCKET LOUPE

- Slide out the lens to turn on the light automatically.
 ● Battery CR2016 (2 pcs.)



- 3.5X, ϕ 35mm Acrylic lens
 ● 79 x 44 x 12(H)mm



- 3X, ϕ 45mm Acrylic lens
 ● 90 x 55 x 13(H)mm