

ⓘ Non JIS material definition is listed on P.1351 - 1352

JTWF (Converting tapered screw type)

①Rc(PT) ②R(PT)

Ⓜ Brass (C3604)

ⓘ Use in atmospheric pressure 980kPa (10kgf/cm²) or lower. Thread JIS B0203 tapered thread for tube R_{Rc}(PT)

B	T	D	D1	d1	d2	f	ℓ	S	d	① Rc(PT)	② RP(T)	Part Number		L 10mm increments
												Type	No.	
17	16	13.8	—	6	—	—	10	6.01	13.157	1/8	1/4	JTWF	12	50~200
21	17	17.3	—	8	—	—	12	6.35	16.662	1/4	3/8		23	
17	16	13.8	11	—	6	15	10	3.97	9.728	1/4	1/8	21		
21	17	17.3	14	10	8	—	—	6.01	13.157	3/8	1/4	32		



Order

Part Number — L
JTWF 12 — 150



Price

Quotation




Days to Ship

Quotation



Example

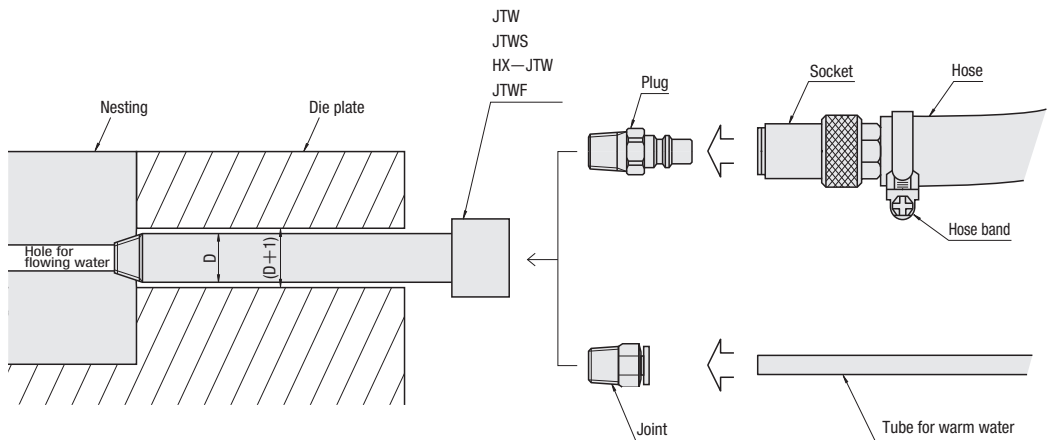

Cooling Components ②
Joints · Hoses
Cooling Inside of Mold