


Applications use	NK1536T	NK2035T	NK2535T	NK3030T	NK3532T	NK4031T	NK4530T	NK5031T	NK5532T	NK6030T	NK6533T	NK7032T	NK7533T
$\alpha^\circ$	15°	20°	25°	30°	35°	40°	45°	50°	55°	60°	65°	70°	75°
Bore chamfering	$\phi 8 \sim 36\text{mm}$	$\phi 8 \sim 36\text{mm}$	$\phi 8 \sim 35\text{mm}$	$\phi 8 \sim 33\text{mm}$	$\phi 8 \sim 32\text{mm}$	$\phi 8 \sim 31\text{mm}$	$\phi 8 \sim 29\text{mm}$	$\phi 12 \sim 31\text{mm}$	$\phi 15 \sim 32\text{mm}$	$\phi 15 \sim 30\text{mm}$	$\phi 20 \sim 33\text{mm}$	$\phi 22 \sim 32\text{mm}$	$\phi 25 \sim 33\text{mm}$

## Wide variety!

- Angle 15° ~ 75° (by 5° increments) can be chosen according your application
- Insert available are rich and will meet with various applications you may need

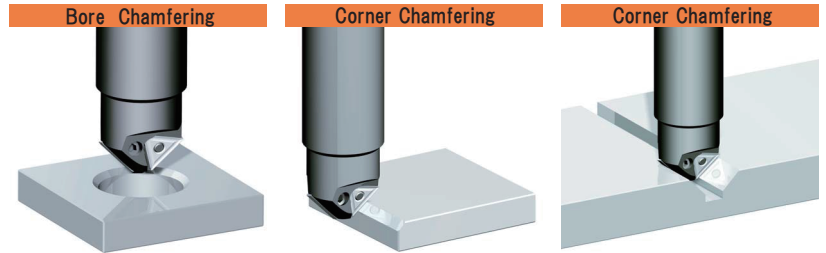

### Body

Model. No.	Blades	Dimensions (mm)							$\alpha^\circ$
		$\phi D$	Minimum cutting diameter $\phi D_s$	$\phi d$	L	$\phi s$	$\phi n$	S	
NK1536T-20	2	37.9	8	20	130	100	30	4.0	15°
NK1536T-25	2	37.9	8	25	130	100	30	4.0	15°
NK1536T	2	37.9	8	32	130	100	30	4.0	15°
NK1536TL	2	37.9	8	32	170	140	30	4.0	15°
NK2035T-20	2	37.1	8	20	130	100	30	5.3	20°
NK2035T-25	2	37.1	8	25	130	100	30	5.3	20°
NK2035T	2	37.1	8	32	130	100	30	5.3	20°
NK2035TL	2	37.1	8	32	170	140	30	5.3	20°
NK2535T-20	2	36.0	8	20	130	100	30	6.5	25°
NK2535T-25	2	36.0	8	25	130	100	30	6.5	25°
NK2535T	2	36.0	8	32	130	100	30	6.5	25°
NK2535TL	2	36.0	8	32	170	140	30	6.5	25°
NK3030T-20	2	34.8	8	20	130	100	30	7.7	30°
NK3030T-25	2	34.8	8	25	130	100	30	7.7	30°
NK3030T	2	34.8	8	32	130	100	30	7.7	30°
NK3030TL	2	34.8	8	32	170	140	30	7.7	30°
NK3532T-20	2	33.3	8	20	130	100	30	8.9	35°
NK3532T-25	2	33.3	8	25	130	100	30	8.9	35°
NK3532T	2	33.3	8	32	130	100	30	8.9	35°
NK3532TL	2	33.3	8	32	170	140	30	8.9	35°
NK4031T-20	2	31.7	8	20	130	100	30	9.9	40°
NK4031T-25	2	31.7	8	25	130	100	30	9.9	40°
NK4031T	2	31.7	8	32	130	100	30	9.9	40°
NK4031TL	2	31.7	8	32	170	140	30	9.9	40°
NK4530T-20	2	29.9	8	20	130	100	30	10.9	45°
NK4530T-25	2	29.9	8	25	130	100	30	10.9	45°
NK4530T	2	29.9	8	32	130	100	30	10.9	45°
NK4530TL	2	29.9	8	32	170	140	30	10.9	45°
NK5031T-20	2	31.9	12	20	130	100	30	11.8	50°
NK5031T-25	2	31.9	12	25	130	100	30	11.8	50°
NK5031T	2	31.9	12	32	130	100	30	11.8	50°
NK5031TL	2	31.9	12	32	170	140	30	11.8	50°
NK5532T-20	2	32.7	15	20	130	100	30	12.7	55°
NK5532T-25	2	32.7	15	25	130	100	30	12.7	55°
NK5532T	2	32.7	15	32	130	100	30	12.7	55°
NK5532TL	2	32.7	15	32	170	140	30	12.7	55°
NK6030T-20	2	30.5	15	20	130	100	30	13.4	60°
NK6030T-25	2	30.5	15	25	130	100	30	13.4	60°
NK6030T	2	30.5	15	32	130	100	30	13.4	60°
NK6030TL	2	30.5	15	32	170	140	30	13.4	60°
NK6533T-20	2	33.1	20	20	130	100	30	14.0	65°
NK6533T-25	2	33.1	20	25	130	100	30	14.0	65°
NK6533T	2	33.1	20	32	130	100	30	14.0	65°
NK6533TL	2	33.1	20	32	170	140	30	14.0	65°
NK7032T-20	2	32.6	22	20	130	100	30	14.5	70°
NK7032T-25	2	32.6	22	25	130	100	30	14.5	70°
NK7032T	2	32.6	22	32	130	100	30	14.5	70°
NK7032TL	2	32.6	22	32	170	140	30	14.5	70°
NK7533T-20	2	33.0	25	20	130	100	30	15.0	75°
NK7533T-25	2	33.0	25	25	130	100	30	15.0	75°
NK7533T	2	33.0	25	32	130	100	30	15.0	75°
NK7533TL	2	33.0	25	32	170	140	30	15.0	75°

※ Inset is not Included. Please Order Separately.  
 ※ Lock pin Wrench we have Standard Equipment.



When mounting insert, please do not take reverse tightening.  
 Due to the eccentricity looking mechanism, poor accuracy or breakage of insert may be occurred  
 When replacing insert, please confirm whether you have been taking reserve tightening or not.