



Corner Chamfering

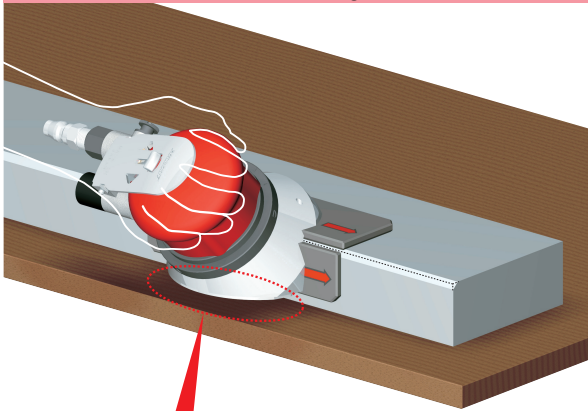

This corner designed do not touch the bottom

Unique and advanced Air operated Portable Handy Chamfering machine !

- only 2kg weight !
- Capacity: Thread ~ C4

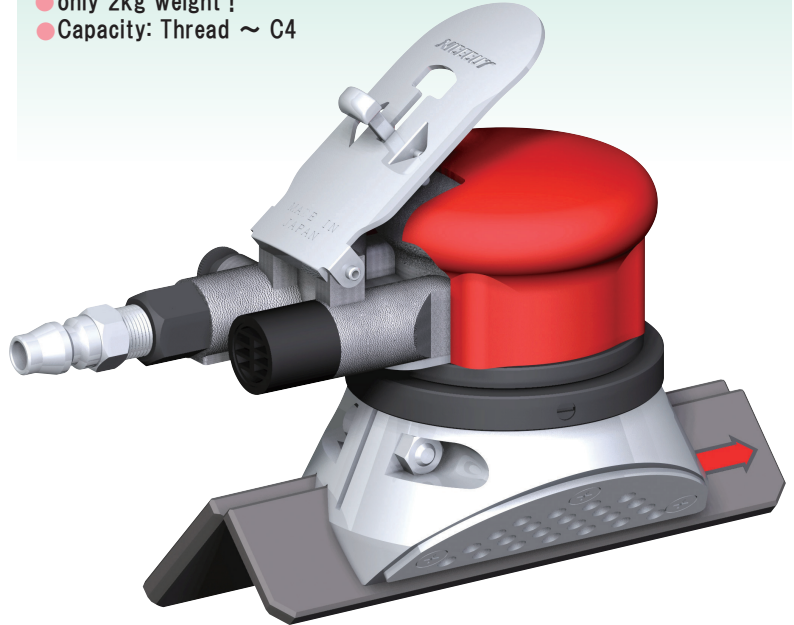

Specification


Air Pressure	0.49~0.68MPa(5~7kg/cm ²)
Non-Load Rotational	10,000r.p.m.
Air Consumption	0.19m ³ /min
Capacity	~C4
Work Thickness	more than 6mm
Weight	2kg

Processing Example

[Chamfering of one corner per 20m in the processing of 1C]

- Insert : SDMW11T4AFEN12 ZA20D
- Material..... SUS304

The Openings Enlarged Photo

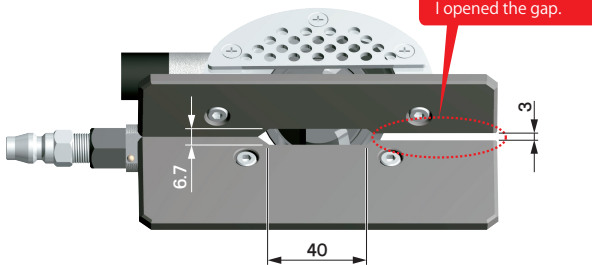

For burr-removal, we make a space Cutter area of Guide Plate groove is widen

※ The dimension could be little different

