



(単位：mm)

ハーフユニオン (Rねじ)

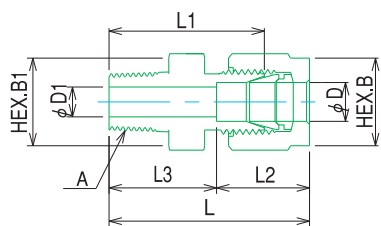

呼び径D	A	D1	B	B1	L	L1	L2	L3	品番
3.2	R1/8	2.7	10	12	30	23.5	13	17	F900-H-3.2A
3.2	R1/4	2.7	10	14	33	26.5	13	20	F900-H-3.2B
6.35	R1/8	5	14	14	33	26	15	18	F900-H-6.35A
6.35	R1/4	5	14	14	36	29	15	21	F900-H-6.35B
6.35	R3/8	5	14	17	37	30	15	22	F900-H-6.35C
6.35	R1/2	5	14	22	42	35	15	27	F900-H-6.35D
9.52	R1/8	5	17	17	36	28	17.5	18.5	F900-H-9.52A
9.52	R1/4	7.5	17	17	39	31	17.5	21.5	F900-H-9.52B
9.52	R3/8	7.5	17	17	40	32	17.5	22.5	F900-H-9.52C
9.52	R1/2	7.5	17	22	44	36	17.5	26.5	F900-H-9.52D
12.7	R1/8	5	22	22	41.5	30.5	24	17.5	F900-H-12.7A
12.7	R1/4	7.5	22	22	44.5	33.5	24	20.5	F900-H-12.7B
12.7	R3/8	10	22	22	45.5	34.5	24	21.5	F900-H-12.7C
12.7	R1/2	10	22	22	48.5	37.5	24	24.5	F900-H-12.7D
19.05	R1/8	5	29	29	44.5	33.5	25.2	19.3	F900-H-19.05A
19.05	R1/4	7.5	29	29	47.5	36.5	25.2	22.3	F900-H-19.05B
19.05	R3/8	10	29	29	48.5	37.5	25.2	23.3	F900-H-19.05C
19.05	R1/2	12.7	29	29	51.5	40.5	25.2	26.3	F900-H-19.05D
19.05	R3/4	16	29	29	53.5	42.5	25.2	28.3	F900-H-19.05E
19.05	R1	16	29	29	57	46	25.2	31.8	F900-H-19.05F
25.4	R3/4	15.7	38	35	57.4	45.2	31.2	26.2	F900-H-25.4E
25.4	R1	22.4	38	35	62.2	50	31.2	31	F900-H-25.4F

ハーフユニオン (NPTねじ)

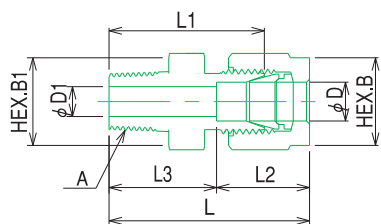

呼び径D	A	D1	B	B1	L	L1	L2	L3	品番
3.2	1/8NPT	2.7	10	12	30	23.5	13	17	F900-H-3.2AN
3.2	1/4NPT	2.7	10	14	33	26.5	13	20	F900-H-3.2BN
6.35	1/8NPT	5	14	14	33	26	15	18	F900-H-6.35AN
6.35	1/4NPT	5	14	14	36	29	15	21	F900-H-6.35BN
6.35	3/8NPT	5	14	19	37	30	15	22	F900-H-6.35CN
6.35	1/2NPT	5	14	22	42	35	15	27	F900-H-6.35DN
9.52	1/8NPT	5	17	17	36	28	17.5	18.5	F900-H-9.52AN
9.52	1/4NPT	7.5	17	17	39	31	17.5	21.5	F900-H-9.52BN
9.52	3/8NPT	7.5	17	19	40	32	17.5	22.5	F900-H-9.52CN
9.52	1/2NPT	7.5	17	22	44	36	17.5	26.5	F900-H-9.52DN
12.7	1/8NPT	5	22	22	41.5	30.5	24	17.5	F900-H-12.7AN
12.7	1/4NPT	7.5	22	22	44.5	33.5	24	20.5	F900-H-12.7BN
12.7	3/8NPT	10	22	22	45.5	34.5	24	21.5	F900-H-12.7CN
12.7	1/2NPT	10	22	22	48.5	37.5	24	24.5	F900-H-12.7DN
19.05	1/8NPT	5	29	29	44.5	33.5	25.2	19.3	F900-H-19.05AN
19.05	1/4NPT	7.5	29	29	47.5	36.5	25.2	22.3	F900-H-19.05BN
19.05	3/8NPT	10	29	29	48.5	37.5	25.2	23.3	F900-H-19.05CN
19.05	1/2NPT	12.7	29	29	51.5	40.5	25.2	26.3	F900-H-19.05DN
19.05	3/4NPT	16	29	29	53.5	42.5	25.2	28.3	F900-H-19.05EN