



超コンパクト自動溶接継手エルボ

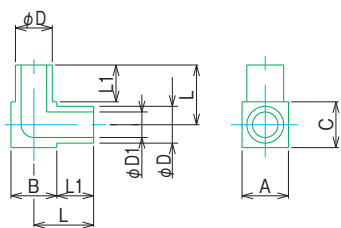


呼び径D	D1	L	L1	A	B	C	品番
6.35	4.4	10.3	6.35	8	7.9	7.9	UJL-6.35M-AW-S
9.52	7.4	11.9	6.35	11.1	11.1	11.1	UJL-9.52M-AW-S
12.7	10.3	13.5	6.35	14.3	14.3	14.3	UJL-12.7M-AW-S

超コンパクト自動溶接継手異径エルボ

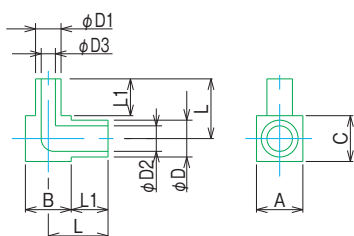


呼び径D	D1	D2	D3	L	L1	A	B	C	品番
9.52	6.35	7.4	4.4	11.9	6.35	11.1	11.1	11.1	UJL-9.52M×6.35M-AW-S
12.7	6.35	10.3	4.4	13.5	6.35	14.3	14.3	14.3	UJL-12.7M×6.35M-AW-S
12.7	9.52	10.3	7.4	13.5	6.35	14.3	14.3	14.3	UJL-12.7M×9.52M-AW-S

超コンパクト自動溶接継手ティ

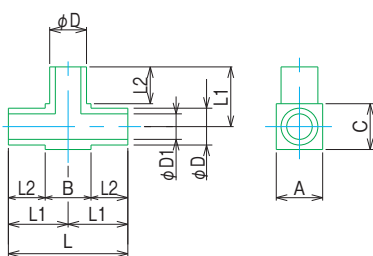

呼び径D	D1	L	L1	L2	A	B	C	品番
6.35	4.4	20.6	10.3	6.35	8	7.9	7.9	UJT-6.35M-AW-S
9.52	7.4	23.8	11.9	6.35	11.1	11.1	11.1	UJT-9.52M-AW-S
12.7	10.3	27	13.5	6.35	14.3	14.3	14.3	UJT-12.7M-AW-S

超コンパクト自動溶接継手異径ティ

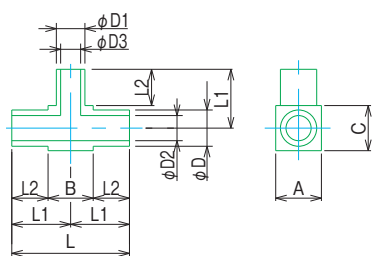

呼び径D	D1	D2	D3	L	L1	L2	A	B	C	品番
9.52	6.35	7.4	4.4	23.8	11.9	6.35	11.1	11.1	11.1	UJT-9.52M×6.35M-AW-S
12.7	6.35	10.3	4.4	27	13.5	6.35	14.3	14.3	14.3	UJT-12.7M×6.35M-AW-S
12.7	9.52	10.3	7.4	27	13.5	6.35	14.3	14.3	14.3	UJT-12.7M×9.52M-AW-S