


TEFLON FITTING

TH TEFLON, MALE CONNECTOR

テフロン用ハーフユニオン

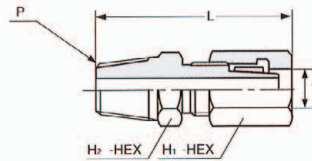


(Unit:mm)

PART. No.	T O.D.X.I.D.	P PIPE THREADS	L	H ₂	H ₁
TH- 6-1	6 × 4	1/8	41	14	14
TH- 6-2	6 × 4	1/4	42	14	14
TH- 8-1	8 × 6	1/8	41	14	14
TH- 8-2	8 × 6	1/4	42	14	14
TH-10-2	10 × 8	1/4	45	17	19
TH-10-3	10 × 8	3/8	47	17	19
TH-12-3	12 × 10	3/8	49	19	22
TH-12-4	12 × 10	1/2	51.5	22	22

TKH TEFLON, BULKHEAD MALE CONNECTOR

テフロン用隔壁ハーフユニオン

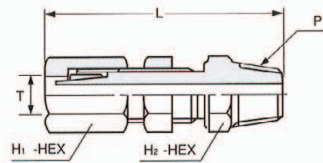


(Unit:mm)

PART. No.	T O.D.X.I.D.	P PIPE THREADS	L	H ₂	H ₁
TKH- 6-1	6 × 4	1/8	49	14	14
TKH- 6-2	6 × 4	1/4	50	14	14
TKH- 8-1	8 × 6	1/8	49	14	14
TKH- 8-1	8 × 6	1/4	50	14	14
TKH-10-2	10 × 8	1/4	57	19	19
TKH-10-3	10 × 8	3/8	59	19	19
TKH-12-3	12 × 10	3/8	61	22	22
TKH-12-4	12 × 10	1/2	63	22	22

TL TEFLON, MALE ELBOW


テフロン用エルボユニオン

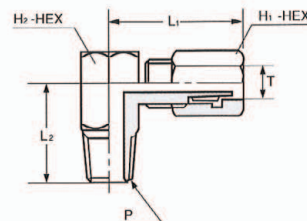

(Unit:mm)

PART. No.	T O.D.X.I.D.	P PIPE THREADS	L ₁	L ₂	H ₂	H ₁
TL- 6-1	6 × 4	1/8	32	26.5	14	14
TL- 6-2	6 × 4	1/4	32	27.5	14	14
TL- 8-1	8 × 6	1/8	32	26.5	14	14
TL- 8-2	8 × 6	1/4	32	27.5	14	14
TL-10-2	10 × 8	1/4	36	30.5	17	17
TL-10-3	10 × 8	3/8	36	30.5	17	17
TL-12-3	12 × 10	3/8	38	32.5	19	22
TL-12-4	12 × 10	1/2	38	36.5	22	22

テフロン用継手の 正しい取付方法

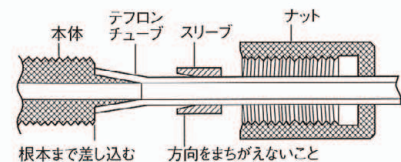

- 1.テフロンチューブ、スリーブ、ナットを図のように正しくセットしてください。
- 2.ナットが廻らなくなるまでスパナで締めつけてください。