


フレヤードユニオン

J

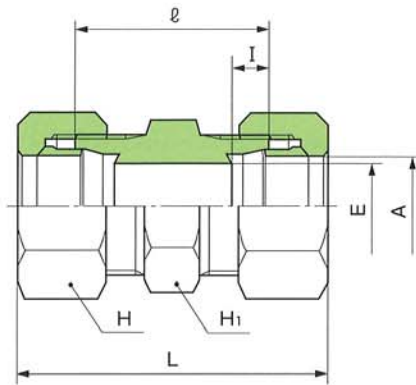


継手の呼び	適用管外径A		E	六角対辺		I	ℓ	手締め L(約)
	呼び径	外径		H ₁	H			
J-4	4	4	2.5	12	12	6	20	35
J-6	6	6	4	14	14	7	30	51
J-8	8	8	6	17	17	7	31	52
J-10	10	10	8	17	19	7	31	54
J-12	12	12	10	19	22	7	31	54
J-15	15	15	12	24	27	7.5	36	61
J-16	16	16	13	27	30	7.5	36	61
J-18	18	18	14	27	32	8	36	61
J-20	20	20	17	30	36	8	38	63
J-22	22	22	18	32	36	9	38	63
J-25	25	25	20	36	41	10	39	66
J-28	28	28	22	41	46	10	43	71
J-30	30	30	25	41	46	10	43	72
J-32	32	32	26	46	50	11	44	73
J-35	35	35	28	46	55	11	44	79
J-38	38	38	32	50	60	12	46	85
J-40	40	40	32	55	60	12	55	94
J-42	42	42	34	55	60	12	55	94
J-50	50	50	40	65	75	12	60	103
J-1/8	1/8	10.5	8	17	19	7	31	54
J-1/4	1/4	13.8	11	22	24	7.5	36	60
J-3/8	3/8	17.3	14	27	32	8	36	61
J-1/2	1/2	21.7	18	32	36	9	38	63
J-3/4	3/4	27.2	22	41	46	10	43	71
J-1	1	34.0	28	46	55	11	44	79
J-1 1/4	1 1/4	42.7	34	60	65	12	57	98
J-1 1/2	1 1/2	48.6	40	65	75	12	60	103

※Average Values

※上記諸元は品質の向上により若干変わることがあります。

隔壁フレヤードユニオン

JA

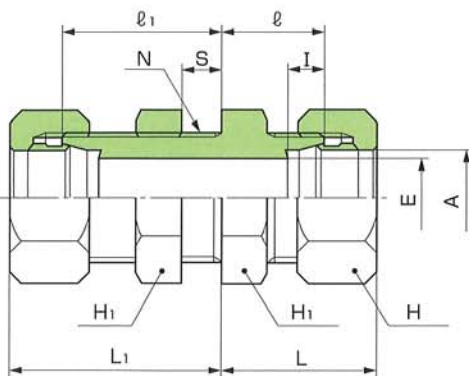

継手の呼び	適用管外径A		E	六角対辺		I	ℓ ₁	ℓ	手締め(約)		N	最大S
	呼び径	外径		H ₁	H				L ₁	L		
JA-4	4	4	2.5	14	12	6	25	14	32.5	21.5	M10×1.25	13
JA-6	6	6	4	17	14	7	32	19	42.5	29.5	M12×1.5	13
JA-8	8	8	6	19	17	7	32	19	42.5	29.5	M14×1.5	13
JA-10	10	10	8	22	19	7	32	20	43.5	31.5	M16×1.5	13
JA-12	12	12	10	24	22	7	32	20	43.5	31.5	M18×1.5	13
JA-15	15	15	12	27	27	7.5	37	22	49.5	34.5	M22×1.5	15
JA-16	16	16	13	30	30	7.5	37	24	49.5	36.5	M24×1.5	15
JA-18	18	18	14	32	32	8	39	24	51.5	36.5	M26×1.5	15
JA-20	20	20	17	32	36	8	39	24	51.5	36.5	M28×1.5	15
JA-22	22	22	18	36	36	9	39	25	51.5	37.5	M30×1.5	15
JA-25	25	25	20	41	41	10	39	25	52.5	38.5	M35×1.5	15
JA-28	28	28	22	46	46	10	41	28	55	42	M38×1.5	15
JA-30	30	30	25	46	46	10	41	28	55.5	42.5	M40×1.5	15
JA-32	32	32	26	50	50	11	43	30	57.5	44.5	M42×1.5	15
JA-35	35	35	28	50	55	11	43	30	60.5	47.5	M45×1.5	15
JA-38	38	38	32	55	60	12	45	31	64.5	50.5	M48×1.5	15
JA-40	40	40	32	60	60	12	50	37	69.5	56.5	M52×2	15
JA-50	50	50	40	70	75	12	50	43	71.5	64.5	M64×2	15
JA-1/8	1/8	10.5	8	22	19	7	32	20	43.5	31.5	M16×1.5	13
JA-1/4	1/4	13.8	11	27	24	7.5	37	22	49	34	M20×1.5	15
JA-3/8	3/8	17.3	14	32	32	8	39	24	51.5	36.5	M26×1.5	15
JA-1/2	1/2	21.7	18	36	36	9	39	25	51.5	37.5	M30×1.5	15
JA-3/4	3/4	27.2	22	46	46	10	41	28	55	42	M38×1.5	15
JA-1	1	34.0	28	50	55	11	43	30	60.5	47.5	M45×1.5	15
JA-1 1/4	1 1/4	42.7	34	65	65	12	50	40	70.5	60.5	M56×2	15
JA-1 1/2	1 1/2	48.6	40	70	75	12	50	43	71.5	64.5	M64×2	15

※Average Values

※上記諸元は品質の向上により若干変わることがあります。