


両口チーズ (オス) F

F

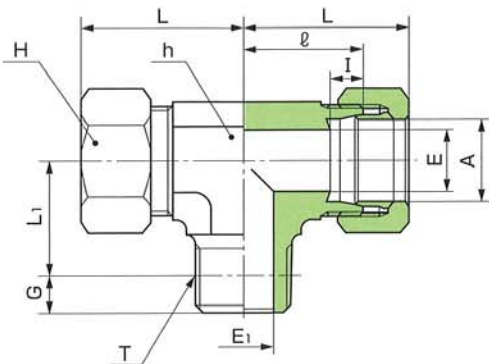


継手の呼び	適用管外径A 呼び径 外径	(PT) T	E	E ₁	基準径の 位置 G	二面幅 h	六角対辺 H	I	ℓ	手締め L (約)	(約) L ₁	
F - 4x1/8	4	1/8	2.5	4	3.97	12	12	6	15	22.5	13	
F - 6x1/8	6	1/8	4	4	3.97	14	14	7	20	30.5	14	
F - 6x1/4	6	1/4	4	7	6.01	17	14	7	23	33.5	17	
F - 8x1/8	8	1/8	6	4	3.97	17	17	7	23	33.5	16	
F - 8x1/4	8	1/4	6	7	6.01	17	17	7	23	33.5	18	
F - 10x1/4	10	1/4	8	7	6.01	17	19	7	23	34.5	19	
F - 10x3/8	10	3/8	8	9	6.35	19	19	7	24	35.5	19.5	
F - 12x1/4	12	1/4	10	7	6.01	19	22	7	24	35.5	18	
F - 12x3/8	12	3/8	10	9	6.35	19	22	7	24	35.5	20.5	
F - 15x3/8	15	3/8	12	9	6.35	24	27	7.5	29	41.5	23.5	
F - 15x1/2	15	1/2	12	12	8.16	24	27	7.5	29	41.5	26	
F - 16x1/2	16	1/2	13	12	8.16	27	30	7.5	32	44.5	27	
F - 18x1/2	18	1/2	14	12	8.16	27	32	8	32	44.5	30	
F - 20x3/4	20	3/4	17	16	9.53	30	36	8	33	45.5	30.5	
F - 22x3/4	22	3/4	18	16	9.53	32	36	9	34	46.5	32.5	
F - 25x3/4	25	3/4	20	16	9.53	36	41	10	36	49.5	33.5	
F - 25x1	25	1	20	22	10.39	36	41	10	36	49.5	35.5	
F - 28x1	28	1	22	22	10.39	41	46	10	41	55	39.5	
F - 30x1	30	1	25	22	10.39	41	46	10	41	55.5	39.5	
F - 30x1 1/4	30	1 1/4	25	31	12.70	46	46	10	46	60.5	42.5	
F - 32x1 1/4	32	1 1/4	26	31	12.70	46	50	11	46	60.5	43.5	
F - 35x1 1/4	35	1 1/4	28	31	12.70	46	55	11	46	63.5	45.5	
F - 38x1 1/2	38	1 1/2	32	36	12.70	50	60	12	50	69.5	48.5	
F - 40x1 1/2	40	1 1/2	32	36	12.70	55	60	12	55	74.5	49.5	
F - 50x2	50	2	40	46	15.88	65	75	12	62	83.5	58	
F - 1/8x1/4	1/8	10.5	1/4	8	7	6.01	17	19	7	23	34.5	19
F - 1/4x3/8	1/4	13.8	3/8	11	9	6.35	22	24	7.5	28	40	22.5
F - 3/8x1/2	3/8	17.3	1/2	14	12	8.16	27	32	8	32	44.5	30
F - 1/2x3/4	1/2	21.7	3/4	18	16	9.53	32	36	9	34	46.5	32.5
F - 3/4x1	3/4	27.2	1	22	22	10.39	41	46	10	41	55	39.5
F - 1x1 1/4	1	34.0	1 1/4	28	31	12.70	46	55	11	46	63.5	45.5
F - 1 1/4x1 1/2	1 1/4	42.7	1 1/2	34	36	12.70	60	65	12	57	77.5	51.5
F - 1 1/2x2	1 1/2	48.6	2	40	46	15.88	65	75	12	62	83.5	58

※Average Values

※上記諸元は品質の向上により若干変わることがあります。

サービスチーズ (メス) FB

FB

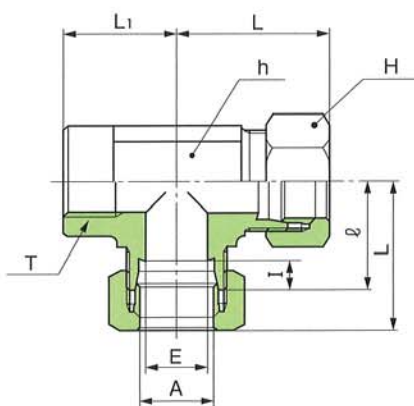

継手の呼び	適用管外径A 呼び径 外径	(PT) T	E	二面幅 h	六角対辺 H	I	ℓ	手締め L (約)	L ₁	
FB - 8x1/4	8	1/4	6	19	17	7	24	34.5	24	
FB - 10x1/4	10	1/4	8	19	19	7	24	35.5	24	
FB - 12x1/4	12	1/4	10	19	22	7	24	35.5	24	
FB - 12x3/8	12	3/8	10	24	22	7	29	40.5	29	
FB - 15x3/8	15	3/8	12	24	27	7.5	29	41.5	29	
FB - 15x1/2	15	1/2	12	30	27	7.5	33	45.5	33	
FB - 16x1/2	16	1/2	13	30	30	7.5	33	45.5	33	
FB - 18x1/2	18	1/2	14	30	32	8	33	45.5	33	
FB - 20x3/4	20	3/4	17	36	36	8	36	48.5	36	
FB - 22x3/4	22	3/4	18	36	36	9	36	48.5	36	
FB - 25x3/4	25	3/4	20	36	41	10	36	49.5	36	
FB - 25x1	25	1	20	46	41	10	46	59.5	46	
FB - 28x1	28	1	22	46	46	10	46	60	46	
FB - 30x1	30	1	25	46	46	10	46	60.5	46	
FB - 30x1 1/4	30	1 1/4	25	55	46	10	55	69.5	55	
FB - 32x1 1/4	32	1 1/4	26	55	50	11	55	69.5	55	
FB - 35x1 1/4	35	1 1/4	28	55	55	11	55	72.5	55	
FB - 1/8x1/4	1/8	10.5	1/4	8	19	19	7	24	35.5	24
FB - 1/4x3/8	1/4	13.8	3/8	11	24	24	7.5	29	41	29
FB - 3/8x1/2	3/8	17.3	1/2	14	30	32	8	33	45.5	33
FB - 1/2x3/4	1/2	21.7	3/4	18	36	36	9	36	48.5	36
FB - 3/4x1	3/4	27.2	1	22	46	46	10	46	60	46
FB - 1x1 1/4	1	34.0	1 1/4	28	55	55	11	55	72.5	55

※Average Values

※上記諸元は品質の向上により若干変わることがあります。