


No.112 フルカップリング

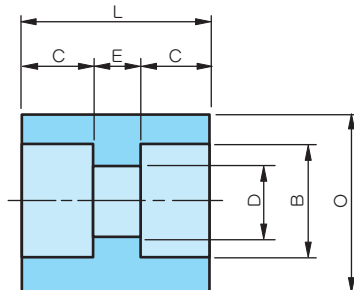

Sch-80

単位: mm


呼び方	B	D	E	C	L	O
SWFC-8A-S80	14.3	9.4	6.4	10	26.4	22
SWFC-10A-S80	17.8	12.7	6.4	10	26.4	26
SWFC-15A-S80	22.2	16.1	9.5	10	29.5	32
SWFC-20A-S80	27.7	21.4	9.5	13	35.5	38
SWFC-25A-S80	34.5	27.2	12.7	13	38.7	46
SWFC-32A-S80	43.2	35.5	12.7	13	38.7	55
SWFC-40A-S80	49.1	41.2	12.7	13	38.7	63
SWFC-50A-S80	61.1	52.7	19.1	16	51.1	78
SWFC-65A-S80	77.1	65.9	19.1	16	51.1	95
SWFC-80A-S80	90.0	78.1	19.1	16	51.1	110

Sch-160

単位: mm

呼び方	B	D	E	C	L	O
SWFC-15A-S160	22.2	12.3	9.5	10	29.5	38
SWFC-20A-S160	27.7	16.2	9.5	13	35.5	42
SWFC-25A-S160	34.5	21.2	12.7	13	38.7	50
SWFC-32A-S160	43.2	29.9	12.7	13	38.7	60
SWFC-40A-S160	49.1	34.4	12.7	13	38.7	70
SWFC-50A-S160	61.1	43.1	19.1	16	51.1	85
SWFC-65A-S160	77.1	57.3	19.1	16	51.1	100
SWFC-80A-S160	90.0	66.9	19.1	16	51.1	120

No.117 ハーフカップリング

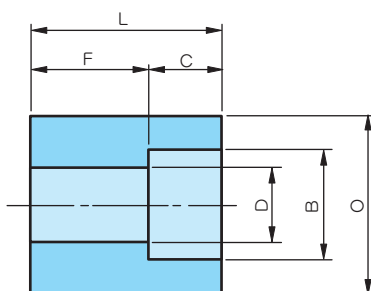

Sch-80

単位: mm

呼び方	B	D	F	C	L	O
SWHC-8A-S80	14.3	9.4	15.9	10	25.9	22
SWHC-10A-S80	17.8	12.7	17.5	10	27.5	26
SWHC-15A-S80	22.2	16.1	22.2	10	32.2	32
SWHC-20A-S80	27.7	21.4	23.8	13	36.8	38
SWHC-25A-S80	34.5	27.2	28.6	13	41.6	46
SWHC-32A-S80	43.2	35.5	30.2	13	43.2	55
SWHC-40A-S80	49.1	41.2	31.8	13	44.8	63
SWHC-50A-S80	61.1	52.7	41.3	16	57.3	78
SWHC-65A-S80	77.1	65.9	42.9	16	58.9	95
SWHC-80A-S80	90.0	78.1	44.5	16	60.5	110

Sch-160

単位: mm

呼び方	B	D	F	C	L	O
SWHC-15A-S160	22.2	12.3	22.2	10	32.2	38
SWHC-20A-S160	27.7	16.2	23.8	13	36.8	42
SWHC-25A-S160	34.5	21.2	28.6	13	41.6	50
SWHC-32A-S160	43.2	29.9	30.2	13	43.2	60
SWHC-40A-S160	49.1	34.4	31.8	13	44.8	70
SWHC-50A-S160	61.1	43.1	41.3	16	57.3	85
SWHC-65A-S160	77.1	57.3	42.9	16	58.9	100
SWHC-80A-S160	90.0	66.9	44.5	16	60.5	120