


ステンレス製差し込み溶接式管継手

JIS B 2316-SCH80


単位：mm

No.102SS 90°エルボ

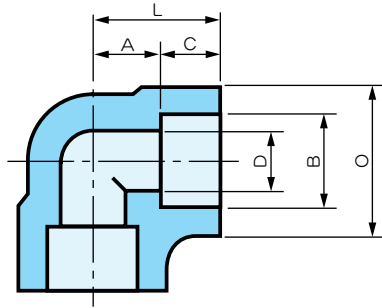

呼び方	B	D	A	C	L	O
SW90E-8A-S80	14.3	9.4	11.1	10	21.1	23
SW90E-10A-S80	17.8	12.7	13.5	12	25.5	27
SW90E-15A-S80	22.2	16.1	15.9	13	28.9	34
SW90E-20A-S80	27.7	21.4	19.1	14	33.1	39
SW90E-25A-S80	34.5	27.2	22.2	16	38.2	47
SW90E-32A-S80	43.2	35.5	27.0	18	45.0	56
SW90E-40A-S80	49.1	41.2	31.8	19	50.8	63
SW90E-50A-S80	61.1	52.7	38.1	22	60.1	76


No.104SS 45°エルボ

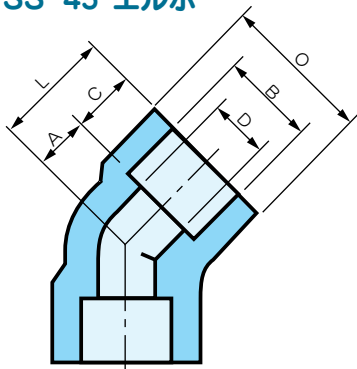

単位：mm

呼び方	B	D	A	C	L	O
SW45E-8A-S80	14.3	9.4	7.9	10	17.9	23
SW45E-10A-S80	17.8	12.7	7.9	12	19.9	27
SW45E-15A-S80	22.2	16.1	11.1	13	24.1	34
SW45E-20A-S80	27.7	21.4	12.7	14	26.7	39
SW45E-25A-S80	34.5	27.2	14.3	16	30.3	47
SW45E-32A-S80	43.2	35.5	17.5	18	35.5	56
SW45E-40A-S80	49.1	41.2	20.6	19	39.6	63
SW45E-50A-S80	61.1	52.7	25.4	22	47.4	76


No.107SS ティー

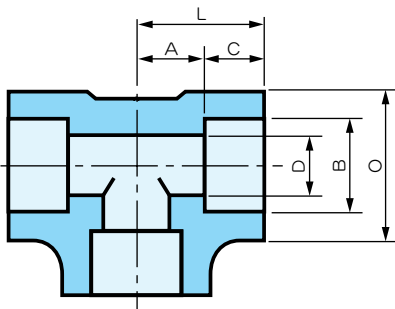

単位：mm

呼び方	B	D	A	C	L	O
SWT-8A-S80	14.3	9.4	11.1	10	21.1	23
SWT-10A-S80	17.8	12.7	13.5	12	25.5	27
SWT-15A-S80	22.2	16.1	15.9	13	28.9	34
SWT-20A-S80	27.7	21.4	19.1	14	33.1	39
SWT-25A-S80	34.5	27.2	22.2	16	38.2	47
SWT-32A-S80	43.2	35.5	27.0	18	45.0	56
SWT-40A-S80	49.1	41.2	31.8	19	50.8	63
SWT-50A-S80	61.1	52.7	38.1	22	60.1	76

No.129SS クロス

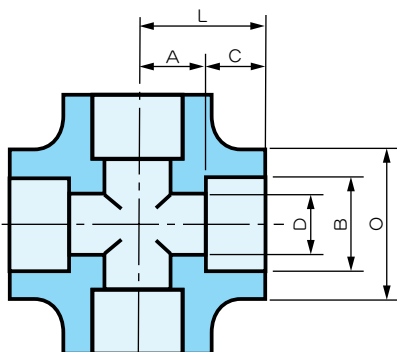

単位：mm

呼び方	B	D	A	C	L	O
SW Cr-8A-S80	14.3	9.4	11.1	10	21.1	23
SW Cr-10A-S80	17.8	12.7	13.5	12	25.5	27
SW Cr-15A-S80	22.2	16.1	15.9	13	28.9	34
SW Cr-20A-S80	27.7	21.4	19.1	14	33.1	39
SW Cr-25A-S80	34.5	27.2	22.2	16	38.2	47
SW Cr-32A-S80	43.2	35.5	27.0	18	45.0	56
SW Cr-40A-S80	49.1	41.2	31.8	19	50.8	63
SW Cr-50A-S80	61.1	52.7	38.1	22	60.1	76