



# 変形フランジ形ユニット

## UCFB 200

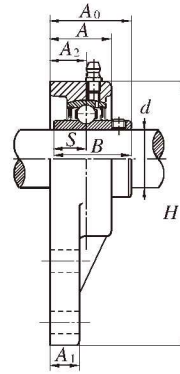

SR タイプシール

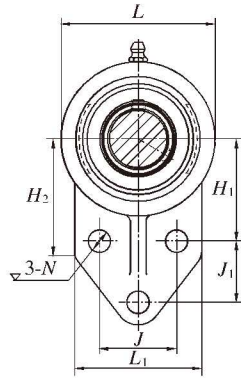

TRL タイプシール

軸径 (mm) d (inch)	寸法 (mm)															取付けボルト の呼び (mm) (inch)		ユニット 呼び番号	適用 軸受箱	軸受 呼び番号	質量 (kg)
	H	L	J	H <sub>2</sub>	L <sub>1</sub>	A	N	A <sub>1</sub>	H <sub>1</sub>	J <sub>1</sub>	A <sub>2</sub>	A <sub>0</sub>	B	S	(mm)	(inch)					
12 1/2	110	62	32	52	52	25.5	10	13	42	27	15	33.3	31.0	12.7	M8	5/16	UCFB201 UCFB201-8	FB201	UC201 UC201-8	0.64	
15 5/8	110	62	32	52	52	25.5	10	13	42	27	15	33.3	31.0	12.7	M8	5/16	UCFB202 UCFB202-10	FB202	UC202 UC202-10	0.64	
17 11/16	110	62	32	52	52	25.5	10	13	42	27	15	33.3	31.0	12.7	M8	5/16	UCFB203 UCFB203-11	FB203	UC203 UC203-11	0.64	
20 3/4	110	62	32	52	52	25.5	10	13	42	27	15	33.3	31.0	12.7	M8	5/16	UCFB204-12 UCFB204	FB204	UC204-12 UC204	0.64	
25 7/8 15/16 1	116	68	34	52	56	27.0	10	13	45	27	16	35.7	34.0	14.3	M8	5/16	UCFB205-14 UCFB205-15 UCFB205 UCFB205-16	FB205	UC205-14 UC205-15 UC205 UC205-16	0.68	
30 1 1/8 1 3/16 2	132	80	40	55	65	31.0	10	13	50	29	18	40.2	38.1	15.9	M8	5/16	UCFB206-18 UCFB206 UCFB206-19 UCFB206-20	FB206	UC206-18 UC206 UC206-19 UC206-20	0.92	
35 1 1/4 1 5/16 1 3/8 1 7/16	144	90	46	62	70	34.0	10	15	55	32	19	44.4	42.9	17.5	M8	5/16	UCFB207-20 UCFB207-21 UCFB207-22 UCFB207 UCFB207-23	FB207	UC207-20 UC207-21 UC207-22 UC207 UC207-23	1.30	
40 1 1/2 1 9/16	164	100	50	72	78	36.0	12	16	60	41	21	51.2	49.2	19.0	M10	3/8	UCFB208-24 UCFB208-25 UCFB208	FB208	UC208-24 UC208-25 UC208	1.80	
45 1 5/8 1 11/16 1 3/4	175	106	54	76	80	38.0	12	18	65	43	22	52.2	49.2	19.0	M10	3/8	UCFB209-26 UCFB209-27 UCFB209-28 UCFB209	FB209	UC209-26 UC209-27 UC209-28 UC209	2.00	
50 1 7/8 1 15/16 2	184	114	58	82	86	40.0	12	18	68	46	22	54.6	51.6	19.0	M10	3/8	UCFB210-30 UCFB210-31 UCFB210 UCFB210-32	FB210	UC210-30 UC210-31 UC210 UC210-32	2.30	