



## リング式銅管継手(計装用)

### ミニチュアバルブFF型

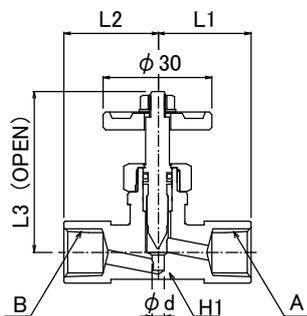


型 式	管用ねじ A (Rc)	管用ねじ B (Rc)	本体長さ			最少穴径 d (mm)	対辺 H1 (mm)
			L1 (mm)	L2 (mm)	L3 (mm)		
GVFF-9001R-BS	1/8	1/8	26	26	44	3.5	17
GVFF-9002R-BS	1/4	1/4	26	26	44	3.5	17
GVFF-9003R-BS	3/8	3/8	30	30	45	3.5	19

### ミニチュアバルブMM型

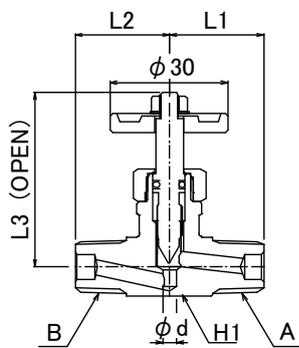


型 式	管用ねじ A (R)	管用ねじ B (R)	本体長さ			最少穴径 d (mm)	対辺 H1 (mm)
			L1 (mm)	L2 (mm)	L3 (mm)		
GVMM-9001R-BS	1/8	1/8	22	22	44	3.5	17
GVMM-9002R-BS	1/4	1/4	24	24	44	3.5	17
GVMM-9003R-BS	3/8	3/8	27	27	44	3.5	17

### ミニチュアバルブMF型

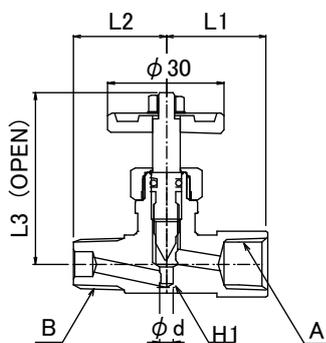


型 式	管用ねじ A (Rc)	管用ねじ B (R)	本体長さ			最少穴径 d (mm)	対辺 H1 (mm)
			L1 (mm)	L2 (mm)	L3 (mm)		
GVMF-9001R-BS	1/8	1/8	22	26	44	3.5	17
GVMF-9002R-BS	1/4	1/4	24	26	44	3.5	17
GVMF-9003R-BS	3/8	3/8	28	30	45	3.5	19

### 袋ナット

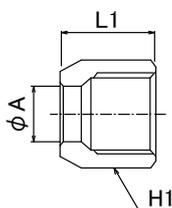

型 式	銅管外径	本体長さ	
	A (mm)	L1 (mm)	H1 (mm)
GN-6-BS	6	14	14
GN-8-BS	8	14	14
GN-10-BS	10	17	17
GN-12-BS	12	19	19
GN-02-BS	6.35	14	14
GN-03-BS	9.53	17	17
GN-04-BS	12.7	20	21

### ソロバン玉

 

型 式	銅管外径	
	A (mm)	L1 (mm)
GS-6-BS	6	7
GS-8-BS	8	7
GS-10-BS	10	7
GS-12-BS	12	7
GS-02-BS	6.35	7
GS-03-BS	9.53	7
GS-04-BS	12.7	8