
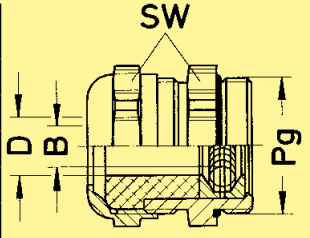

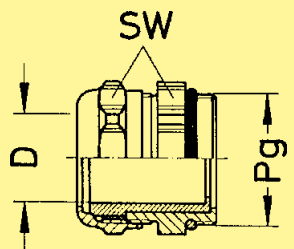

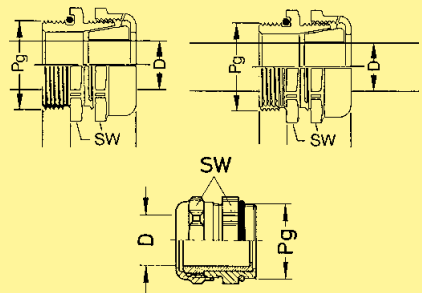


ケーブルエントリープロテクション (Pg ネジ)

名称	部品番号	Pg	図	寸法 mm																																																															
EMC クランプ Pg ネジ付 (IP 68) 	09 62 000 5023	11		<table border="1"> <thead> <tr> <th>SW</th> <th>ケーブル Ø D</th> <th>シール ド-Ø B</th> </tr> </thead> <tbody> <tr><td>20</td><td>4 ... 6.5</td><td>2.5 ... 6.5</td></tr> <tr><td>20</td><td>6.5 ... 9.5</td><td>3.5 ... 8.5</td></tr> <tr><td>22</td><td>8 ... 10.5</td><td>6.5 ... 10.5</td></tr> <tr><td>22</td><td>6.5 ... 9.5</td><td>2.5 ... 6.5</td></tr> <tr><td>22</td><td>9 ... 13</td><td>6.5 ... 10.5</td></tr> <tr><td>24</td><td>6.5 ... 9.5</td><td>3.5 ... 8</td></tr> <tr><td>24</td><td>9 ... 13</td><td>4.5 ... 8</td></tr> <tr><td>30</td><td>11.5 ... 15.5</td><td>9.5 ... 13.5</td></tr> <tr><td>30</td><td>14 ... 18</td><td>10.5 ... 14.5</td></tr> <tr><td>40</td><td>17 ... 20.5</td><td>15 ... 20</td></tr> <tr><td>40</td><td>20 ... 25</td><td>15 ... 20</td></tr> <tr><td>50</td><td>24 ... 28</td><td>18 ... 25.5</td></tr> <tr><td>50</td><td>27 ... 32</td><td>24 ... 31</td></tr> </tbody> </table>	SW	ケーブル Ø D	シール ド-Ø B	20	4 ... 6.5	2.5 ... 6.5	20	6.5 ... 9.5	3.5 ... 8.5	22	8 ... 10.5	6.5 ... 10.5	22	6.5 ... 9.5	2.5 ... 6.5	22	9 ... 13	6.5 ... 10.5	24	6.5 ... 9.5	3.5 ... 8	24	9 ... 13	4.5 ... 8	30	11.5 ... 15.5	9.5 ... 13.5	30	14 ... 18	10.5 ... 14.5	40	17 ... 20.5	15 ... 20	40	20 ... 25	15 ... 20	50	24 ... 28	18 ... 25.5	50	27 ... 32	24 ... 31																					
	SW	ケーブル Ø D			シール ド-Ø B																																																														
	20	4 ... 6.5			2.5 ... 6.5																																																														
	20	6.5 ... 9.5			3.5 ... 8.5																																																														
	22	8 ... 10.5			6.5 ... 10.5																																																														
	22	6.5 ... 9.5			2.5 ... 6.5																																																														
	22	9 ... 13			6.5 ... 10.5																																																														
	24	6.5 ... 9.5			3.5 ... 8																																																														
	24	9 ... 13			4.5 ... 8																																																														
	30	11.5 ... 15.5			9.5 ... 13.5																																																														
	30	14 ... 18			10.5 ... 14.5																																																														
	40	17 ... 20.5			15 ... 20																																																														
	40	20 ... 25			15 ... 20																																																														
	50	24 ... 28			18 ... 25.5																																																														
	50	27 ... 32			24 ... 31																																																														
09 62 000 5024	11																																																																		
09 62 000 5025	11																																																																		
09 62 000 5003	13.5																																																																		
09 62 000 5004	13.5																																																																		
09 62 000 5005	16																																																																		
09 62 000 5006	16																																																																		
09 62 000 5007	21																																																																		
09 62 000 5008	21																																																																		
09 62 000 5009	29																																																																		
09 62 000 5010	29																																																																		
09 62 000 5011	36																																																																		
09 62 000 5012	36																																																																		
ユニバーサルケーブルグランド Pg (IP 68) 金属製 	09 00 000 5080	11		<table border="1"> <thead> <tr> <th>色</th> <th>SW</th> <th>ケーブル Ø D</th> </tr> </thead> <tbody> <tr><td>グレー</td><td>20</td><td>5 ... 8</td></tr> <tr><td>黒色</td><td>20</td><td>6.5 ... 9.5</td></tr> <tr><td>緑</td><td>20</td><td>7 ... 10.5</td></tr> <tr><td>黒色</td><td>22</td><td>6.5 ... 9.5</td></tr> <tr><td>緑</td><td>22</td><td>7 ... 10.5</td></tr> <tr><td>赤</td><td>22</td><td>9 ... 13</td></tr> <tr><td>黒色</td><td>24</td><td>6.5 ... 9.5</td></tr> <tr><td>緑</td><td>24</td><td>7 ... 10.5</td></tr> <tr><td>赤</td><td>24</td><td>9 ... 13</td></tr> <tr><td>白</td><td>24</td><td>11.5 ... 15.5</td></tr> <tr><td>緑</td><td>30</td><td>7 ... 10.5</td></tr> <tr><td>赤</td><td>30</td><td>9 ... 13</td></tr> <tr><td>白</td><td>30</td><td>11.5 ... 15.5</td></tr> <tr><td>青</td><td>30</td><td>14 ... 18</td></tr> <tr><td>青</td><td>40</td><td>14 ... 18</td></tr> <tr><td>ブラウン</td><td>40</td><td>17 ... 21</td></tr> <tr><td>オレンジ</td><td>40</td><td>20 ... 25</td></tr> <tr><td>ライト・イエロー</td><td>40</td><td>24 ... 28</td></tr> <tr><td>ライト・ブルー</td><td>50</td><td>29 ... 34</td></tr> <tr><td>ピンク</td><td>50</td><td>32 ... 36</td></tr> </tbody> </table>	色	SW	ケーブル Ø D	グレー	20	5 ... 8	黒色	20	6.5 ... 9.5	緑	20	7 ... 10.5	黒色	22	6.5 ... 9.5	緑	22	7 ... 10.5	赤	22	9 ... 13	黒色	24	6.5 ... 9.5	緑	24	7 ... 10.5	赤	24	9 ... 13	白	24	11.5 ... 15.5	緑	30	7 ... 10.5	赤	30	9 ... 13	白	30	11.5 ... 15.5	青	30	14 ... 18	青	40	14 ... 18	ブラウン	40	17 ... 21	オレンジ	40	20 ... 25	ライト・イエロー	40	24 ... 28	ライト・ブルー	50	29 ... 34	ピンク	50	32 ... 36
	色	SW			ケーブル Ø D																																																														
	グレー	20			5 ... 8																																																														
	黒色	20			6.5 ... 9.5																																																														
	緑	20			7 ... 10.5																																																														
	黒色	22			6.5 ... 9.5																																																														
	緑	22			7 ... 10.5																																																														
	赤	22			9 ... 13																																																														
	黒色	24			6.5 ... 9.5																																																														
	緑	24			7 ... 10.5																																																														
	赤	24			9 ... 13																																																														
	白	24			11.5 ... 15.5																																																														
	緑	30			7 ... 10.5																																																														
	赤	30			9 ... 13																																																														
	白	30			11.5 ... 15.5																																																														
	青	30			14 ... 18																																																														
	青	40			14 ... 18																																																														
	ブラウン	40			17 ... 21																																																														
	オレンジ	40			20 ... 25																																																														
	ライト・イエロー	40			24 ... 28																																																														
	ライト・ブルー	50			29 ... 34																																																														
ピンク	50	32 ... 36																																																																	
09 00 000 5081	11																																																																		
09 00 000 5082	11																																																																		
09 00 000 5083	13.5																																																																		
09 00 000 5084	13.5																																																																		
09 00 000 5085	13.5																																																																		
09 00 000 5086	16																																																																		
09 00 000 5087	16																																																																		
09 00 000 5088	16																																																																		
09 00 000 5089	16																																																																		
09 00 000 5090	21																																																																		
09 00 000 5091	21																																																																		
09 00 000 5092	21																																																																		
09 00 000 5093	21																																																																		
09 00 000 5094	29																																																																		
09 00 000 5095	29																																																																		
09 00 000 5096	29																																																																		
09 00 000 5097	29																																																																		
09 00 000 5098	36																																																																		
09 00 000 5099	36																																																																		
ケーブルエントリープロテクション (Pg ネジ) (IP 68) アクセサリー 	09 00 000 5183	11		<table border="1"> <thead> <tr> <th>SW</th> <th>ケーブル Ø D</th> </tr> </thead> <tbody> <tr><td>21</td><td>7 ... 12</td></tr> <tr><td>24</td><td>7 ... 12</td></tr> <tr><td>33</td><td>13 ... 18</td></tr> </tbody> </table>	SW	ケーブル Ø D	21	7 ... 12	24	7 ... 12	33	13 ... 18																																																							
	SW	ケーブル Ø D																																																																	
	21	7 ... 12																																																																	
24	7 ... 12																																																																		
33	13 ... 18																																																																		
09 00 000 5182	11																																																																		
09 00 000 5153	21																																																																		

太字はドイツでの標準在庫品