

3 - ⑦ ナイロンクリップ

標準グレード

屋内使用

RoHS適合





HFハロゲンフリー

色 乳白

材質 66ナイロン

UL難燃グレード(主原料) UL94V-2

常時使用温度範囲 -40°C~+85°C

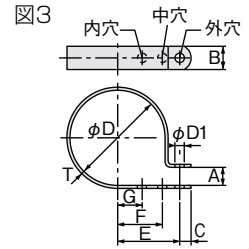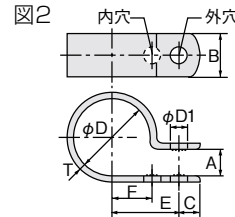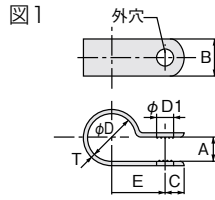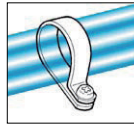

型番	Article-No.	図番	固定時の内径 (φmm)		寸法(mm)										使用ビス	包装単位 *販売単位 (個)	ケース 入れ目 (個)
					φD	φD1	A	B	C	E	F	G	T				
AB-2N	211-00191	1	3.0		3.3	4.3	3.2	9.5	4.8	9.5			1.1	M4	100	20,000	
AB-3N	211-00195	1	4.5		5.3	4.3	4.8	9.5	4.8	10.3			1.1	M4	100	20,000	
AB-4N	211-00198	1	6.0		6.8	4.3	4.8	9.5	4.8	11.1			1.1	M4	100	20,000	
AB-5N	211-00205	1	7.5		8.4	4.3	4.8	9.5	4.8	11.9			1.1	M4	100	10,000	
AB-6N	211-00207	1	9.5		10.6	4.3	6.3	9.5	4.8	12.7			1.1	M4	100	10,000	
AB-7N	211-00209	1	10.5		12.2	4.3	6.3	9.5	4.8	13.5			1.1	M4	100	10,000	
AB-8N	211-00211	1	11.5		13.2	4.3	6.3	9.5	4.8	14.3			1.1	M4	100	10,000	
AB-9N	211-00213	1	13.5		15.2	4.3	6.3	9.5	4.8	15.1			1.1	M4	100	10,000	
AB-10N	211-00175	1	14.5		16.0	4.3	6.3	9.5	4.8	15.9			1.1	M4	100	10,000	
AB-11N	211-00177	1	16.5		19.0	5.1	7.9	12.7	6.3	17.5			1.8	M5	100	4,000	
AB-12N	211-00179	1	17.5		19.8	5.1	7.9	12.7	6.3	18.2			1.8	M5	100	4,000	
AB-13N	211-00181	1	20.0		22.1	5.1	7.9	12.7	6.3	19.0			1.8	M5	100	4,000	
AB-14N	211-00183	2	21.0	19.0	22.9	5.1	7.9	12.7	6.3	19.8	11.9		1.8	M5	100	3,000	
AB-16N	211-00185	2	24.5	22.5	26.9	5.1	7.9	12.7	6.3	21.4	13.5		1.8	M5	100	3,000	
AB-18N	211-00187	2	27.0	24.5	29.2	5.1	7.9	12.7	6.3	23.0	15.1		1.8	M5	50	2,500	
AB-24N	211-00189	3	37.0	35.5	39.4	5.1	9.5	12.7	6.3	27.8	19.8	11.9	1.8	M5	50	1,000	
AB-32N	211-00193	3	49.0	47.0	43.5	52.1	5.1	9.5	12.7	6.3	34.1	24.6	13.5	1.8	M5	25	1,000

F 配線固定
アクセサリ

マウントベース

接着タイプ

ビス止めタイプ

スナップ止め
タイプ

ダクト用
その他
アクセサリ

ヘラフック

耐候グレード

屋外使用

RoHS適合

HFハロゲンフリー

色 黒

材質 66ナイロン

UL難燃グレード(主原料) UL94V-2

常時使用温度範囲 -40°C~+85°C

型番	Article-No.	図番	固定時の内径 (φ mm)		寸法(mm)										使用ビス	包装単位 *販売単位 (個)	ケース 入れ目 (個)
					φD	φD1	A	B	C	E	F	G	T				
AB-2N-W	211-00192	1	3.0		3.3	4.3	3.2	9.5	4.8	9.5			1.1	M4	100	20,000	
AB-3N-W	211-00197	1	4.5		5.3	4.3	4.8	9.5	4.8	10.3			1.1	M4	100	20,000	
AB-4N-W	211-00204	1	6.0		6.8	4.3	4.8	9.5	4.8	11.1			1.1	M4	100	20,000	
AB-5N-W	211-00206	1	7.5		8.4	4.3	4.8	9.5	4.8	11.9			1.1	M4	100	10,000	
AB-6N-W	211-00208	1	9.5		10.6	4.3	6.3	9.5	4.8	12.7			1.1	M4	100	10,000	
AB-7N-W	211-00210	1	10.5		12.2	4.3	6.3	9.5	4.8	13.5			1.1	M4	100	10,000	
AB-8N-W	211-00212	1	11.5		13.2	4.3	6.3	9.5	4.8	14.3			1.1	M4	100	10,000	
AB-9N-W	211-00214	1	13.5		15.2	4.3	6.3	9.5	4.8	15.1			1.1	M4	100	10,000	
AB-10N-W	211-00176	1	14.5		16.0	4.3	6.3	9.5	4.8	15.9			1.1	M4	100	10,000	
AB-11N-W	211-00178	1	16.5		19.0	5.1	7.9	12.7	6.3	17.5			1.8	M5	100	4,000	
AB-12N-W	211-00180	1	17.5		19.8	5.1	7.9	12.7	6.3	18.2			1.8	M5	100	4,000	
AB-13N-W	211-00182	1	20.0		22.1	5.1	7.9	12.7	6.3	19.0			1.8	M5	100	4,000	
AB-14N-W	211-00184	2	21.0	19.0	22.9	5.1	7.9	12.7	6.3	19.8	11.9		1.8	M5	100	3,000	
AB-16N-W	211-00186	2	24.5	22.5	26.9	5.1	7.9	12.7	6.3	21.4	13.5		1.8	M5	100	3,000	
AB-18N-W	211-00188	2	27.0	24.5	29.2	5.1	7.9	12.7	6.3	23.0	15.1		1.8	M5	50	2,500	
AB-24N-W	211-00190	3	37.0	35.5	39.4	5.1	9.5	12.7	6.3	27.8	19.8	11.9	1.8	M5	50	1,000	
AB-32N-W	211-00194	3	49.0	47.0	43.5	52.1	5.1	9.5	12.7	6.3	34.1	24.6	13.5	1.8	M5	25	1,000