
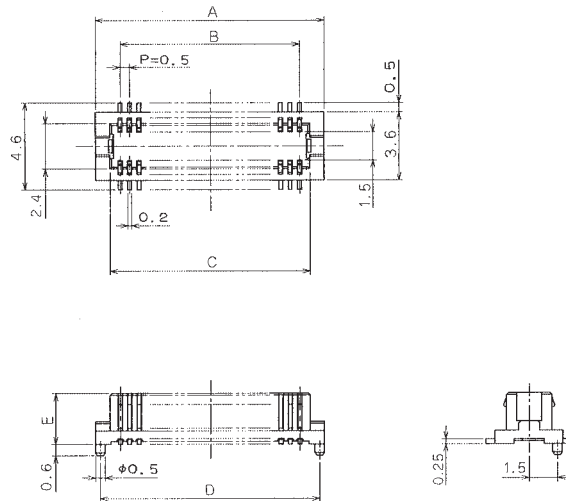


■レセプタクル 補強金具無

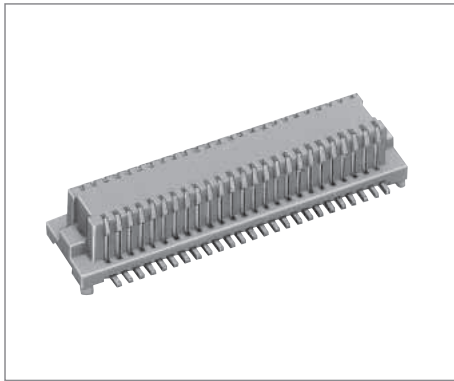

●スタッキング高さ：3mm品

単位：mm

製品番号	HRS No.	極数	A	B	C	D	E	備考	RoHS
DF12A (3.0) -10DS-0.5V (81)	CL537-0626-9-81	10	4.6	2.0	3.1	4.1	2.2	補強金具：無 ガイドポスト：有	○
DF12A (3.0) -14DS-0.5V (81)	CL537-0915-6-81	14	5.6	3.0	4.1	5.1			
DF12A (3.0) -20DS-0.5V (81)	CL537-0628-4-81	20	7.1	4.5	5.6	6.6			
DF12A (3.0) -30DS-0.5V (81)	CL537-0630-6-81	30	9.6	7.0	8.1	9.1			
DF12A (3.0) -32DS-0.5V (81)	CL537-0637-5-81	32	10.1	7.5	8.6	9.6			
DF12A (3.0) -36DS-0.5V (81)	CL537-0631-9-81	36	11.1	8.5	9.6	10.6			
DF12A (3.0) -40DS-0.5V (81)	CL537-0632-1-81	40	12.1	9.5	10.6	11.6			
DF12A (3.0) -50DS-0.5V (81)	CL537-0634-7-81	50	14.6	12.0	13.1	14.1			
DF12A (3.0) -60DS-0.5V (81)	CL537-0636-2-81	60	17.1	14.5	15.6	16.6			
DF12A (3.0) -80DS-0.5V (81)	CL537-0638-8-81	80	22.1	19.5	20.6	21.6			
DF12C (3.0) -10DS-0.5V (81)	CL537-0686-0-81	10	4.6	2.0	3.1	—	2.2	補強金具：無 ガイドポスト：無	○
DF12C (3.0) -14DS-0.5V (81)	CL537-0917-1-81	14	5.6	3.0	4.1	—			
DF12C (3.0) -20DS-0.5V (81)	CL537-0686-6-81	20	7.1	4.5	5.6	—			
DF12C (3.0) -30DS-0.5V (81)	CL537-0690-8-81	30	9.6	7.0	8.1	—			
DF12C (3.0) -32DS-0.5V (81)	CL537-0697-7-81	32	10.1	7.5	8.6	—			
DF12C (3.0) -36DS-0.5V (81)	CL537-0691-0-81	36	11.1	8.5	9.6	—			
DF12C (3.0) -40DS-0.5V (81)	CL537-0692-3-81	40	12.1	9.5	10.6	—			
DF12C (3.0) -50DS-0.5V (81)	CL537-0694-9-81	50	14.6	12.0	13.1	—			
DF12C (3.0) -60DS-0.5V (81)	CL537-0696-4-81	60	17.1	14.5	15.6	—			
DF12C (3.0) -80DS-0.5V (81)	CL537-0212-6-81	80	22.1	19.5	20.6	—			

●スタッキング高さ：3.5~5mm品

単位：mm

製品番号	HRS No.	極数	A	B	C	D	E	備考	RoHS
DF12A-20DS-0.5V (81)	CL537-0078-5-81	20	7.1	4.5	5.6	6.6	2.7	補強金具：無 ガイドポスト：有	○
DF12A-30DS-0.5V (81)	CL537-0080-7-81	30	9.6	7.0	8.1	9.1			
DF12A-32DS-0.5V (81)	CL537-0087-6-81	32	10.1	7.5	8.6	9.6			
DF12A-36DS-0.5V (81)	CL537-0081-0-81	36	11.1	8.5	9.6	10.6			
DF12A-40DS-0.5V (81)	CL537-0082-2-81	40	12.1	9.5	10.6	11.6			
DF12A-50DS-0.5V (81)	CL537-0084-8-81	50	14.6	12.0	13.1	14.1			
DF12A-60DS-0.5V (81)	CL537-0086-3-81	60	17.1	14.5	15.6	16.6			
DF12C-20DS-0.5V (81)	CL537-0203-5-81	20	7.1	4.5	5.6	—	2.7	補強金具：無 ガイドポスト：無	○
DF12C-30DS-0.5V (81)	CL537-0205-0-81	30	9.6	7.0	8.1	—			
DF12C-32DS-0.5V (81)	CL537-0212-6-81	32	10.1	7.5	8.6	—			
DF12C-36DS-0.5V (81)	CL537-0206-3-81	36	11.1	8.5	9.6	—			
DF12C-40DS-0.5V (81)	CL537-0207-6-81	40	12.1	9.5	10.6	—			
DF12C-50DS-0.5V (81)	CL537-0209-1-81	50	14.6	12.0	13.1	—			
DF12C-60DS-0.5V (81)	CL537-0211-3-81	60	17.1	14.5	15.6	—			

(注) 梱包は、エンボス梱包となります。(1000個/リール)  
ご注文は、リール数でお願い致します。