



7 めすおすベンド
Bends, 90°, male and female, plain
(MBE)

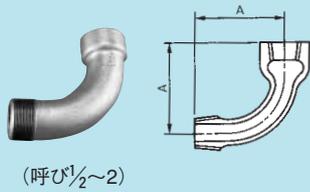


(呼び $\frac{1}{2}$ ~2)

8 めすおすベンド (バンド付)
Bends, 90°, male and female, banded
(BMBE)

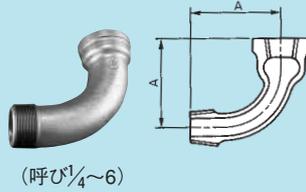

(呼び $\frac{1}{4}$ ~6)

9 45°めすおすベンド (バンド付)
Bends, 45°, male and female, banded
(BMBE45)

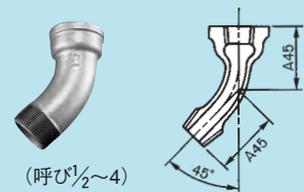

(呼び $\frac{1}{2}$ ~4)


(単位 mm)

(単位 mm)

呼び径 (A)	呼 び	中心から端面までの距離	
		A	A45
8	$\frac{1}{4}$	38	—
10	$\frac{3}{8}$	44	—
15	$\frac{1}{2}$	52	38
20	$\frac{3}{4}$	65	45
25	1	82	55
32	$1\frac{1}{4}$	100	63
40	$1\frac{1}{2}$	115	70


呼び径 (A)	呼 び	中心から端面までの距離	
		A	A45
50	2	140	85
65	$2\frac{1}{2}$	175	100
80	3	205	115
100	4	260	145
125	5	318	
150	6	375	

10 めすベンド (バンド付)
Bends, 90°, female banded
(BIBE)

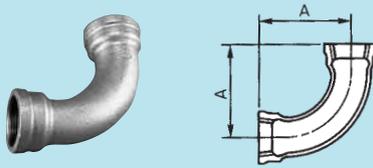

(呼び $\frac{1}{2}$ ~3)

11 おすベンド
Bends, 90°, male
(OBE)

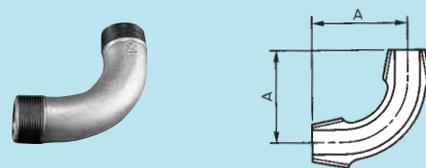

(呼び $\frac{1}{4}$ ~2)

(単位 mm)

(単位 mm)

呼び径 (A)	呼 び	品 名		中心から端面までの距離 A
		BIBE	OBE	
8	$\frac{1}{4}$		●	38
10	$\frac{3}{8}$		●	44
15	$\frac{1}{2}$	●	●	52
20	$\frac{3}{4}$	●	●	65
25	1	●	●	82


呼び径 (A)	呼 び	品 名		中心から端面までの距離 A
		BIBE	OBE	
32	$1\frac{1}{4}$	●	●	100
40	$1\frac{1}{2}$	●	●	115
50	2	●	●	140
65	$2\frac{1}{2}$	●		175
80	3	●		205

12 ソケット (爪付)
Sockets, plain, with ribs (S)



(呼び $\frac{1}{8}$ ~2)

13 ソケット (バンド付)
Sockets, banded, with ribs (BS)

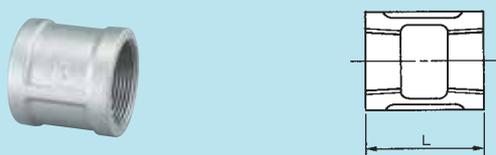

(呼び $\frac{1}{8}$ ~6)

(単位 mm)

(単位 mm)

呼び径 (A)	呼 び	品 名		L
		S	BS	
6	$\frac{1}{8}$	●	●	22
8	$\frac{1}{4}$	●	●	25
10	$\frac{3}{8}$	●	●	30
15	$\frac{1}{2}$	●	●	35
20	$\frac{3}{4}$	●	●	40
25	1	●	●	45
32	$1\frac{1}{4}$	●	●	50

呼び径 (A)	呼 び	品 名		L
		S	BS	
40	$1\frac{1}{2}$	●	●	55
50	2	●	●	60
65	$2\frac{1}{2}$	●	●	70
80	3		●	75
100	4		●	85
125	5		●	95
150	6		●	105