


■下表中の△印は(財)日本消防設備安全センターの認定品です。認定番号:PJ-158号

■下表中の※印はJIS B 2301の規定にない製品です。JIS規格品と指定されている用途へのご使用にあたっては事前に弊社までお問い合わせください。

**17** 径違いエルボ  
Elbows, 90°, plain, reducing (RL)




(呼び $\frac{3}{4}$ ~2)

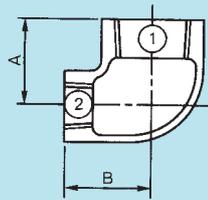

**18** 径違いエルボ (バンド付)  
Elbows, 90°, banded, reducing (BRL)



(呼び $\frac{1}{4}$ ~6)

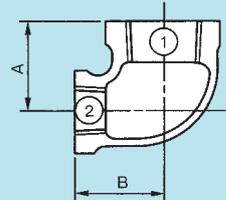

(単位 mm)

呼び径 (A)	呼び ①×②	品名		中心から端面までの距離	
		RL	BRL	A	B
※ 8×6	$\frac{1}{4} \times \frac{1}{8}$		●	18	18
10×6	$\frac{3}{8} \times \frac{1}{8}$		●	19	21
10×8	$\frac{3}{8} \times \frac{1}{4}$		●	20	22
※ 15×6	$\frac{1}{2} \times \frac{1}{8}$		●	22	23
15×8	$\frac{1}{2} \times \frac{1}{4}$		●	24	24
15×10	$\frac{1}{2} \times \frac{3}{8}$		●	26	25
※ 20×8	$\frac{3}{4} \times \frac{1}{4}$		●	25	27
20×10	$\frac{3}{4} \times \frac{3}{8}$		●	28	28
20×15	$\frac{3}{4} \times \frac{1}{2}$	●	●	29	30
25×10	$1 \times \frac{3}{8}$		●	30	31
25×15	$1 \times \frac{1}{2}$	●	●	32	33
25×20	$1 \times \frac{3}{4}$	●	●	34	35
32×15	$1\frac{1}{4} \times \frac{1}{2}$		●	34	38
32×20	$1\frac{1}{4} \times \frac{3}{4}$	●	●	38	40
32×25	$1\frac{1}{4} \times 1$	●	●	40	42
40×15	$1\frac{1}{2} \times \frac{1}{2}$		●	35	42
40×20	$1\frac{1}{2} \times \frac{3}{4}$		●	38	43
40×25	$1\frac{1}{2} \times 1$	●	●	41	45
40×32	$1\frac{1}{2} \times 1\frac{1}{4}$	●	●	45	48
50×15	$2 \times \frac{1}{2}$		●	38	48
50×20	$2 \times \frac{3}{4}$		●	41	49
50×25	$2 \times 1$		●	44	51
50×32	$2 \times 1\frac{1}{4}$	●	●	48	54
50×40	$2 \times 1\frac{1}{2}$	●	●	52	55
△※ 65×15	$2\frac{1}{2} \times \frac{1}{2}$		●	41	57


(単位 mm)

呼び径 (A)	呼び ①×②	品名		中心から端面までの距離	
		RL	BRL	A	B
△※ 65×20	$2\frac{1}{2} \times \frac{3}{4}$		●	44	58
65×25	$2\frac{1}{2} \times 1$		●	48	60
65×32	$2\frac{1}{2} \times 1\frac{1}{4}$		●	52	62
65×40	$2\frac{1}{2} \times 1\frac{1}{2}$		●	55	62
65×50	$2\frac{1}{2} \times 2$		●	60	65
△※ 80×15	$3 \times \frac{1}{2}$		●	44	64
△※ 80×20	$3 \times \frac{3}{4}$		●	46	66
△※ 80×25	$3 \times 1$		●	50	68
80×32	$3 \times 1\frac{1}{4}$		●	55	70
80×40	$3 \times 1\frac{1}{2}$		●	58	72
80×50	$3 \times 2$		●	62	72
80×65	$3 \times 2\frac{1}{2}$		●	72	75
△※100×25	$4 \times 1$		●	57	83
△※100×32	$4 \times 1\frac{1}{4}$		●	61	86
△※100×40	$4 \times 1\frac{1}{2}$		●	63	86
100×50	$4 \times 2$		●	69	87
100×65	$4 \times 2\frac{1}{2}$		●	78	90
100×80	$4 \times 3$		●	83	91
※125×50	$5 \times 2$		●	72	103
125×80	$5 \times 3$		●	87	107
125×100	$5 \times 4$		●	100	111
※150×80	$6 \times 3$		●	92	120
150×100	$6 \times 4$		●	102	125
150×125	$6 \times 5$		●	116	128

**19** T  
Tees, plain, equal (T)




(呼び $\frac{1}{8}$ ~2)

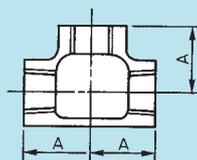

**20** T (バンド付)  
Tees, banded, equal (BT)



(呼び $\frac{1}{8}$ ~6)

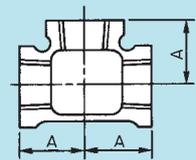

(単位 mm)

呼び径 (A)	呼び	品名		中心から端面までの距離 A
		T	BT	
6	$\frac{1}{8}$	●	●	17
8	$\frac{1}{4}$	●	●	19
10	$\frac{3}{8}$	●	●	23
15	$\frac{1}{2}$	●	●	27
20	$\frac{3}{4}$	●	●	32
25	1	●	●	38
32	$1\frac{1}{4}$	●	●	46

(単位 mm)

呼び径 (A)	呼び	品名		中心から端面までの距離 A
		T	BT	
40	$1\frac{1}{2}$	●	●	48
50	2	●	●	57
65	$2\frac{1}{2}$		●	69
80	3		●	78
100	4		●	97
125	5		●	113
150	6		●	132