



●おすアダプター (ZLMS)

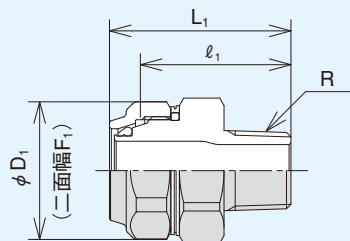

単位:mm

呼び方 (Su)	L1	l1	φD1 (二面幅F1)	R
13×1/2	46.5	38	30.5 (28)	1/2
20×1/2	49	40.5	37 (34)	1/2
20×3/4	51	42.5	37 (34)	3/4
25×1	54	45.5	45 (41)	1
30×1	60	49	52 (49.5)	1
30×1 1/4	61	50	52 (49.5)	1 1/4
40×1 1/4	63	52	61.5 (58.5)	1 1/4
40×1 1/2	61	50	61.5 (58.5)	1 1/2
50×1 1/2	63	52	66 (62.5)	1 1/2
50×2	67	56	66 (62.5)	2
60×2	67	56	79 (75)	2
60×2 1/2	71	60	79 (75)	2 1/2

●めすアダプター (ZLFS)

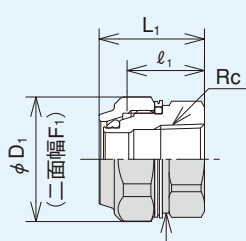


単位:mm

呼び方 (Su)	L1	l1	φD1 (二面幅F1)	Rc
13×1/2	38.5	30	30.5 (28)	1/2
20×1/2	31.5	23	37 (34)	1/2
20×3/4	40.5	32	37 (34)	3/4
25×1	43.5	35	45 (41)	1
30×1	51	40	52 (49.5)	1
30×1 1/4	51	40	52 (49.5)	1 1/4
40×1 1/4	51	40	61.5 (58.5)	1 1/4
40×1 1/2	51	40	61.5 (58.5)	1 1/2
50×1 1/2	51	40	66 (62.5)	1 1/2
50×2	59	48	66 (62.5)	2
60×2	59	48	79 (75)	2
60×2 1/2	59	48	79 (75)	2 1/2

注) 呼び方25×1以下のめすアダプターと水栓ソケット (ZLWS)との区別は、※印の加工の有無で行ってください。


●水栓エルボ (ZLWL)

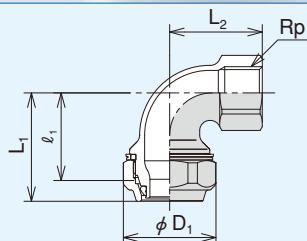

単位:mm

呼び方 (Su)	L1	l1	L2	φD1 (二面幅F1)	Rp
13×1/2	38.5	30	37	30.5 (28)	1/2
20×1/2	43.5	35	37	37 (34)	1/2
20×3/4	43.5	35	39	37 (34)	3/4
25×1	48.5	40	47	45 (41)	1


●水栓ソケット (ZLWS)

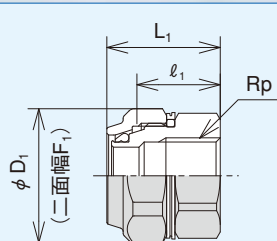

単位:mm

呼び方 (Su)	L1	l1	φD1 (二面幅F1)	Rp
13×1/2	38.5	30	30.5 (28)	1/2
20×1/2	31.5	23	37 (34)	1/2
20×3/4	40.5	32	37 (34)	3/4


●おねじ付きエルボ (ZLML)

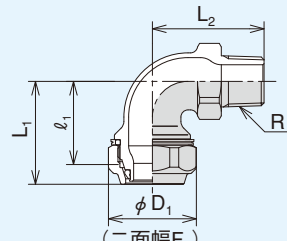

単位:mm

呼び方 (Su)	L1	l1	L2	φD1 (二面幅F1)	R
20×1/2	43.5	35	47	37 (34)	1/2
20×3/4	43.5	35	49	37 (34)	3/4

●めねじ付きエルボ (ZLFL)

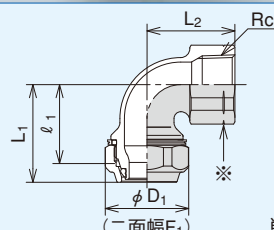


単位:mm

呼び方 (Su)	L1	l1	L2	φD1 (二面幅F1)	Rc
20×3/4	43.5	35	39	37 (34)	3/4

注) めねじ付きエルボと水栓エルボ (ZLWL)との区別は、※印の加工の有無で行ってください。

●水栓T (ZLWT)

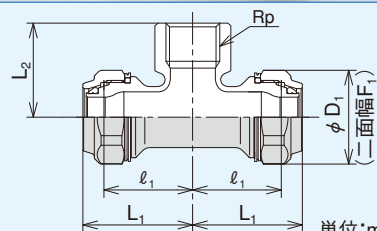

単位:mm

呼び方 (Su)	L1	l1	L2	φD1 (二面幅F1)	Rp
13×1/2	38.5	30	37	30.5 (28)	1/2
20×1/2	43.5	35	37	37 (34)	1/2
20×3/4	43.5	35	42	37 (34)	3/4
25×1	48.5	40	47	45 (41)	1