 




テクノディスク・A (タイプ)・Z (タイプ)




品番	直径×穴径 (mm)	砥材	最高使用回転数	粒度分布													包装 単位	希望小売価格		
				24	36	40	60	80	100	120	150	180	240	320	400	600			800	1000
TDS10015-A	100×15	A	13,600r.p.m.			●	●	●	●	●	●	●	●	●	●				5	820円
TDS10015-Z	100×15	Z	13,600r.p.m.			●	●	●											5	920円

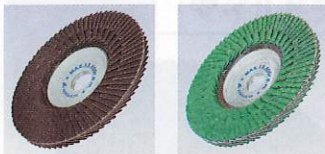

 
テクノディスク・LS-25 A,Z・LS-15 A,Z



品番	直径×穴径 (mm)	砥材	最高使用回転数	粒度分布													包装 単位	希望小売価格		
				24	36	40	60	80	100	120	150	180	240	320	400	600			800	1000
TDLS-25A	100×15	A	13,600r.p.m.			●	●	●	●	●	●	●	●	●	●				5	1,540円
TDLS-25Z	100×15	Z	13,600r.p.m.			●	●	●	●	●									5	1,540円
TDLS-15A	100×15	A	13,600r.p.m.			●	●	●	●	●	●	●	●	●	●				5	1,040円
TDLS-15Z	100×15	Z	13,600r.p.m.			●	●	●	●	●									5	1,040円

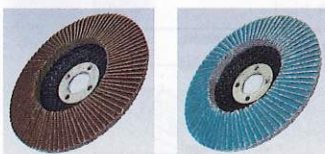

テクノディスク・コニカルタイプ A,Z

 


品番	直径×穴径 (mm)	砥材	最高使用回転数	粒度分布													包装 単位	参考価格		
				24	36	40	60	80	100	120	150	180	240	320	400	600			800	1000
CON10015-A	100×15(16)	A	13,600r.p.m.			●	●	●	●	●									10	800円
CON12522-A	125×22.2	A	11,000r.p.m.			●	●	●	●	●									10	1,360円
CON18022-A	180×22.2	A	8,400r.p.m.			●	●	●	●	●									5	1,920円
CON10015-Z	100×15(16)	Z	13,600r.p.m.	●	●														10	870円
CON10015-Z	100×15(16)	Z	13,600r.p.m.			●	●	●											10	800円
CON12522-Z	125×22.2	Z	11,000r.p.m.	●	●														10	1,500円
CON12522-Z	125×22.2	Z	11,000r.p.m.			●	●	●											10	1,360円
CON18022-Z	180×22.2	Z	8,400r.p.m.	●	●														5	2,140円
CON18022-Z	180×22.2	Z	8,400r.p.m.			●	●	●											5	1,920円

※参考価格:特別価格体系を採用しています。



 テクノディスク・C/LL-C



品番	直径×穴径 (mm)	砥材	最高使用回転数	粒度分布													包装 単位	希望小売価格		
				24	36	40	60	80	100	120	150	180	240	320	400	600			800	1000
TD10015-C	100×15	C	13,600r.p.m.			●	●	●	●	●	●	●	●	●	●	●			5	1,180円
TD10015-LLC	100×15	C	13,600r.p.m.		●	●	●	●	●	●	●	●	●	●	●	●			5	1,180円