
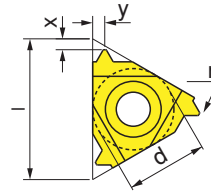


# ISOメートルねじ切りチップ(ISO) 仕上刃(さらえ刃)付タイプ

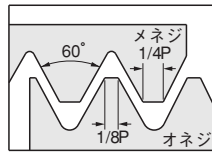

## ISO 内径ねじ用

販売単位：5個

形状	型番	用途		寸法(mm)					PVDコーティング					超微粒子超硬
		ピッチ	山数	d	l	r	x	y	IC228	IC808	IC908	IC1007	IC08	
IRチップ	06IR 0.50 ISO	0.50	—	3.969	6	0.03	0.5	0.5	●					
	06IR 0.75 ISO	0.75	—	3.969	6	0.04	0.5	0.5	●					
	06IR 1.00 ISO	1.00	—	3.969	6	0.05	0.5	0.6	●					
	06IR 1.25 ISO	1.25	—	3.969	6	0.07	0.6	0.6	●					
	08IR 0.50 ISO	0.50	—	4.763	6	0.03	0.6	0.5	●					
	08IR 0.75 ISO	0.75	—	4.763	6	0.04	0.6	0.5	●					
	08IR 1.00 ISO	1.00	—	4.763	8	0.05	0.6	0.6	●		●			
	08IR 1.25 ISO	1.25	—	4.763	8	0.07	0.6	0.7	●					
	08IR 1.50 ISO	1.50	—	4.763	8	0.08	0.6	0.7	●					
	11IR 0.50 ISO	0.50	—	6.350	11	0.04	0.8	0.6			●			
	11IR 0.75 ISO	0.75	—	6.350	11	0.04	0.6	0.6			●			
	11IR 0.80 ISO	0.80	—	6.350	11	0.04	0.6	0.6			●			
	11IR 1.00 ISO	1.00	—	6.350	11	0.05	0.6	0.7			●			
	11IR 1.25 ISO	1.25	—	6.350	11	0.07	0.8	0.9			●			
	11IR 1.50 ISO	1.50	—	6.350	11	0.08	0.8	1.0			●	▲		
	11IR 1.75 ISO	1.75	—	6.350	11	0.10	0.9	1.1			●			
11IR 2.00 ISO	2.00	—	6.350	11	0.12	1.0	1.3			●				
最新IC808材質	16IR 0.50 ISO	0.50	—	9.525	16	0.03	0.6	0.6			●			
	16IR 0.70 ISO	0.70	—	9.525	16	0.04	0.6	0.6			●			
	16IR 0.75 ISO	0.75	—	9.525	16	0.04	0.6	0.6	○		●			
	16IR 0.80 ISO	0.80	—	9.525	16	0.04	0.6	0.6			●			
	16IR 1.00 ISO	1.00	—	9.525	16	0.05	0.6	0.7			●			
	16IR 1.25 ISO	1.25	—	9.525	16	0.07	0.8	0.9	○		●			
	16IR 1.50 ISO	1.50	—	9.525	16	0.08	0.8	1.0			●	▲		
	16IR 1.75 ISO	1.75	—	9.525	16	0.10	0.9	1.2			●			
	16IR 2.00 ISO	2.00	—	9.525	16	0.12	1.0	1.3			●			
	16IR 2.50 ISO	2.50	—	9.525	16	0.15	1.1	1.5			●			
	16IR 3.00 ISO	3.00	—	9.525	16	0.18	1.1	1.5			●			
	22IR 3.50 ISO	3.50	—	12.700	22	0.22	1.6	2.3			●			
	22IR 4.00 ISO	4.00	—	12.700	22	0.25	1.6	2.4			●			
	22IR 4.50 ISO	4.50	—	12.700	22	0.29	1.6	2.4			●			
	22IR 5.00 ISO	5.00	—	12.700	22	0.32	1.7	2.5			●			
	IRBチップ	11IRB 0.50 ISO	0.50	—	6.350	11	0.00	0.6	0.6			▲		
11IRB 0.75 ISO		0.75	—	6.350	11	0.00	0.6	0.6			▲			
11IRB 0.80 ISO		0.80	—	6.350	11	0.00	0.6	0.6			▲			
11IRB 1.00 ISO		1.00	—	6.350	11	0.00	0.6	0.6			▲			
11IRB 1.25 ISO		1.25	—	6.350	11	0.00	0.8	0.9			▲			
11IRB 1.50 ISO		1.50	—	6.350	11	0.00	0.8	0.9			▲			
11IRB 1.75 ISO		1.75	—	6.350	11	0.00	0.8	0.9			▲			
11IRB 2.00 ISO		2.00	—	6.350	11	0.00	0.8	0.9			▲			
16IRB 1.00 ISO		1.00	—	9.525	16	0.05	0.6	0.7			●			
16IRB 1.25 ISO		1.25	—	9.525	16	0.07	0.8	0.9			●			
16IRB 1.50 ISO		1.50	—	9.525	16	0.08	0.8	1.0			●			
16IRB 1.75 ISO		1.75	—	9.525	16	0.10	0.9	1.2			●			
16IRB 2.00 ISO		2.00	—	9.525	16	0.12	1.0	1.3			●			
16IRB 2.50 ISO		2.50	—	9.525	16	0.15	1.1	1.5			●			
16IRB 3.00 ISO		3.00	—	9.525	16	0.18	1.1	1.5			●			
11IRM 1.00 ISO		1.00	—	6.350	11	0.05	0.6	0.7			▲	●		
11IRM 1.50 ISO	1.50	—	6.350	11	0.08	0.8	1.0			●	▲			
16IRM 1.00 ISO	1.00	—	9.525	16	0.05	0.6	0.7			●	●	▲		
16IRM 1.25 ISO	1.25	—	9.525	16	0.07	0.8	0.9			●	●			
16IRM 1.50 ISO	1.50	—	9.525	16	0.08	0.8	1.0			●	●	▲		
16IRM 1.75 ISO	1.75	—	9.525	16	0.10	0.9	1.2			▲	●			
16IRM 2.00 ISO	2.00	—	9.525	16	0.12	1.0	1.3			●	●	▲		
16IRM 2.50 ISO	2.50	—	9.525	16	0.15	1.1	1.5			▲	●	▲		
16IRM 3.00 ISO	3.00	—	9.525	16	0.18	1.1	1.5			●	●	▲		

ねじ切り工具