


イグリデュールJ — スリーブ型ベアリング — タイプS

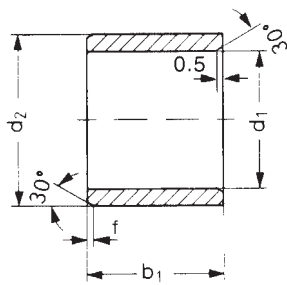

- f = 0.3 ▶ d1 = 1~6
- f = 0.5 ▶ d1 = 6~12
- f = 0.8 ▶ d1 = 12~30
- f = 1.2 ▶ d1 > 30

内径d1を面取り加工
ISO 3547-1による寸法公差

製品番号の構成

J S M-02 03 - 07



製品番号	d1*	d2	b1 h13
JSM-0203-07	2.0	3.5	7.0
JSM-0205-02	2.0	5.0	2.5
JSM-0206-02	2.5	6.0	2.5
JSM-0304-05	3.0	4.5	5.0
JSM-0304-09	3.0	4.5	9.0
JSM-0305-04	3.0	5.0	4.0
JSM-0308-04	3.0	8.0	4.0
JSM-0405-04	4.0	5.5	4.0
JSM-0405-08	4.0	5.5	8.0
JSM-0507-046	5.0	7.0	4.6
JSM-0507-05	5.0	7.0	5.0
JSM-0507-10	5.0	7.0	10.0
JSM-0507-15	5.0	7.0	15.0
JSM-0607-08	6.0	7.0	8.0
JSM-0607-12.5	6.0	7.0	12.5
JSM-0607-14	6.0	7.0	14.0
JSM-0608-043	6.0	8.0	4.3
JSM-0608-06	6.0	8.0	6.0
JSM-0608-10	6.0	8.0	10.0
JSM-0609-06	6.0	9.0	6.0
JSM-0610-10	6.0	10.0	10.0
JSM-0709-09	7.0	9.0	9.0
JSM-0810-04	8.0	10.0	4.0
JSM-0810-06	8.0	10.0	6.0
JSM-0810-08	8.0	10.0	8.0
JSM-0810-10	8.0	10.0	10.0
JSM-0810-12	8.0	10.0	12.0
JSM-0810-16	8.0	10.0	16.0
JSM-0812-10	8.0	12.0	10.0
JSM-0812-12	8.0	12.0	12.0
JSM-1012-05	10.0	12.0	5.0
JSM-1012-06	10.0	12.0	6.0
JSM-1012-08	10.0	12.0	8.0
JSM-1012-10	10.0	12.0	10.0
JSM-1012-11	10.0	12.0	11.0
JSM-1012-12	10.0	12.0	12.0
JSM-1012-15	10.0	12.0	15.0
JSM-1012-20	10.0	12.0	20.0
JSM-1014-10	10.0	14.0	10.0
JSM-1014-16	10.0	14.0	16.0
JSM-1214-06	12.0	14.0	6.0
JSM-1214-08	12.0	14.0	8.0
JSM-1214-09	12.0	14.0	9.0
JSM-1214-10	12.0	14.0	10.0
JSM-1214-15	12.0	14.0	15.0
JSM-1216-12	12.0	16.0	12.0
JSM-1216-17	12.0	16.0	17.0

製品番号	d1*	d2	b1 h13
JSM-1416-05	14.0	16.0	5.0
JSM-1416-08	14.0	16.0	8.0
JSM-1416-10	14.0	16.0	10.0
JSM-1416-15	14.0	16.0	15.0
JSM-1416-20	14.0	16.0	20.0
JSM-1416-25	14.0	16.0	25.0
JSM-1418-18	14.0	18.0	18.0
JSM-1517-12	15.0	17.0	12.0
JSM-1517-20	15.0	17.0	20.0
JSM-1618-10	16.0	18.0	10.0
JSM-1618-12	16.0	18.0	12.0
JSM-1618-15	16.0	18.0	15.0
JSM-1618-20	16.0	18.0	20.0
JSM-1620-16	16.0	20.0	16.0
JSM-1622-16	16.0	22.0	16.0
JSM-1622-20	16.0	22.0	20.0
JSM-1820-15	18.0	20.0	15.0
JSM-1820-20	18.0	20.0	20.0
JSM-1922-14	19.0	22.0	14.0
JSM-2022-20	20.0	22.0	20.0
JSM-2022-30	20.0	22.0	30.0
JSM-2023-15	20.0	23.0	15.0
JSM-2023-20	20.0	23.0	20.0
JSM-2026-06	20.0	26.0	6.0
JSM-2026-20	20.0	26.0	20.0
JSM-2026-25	20.0	26.0	25.0
JSM-2026-30	20.0	26.0	30.0
JSM-2427-25	24.0	27.0	25.0
JSM-2427-46	24.0	27.0	46.0
JSM-2528-12	25.0	28.0	12.0
JSM-2528-20	25.0	28.0	20.0
JSM-2528-30	25.0	28.0	30.0
JSM-2532-25	25.0	32.0	25.0
JSM-2532-32	25.0	32.0	32.0
JSM-2532-35	25.0	32.0	35.0
JSM-2630-20	26.0	30.0	20.0
JSM-3034-20	30.0	34.0	20.0
JSM-3034-25	30.0	34.0	25.0
JSM-3034-30	30.0	34.0	30.0
JSM-3038-40	30.0	38.0	40.0
JSM-3236-20	32.0	36.0	20.0
JSM-3236-30	32.0	36.0	30.0
JSM-3236-40	32.0	36.0	40.0
JSM-3539-20	35.0	39.0	20.0
JSM-3539-30	35.0	39.0	30.0
JSM-3539-40	35.0	39.0	40.0
JSM-3640-45	36.0	40.0	45.0

イグリデュールJ

電話：03-5819-2030
FAX：03-5819-2055

