


# イグリデュールX — スリーブ型ベアリング — タイプS

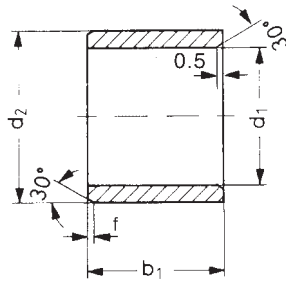

- f = 0.3 ▶ d1 = 1~6
  - f = 0.5 ▶ d1 = 6~12
  - f = 0.8 ▶ d1 = 12~30
  - f = 1.2 ▶ d1 > 30
- 内径d1を面取り加工  
ISO 3547-1による寸法公差

製品番号の構成

X S M-02 03 - 03



製品番号	d1*	d2	b1 h13
XSM-0203-03	2.0	3.5	3.0
XSM-0304-03	3.0	4.5	3.0
XSM-0304-06	3.0	4.5	6.0
XSM-0405-04	4.0	5.5	4.0
XSM-0507-035	5.0	7.0	3.5
XSM-0507-05	5.0	7.0	5.0
XSM-0507-08	5.0	7.0	8.0
XSM-0608-06	6.0	8.0	6.0
XSM-0608-08	6.0	8.0	8.0
XSM-0608-10	6.0	8.0	10.0
XSM-0608-13	6.0	8.0	13.8
XSM-0709-12	7.0	9.0	12.0
XSM-0810-06	8.0	10.0	6.0
XSM-0810-08	8.0	10.0	8.0
XSM-0810-10	8.0	10.0	10.0
XSM-0810-12	8.0	10.0	12.0
XSM-0810-15	8.0	10.0	15.0
XSM-1012-06	10.0	12.0	6.0
XSM-1012-08	10.0	12.0	8.0
XSM-1012-10	10.0	12.0	10.0
XSM-1012-20	10.0	12.0	20.0
XSM-1214-035	12.0	14.0	3.5
XSM-1214-06	12.0	14.0	6.0
XSM-1214-08	12.0	14.0	8.0
XSM-1214-10	12.0	14.0	10.0
XSM-1214-12	12.0	14.0	12.0
XSM-1214-15	12.0	14.0	15.0
XSM-1214-20	12.0	14.0	20.0
XSM-1416-12	14.0	16.0	12.0
XSM-1416-15	14.0	16.0	15.0
XSM-1416-20	14.0	16.0	20.0
XSM-1517-10	15.0	17.0	10.0
XSM-1517-15	15.0	17.0	15.0
XSM-1517-20	15.0	17.0	20.0
XSM-1618-10	16.0	18.0	10.0
XSM-1618-12	16.0	18.0	12.0
XSM-1618-15	16.0	18.0	15.0
XSM-1618-20	16.0	18.0	20.0
XSM-1618-35	16.0	18.0	35.0
XSM-1719-20	17.0	19.0	20.0
XSM-1820-15	18.0	20.0	15.0
XSM-1820-20	18.0	20.0	20.0
XSM-2022-140	20.0	22.0	14.0
XSM-2022-145	20.0	22.0	14.5

製品番号	d1*	d2	b1 h13
XSM-2022-18	20.0	22.0	18.0
XSM-2022-20	20.0	22.0	20.0
XSM-2023-07	20.0	23.0	7.0
XSM-2023-10	20.0	23.0	10.0
XSM-2023-15	20.0	23.0	15.0
XSM-2023-20	20.0	23.0	20.0
XSM-2023-25	20.0	23.0	25.0
XSM-2023-30	20.0	23.0	30.0
XSM-2225-15	22.0	25.0	15.0
XSM-2225-20	22.0	25.0	20.0
XSM-2426-20	24.0	26.0	20.0
XSM-2427-20	24.0	27.0	20.0
XSM-2528-077	25.0	28.0	7.7
XSM-2528-09	25.0	28.0	9.0
XSM-2528-12	25.0	28.0	12.0
XSM-2528-13	25.0	28.0	13.0
XSM-2528-15	25.0	28.0	15.0
XSM-2528-20	25.0	28.0	20.0
XSM-2528-30	25.0	28.0	30.0
XSM-2730-05	27.0	30.0	5.7
XSM-2832-20	28.0	32.0	20.0
XSM-2832-30	28.0	32.0	30.0
XSM-3034-20	30.0	34.0	20.0
XSM-3034-25	30.0	34.0	25.0
XSM-3034-30	30.0	34.0	30.0
XSM-3034-40	30.0	34.0	40.0
XSM-3236-25	32.0	36.0	25.0
XSM-3236-30	32.0	36.0	30.0
XSM-3539-20	35.0	39.0	20.0
XSM-3539-30	35.0	39.0	30.0
XSM-3539-40	35.0	39.0	40.0
XSM-3539-50	35.0	39.0	50.0
XSM-4044-30	40.0	44.0	30.0
XSM-4044-40	40.0	44.0	40.0
XSM-4044-50	40.0	44.0	50.0
XSM-4550-50	45.0	50.0	50.0
XSM-5055-30	50.0	55.0	30.0
XSM-5055-40	50.0	55.0	40.0
XSM-5055-60	50.0	55.0	60.0
XSM-5560-50	55.0	60.0	50.0
XSM-6065-45	60.0	65.0	45.0
XSM-6065-60	60.0	65.0	60.0
XSM-6570-50	65.0	70.0	50.0
XSM-7075-70	70.0	75.0	70.0

\* イグリデュールXの公差等級：F10

イグリデュールX

電話：03-5819-2030  
FAX：03-5819-2055

