



IHARA スイベルジョイント : SJS形

SJS5-4

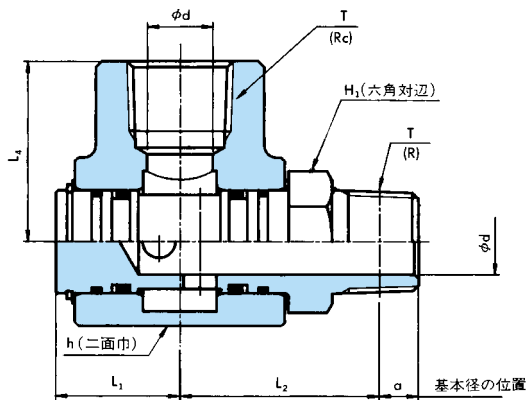

SJS5-5

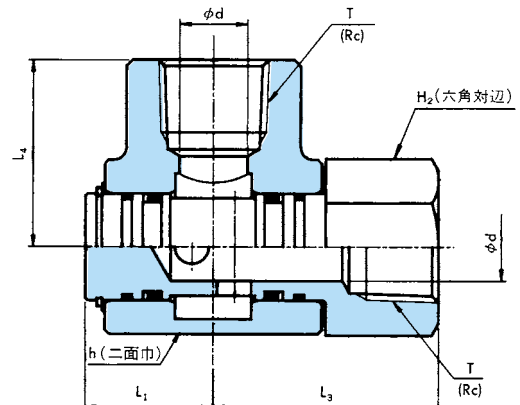


単位Unit : mm


呼び方

Fメス×オスM	Fメス×メスF	T	d	L1	L2	L3	L4	a	h	H1	H2
SJS502-402	SJS502-502	1/4	5	19.5	31.5	34.5	30	6.01	22	14	19
SJS503-403	SJS503-503	3/8	8	22	35.7	39	30	6.35	27	19	24
SJS504-404	SJS504-504	1/2	11.5	24	40.3	45.5	35	8.16	32	22	30
SJS506-406	SJS506-506	3/4	16	30	48.5	55	42	9.53	41	30	36
SJS508-408	SJS508-508	1	20	36	57.1	64.5	46	10.39	46	36	41
SJS510-410	SJS510-510	1 1/4	26	40	65.3	75	58	12.7	60	46	55

SJS6-4

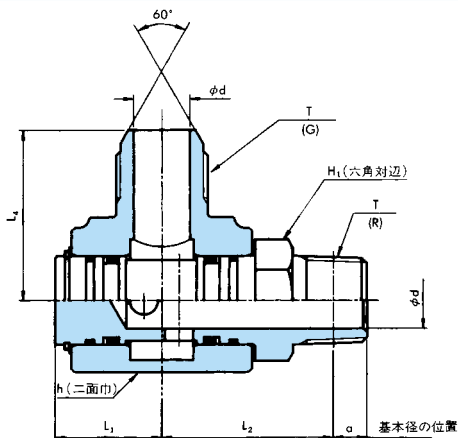

SJS6-5

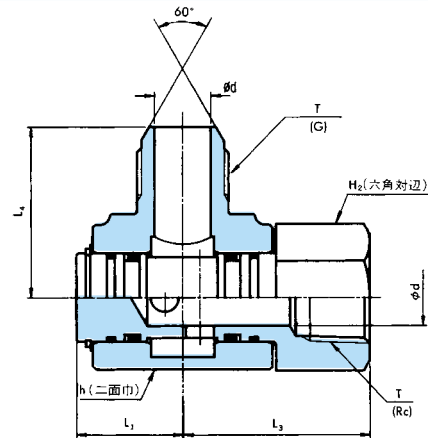

単位Unit : mm

呼び方

Mオス×オスM	Mオス×メスF	T	d	L1	L2	L3	L4	a	h	H1	H2
SJS602-402	SJS602-502	1/4	5	19.5	31.5	34.5	30	6.01	22	14	19
SJS603-403	SJS603-503	3/8	8	22	35.7	39	33	6.35	27	19	24
SJS604-404	SJS604-504	1/2	11.5	24	40.3	45.5	38	8.16	32	22	30
SJS606-406	SJS606-506	3/4	16	30	48.5	55	42	9.53	41	30	36
SJS608-408	SJS608-508	1	20	36	57.1	64.5	54	10.39	46	36	41
SJS610-410	SJS610-510	1 1/4	26	40	65.3	75	63	12.7	60	46	55