
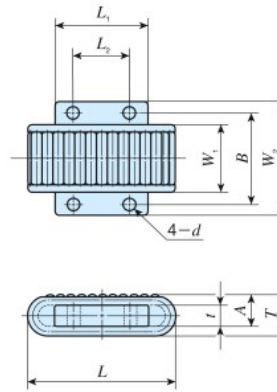


# IKO Roller Way

Shape	<b>SR</b>		
			
Size	15	20	25
	32	40	50



Identification number		Mass (Ref.) g				
			$W_1$	$W_2$	$L$	$A$
SR 1540	—	62	15	30	40	11
—	GSN 15	82	15	30	40	15
SR 2050	—	120	20	36	50	12
—	GSN 20	145	20	36	50	15
SR 2560	—	210	25	45	60	14
—	GSN 25	260	25	45	60	18
SR 3270	—	345	32	55	70	15
—	GSN 32	413	32	55	70	18
SR 4090	—	750	40	68	87	21
—	GSN 40	940	40	68	92	25
SR 50125	—	1 870	50	82	125	30
—	GSN 50	1 800	50	82	121	30