


EFH PLASTIC HINGES



ELESA Original Design CFE.



EFH-SS
(Tapped)

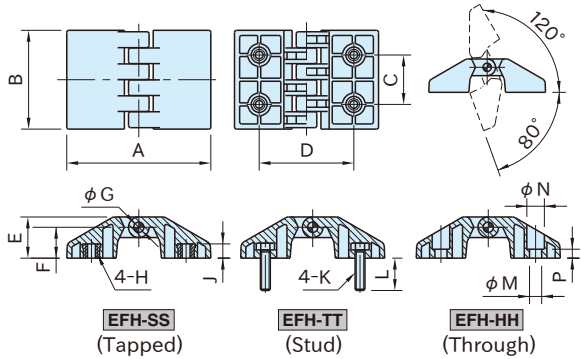

Body	Pivot Pin	Insert & Stud
Polyamide plastic Black matte	Stainless steel (SUS303)	Brass (C3604B) Nickel plated finish

EFH-SS (Tapped)

Part Number	A	B	C	D	E	F	G	H	J	Weight (g)
EFH 4530SS	45	30	15	30	12.5	9.5	2.5	M3×0.5	4	11
EFH 6040SS	59	40	20	40.4	16.5	12.5	4	M4×0.7	5.5	26
EFH 7050SS	70	48	24	46	20	15	5	M5×0.8	6.5	44
EFH10065SS	97	66	33	63.7	27.5	21	6	M6×1	10	103


EFH-TT (Stud)

Part Number	A	B	C	D	E	F	G	K	L	Weight (g)
EFH 4530TT	45	30	15	30	12.5	9.5	2.5	M3×0.5	13	14
EFH 6040TT	59	40	20	40.4	16.5	12.5	4	M4×0.7	18	34
EFH 7050TT	70	48	24	46	20	15	5	M5×0.8	17	58
EFH10065TT	97	66	33	63.7	27.5	21	6	M6×1	16	124

EFH-HH (Through)

Part Number	A	B	C	D	E	F	G	M	N	P	Weight (g)
EFH 4530HH	45	30	15	30	12.5	9.5	2.5	3.5	6	4	8
EFH 6040HH	59	40	20	40.4	16.5	12.5	4	4.5	7.5	4.5	19
EFH 7050HH	70	48	24	46	20	15	5	5.5	9	6.5	31
EFH10065HH	97	66	33	63.7	27.5	21	6	6.5	10.5	10	77

How To Use

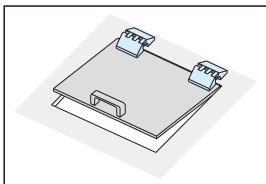

- Perfect for use on doors with gaskets.
- Pivot angle : Max. 200°
- Working temperature : Between -20°C and 80°C