

STG-SOFT

SOFT-TOUCH REVOLVING TAPERED KNOBS




Original ELESA Model IEL+x SOFT



STG-SOFT



STG-R-SOFT

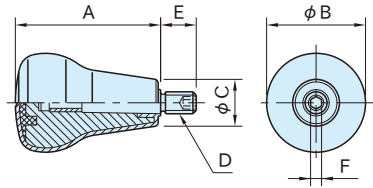

Body	Shank
Polypropylene plastic Coated with thermoplastic elastomer Shore A 70 Black matte	Steel (SUM22L) Zinc plated

Without Aluminum Ring Part Number	With Aluminum Ring Part Number	A	B	C	D	E	F	Weight (g)
STG47×10-SOFT	-	47	45	28	M10×1.5	17	5	80
STG65×10-SOFT	STG65×10R-SOFT	65		23				99

Features:

- A hex-wrench socket is provided at the end of the shank for installation.
- Elastomer coating helps to dampen vibrations.

Technical Information:

Working temperature : Between 0°C and 80°C