


TG**CAPPED BALL KNOBS(Self-Locking)**

Original ELESA Model SH.N

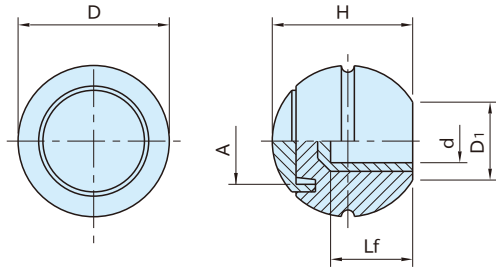

Knob	Insert	Cap
Phenolic plastic Glossy Finish Black	Polyamide plastic White	Special polyamide

Part Number	D	D ₁	H	d	L _f	A	Weight (g)
TG35	35	15	33	10	18	20	26
TG40	40	18	38	12	21	25	38
TG45	45	21	43				60

Features

The polyamide self-locking insert provides easy press-fit mounting on a plain shaft and allows preventing the knob from getting loose through successive receipt of vibrations.

- No need to thread a shaft. Knobs can accept a standard bright steel bar finished to h9 tolerance.
- Elastic polyamide insert provides firm gripping that is not affected by vibrations or normal pull-out force.
- Knobs can be repeatedly loaded and unloaded up to several times.



- Symbol-mark labels as shown above can be stuck to the inside of the cap.

Technical Information

Working temperature : Between -20°C and 90°C

Notes

Ensure that the cap has no contacts with alcohol.