

形状・寸法

■ 径違いチーズ


T (R)

単位:mm

単位:mm

径の呼び ① × ② × ③		外径		中心から端面 までの距離	
A	B	OD 1	OD 2	C	M
20×20×15	$\frac{3}{4} \times \frac{3}{4} \times \frac{1}{2}$	27.2	21.7	28.6	28.6
25×25×20	$1 \times 1 \times \frac{3}{4}$	34.0	27.2	38.1	38.1
25×25×15	$1 \times 1 \times \frac{1}{2}$	34.0	21.7	38.1	38.1
32×32×25	$1\frac{1}{4} \times 1\frac{1}{4} \times 1$	42.7	34.0	47.6	47.6
32×32×20	$1\frac{1}{4} \times 1\frac{1}{4} \times \frac{3}{4}$	42.7	27.2	47.6	47.6
32×32×15	$1\frac{1}{4} \times 1\frac{1}{4} \times \frac{1}{2}$	42.7	21.7	47.6	47.6
40×40×32	$1\frac{1}{2} \times 1\frac{1}{2} \times 1\frac{1}{4}$	48.6	42.7	57.2	57.2
40×40×25	$1\frac{1}{2} \times 1\frac{1}{2} \times 1$	48.6	34.0	57.2	57.2
40×40×20	$1\frac{1}{2} \times 1\frac{1}{2} \times \frac{3}{4}$	48.6	27.2	57.2	57.2
40×40×15	$1\frac{1}{2} \times 1\frac{1}{2} \times \frac{1}{2}$	48.6	21.7	57.2	57.2
50×50×40	$2 \times 2 \times 1\frac{1}{2}$	60.5	48.6	63.5	60.3
50×50×32	$2 \times 2 \times 1\frac{1}{4}$	60.5	42.7	63.5	57.2
50×50×25	$2 \times 2 \times 1$	60.5	34.0	63.5	50.8
50×50×20	$2 \times 2 \times \frac{3}{4}$	60.5	27.2	63.5	44.5
50×50×15	$2 \times 2 \times \frac{1}{2}$	60.5	21.7	63.5	44.5

径の呼び ① × ② × ③		外径		中心から端面 までの距離	
A	B	OD 1	OD 2	C	M
65×65×50	$2\frac{1}{2} \times 2\frac{1}{2} \times 2$	76.3	60.5	76.2	69.9
65×65×40	$2\frac{1}{2} \times 2\frac{1}{2} \times 1\frac{1}{2}$	76.3	48.6	76.2	66.7
65×65×32	$2\frac{1}{2} \times 2\frac{1}{2} \times 1\frac{1}{4}$	76.3	42.7	76.2	63.5
65×65×25	$2\frac{1}{2} \times 2\frac{1}{2} \times 1$	76.3	34.0	76.2	57.2
80×80×65	$3 \times 3 \times 2\frac{1}{2}$	89.1	76.3	85.7	82.6
80×80×50	$3 \times 3 \times 2$	89.1	60.5	85.7	76.2
80×80×40	$3 \times 3 \times 1\frac{1}{2}$	89.1	48.6	85.7	73.0
80×80×32	$3 \times 3 \times 1\frac{1}{4}$	89.1	42.7	85.7	69.9
80×80×25	$3 \times 3 \times 1$	89.1	34.0	85.7	65.7
100×100×80	$4 \times 4 \times 3$	114.3	89.1	104.8	98.4
100×100×65	$4 \times 4 \times 2\frac{1}{2}$	114.3	76.3	104.8	95.3
100×100×50	$4 \times 4 \times 2$	114.3	60.5	104.8	88.9
100×100×40	$4 \times 4 \times 1\frac{1}{2}$	114.3	48.6	104.8	85.7
125×125×100	$5 \times 5 \times 4$	139.8	114.3	123.8	117.5
125×125×80	$5 \times 5 \times 3$	139.8	89.1	123.8	111.1
125×125×65	$5 \times 5 \times 2\frac{1}{2}$	139.8	76.3	123.8	108.0
150×150×125	$6 \times 6 \times 5$	165.2	139.8	142.9	136.5
150×150×100	$6 \times 6 \times 4$	165.2	114.3	142.9	130.2
150×150×80	$6 \times 6 \times 3$	165.2	89.1	142.9	123.8
150×150×50	$6 \times 6 \times 2$	165.2	60.5	142.9	115.9
200×200×150	$8 \times 8 \times 6$	216.3	165.2	177.8	168.3
200×200×125	$8 \times 8 \times 5$	216.3	139.8	177.8	161.9
200×200×100	$8 \times 8 \times 4$	216.3	114.3	177.8	155.6
250×250×200	$10 \times 10 \times 8$	267.4	216.3	215.9	203.2
250×250×150	$10 \times 10 \times 6$	267.4	165.2	215.9	193.7
300×300×250	$12 \times 12 \times 10$	318.5	267.4	254.0	241.3
300×300×200	$12 \times 12 \times 8$	318.5	216.3	254.0	228.6
300×300×150	$12 \times 12 \times 6$	318.5	165.2	254.0	219.1

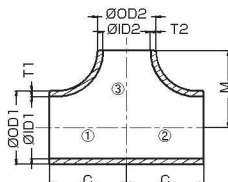


備考：径の呼び 50×50×15^A、80×80×25^A及び 150×150×50^Aはイソック標準寸法です。

■ キャップ

CAP

単位:mm

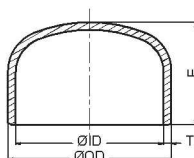

径の呼び		外径 OD	10S		20S		S40		背から端面 までの距離 E
A	B		内径 ID	厚さ T	内径 ID	厚さ T	内径 ID	厚さ T	
15	$\frac{1}{2}$	21.7	17.5	2.1	16.7	2.5	16.1	2.8	25.4
20	$\frac{3}{4}$	27.2	23.0	2.1	22.2	2.5	21.4	2.9	25.4
25	1	34.0	28.4	2.8	28.0	3.0	27.2	3.4	38.1
32	$1\frac{1}{4}$	42.7	37.1	2.8	36.7	3.0	35.5	3.6	38.1
40	$1\frac{1}{2}$	48.6	43.0	2.8	42.6	3.0	41.2	3.7	38.1
50	2	60.5	54.9	2.8	53.5	3.5	52.7	3.9	38.1
65	$2\frac{1}{2}$	76.3	70.3	3.0	69.3	3.5	65.9	5.2	38.1
80	3	89.1	83.1	3.0	81.1	4.0	78.1	5.5	50.8
90	$3\frac{1}{2}$	101.6	95.6	3.0	93.6	4.0	90.2	5.7	63.5
100	4	114.3	108.3	3.0	106.3	4.0	102.3	6.0	63.5
125	5	139.8	133.0	3.4	129.8	5.0	126.6	6.6	76.2
150	6	165.2	158.4	3.4	155.2	5.0	151.0	7.1	88.9
200	8	216.3	208.3	4.0	203.3	6.5	199.9	8.2	101.6
250	10	267.4	259.4	4.0	254.4	6.5	248.8	9.3	127.0
300	12	318.5	309.5	4.5	305.5	6.5	297.9	10.3	152.4