



90°大曲りY (TY)

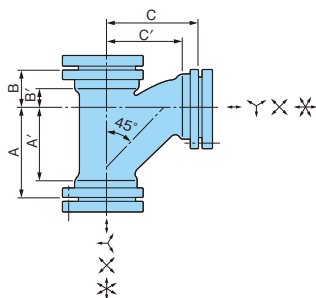

単位: mm

呼 び	端面~中心			管つき当たり部 ~中心		
	A	B	C	A'	B'	C'
1 1/4	87	31	86	69	13	68
1 1/2	96	35	95	77	16	76
1 1/2 x 1 1/4	88	31	89	69	12	71
2	115	42	114	93	20	92
2 x 1 1/4	95	31	98	73	9	80
2 x 1 1/2	102	35	103	80	13	84
2 1/2	140	51	139	115	26	114
2 1/2 x 1 1/2	108	35	114	83	10	95
2 1/2 x 2	120	42	123	95	17	101
3	160	58	158	132	30	130
3 x 1 1/2	114	35	123	86	7	104
3 x 2	126	42	133	98	14	111
3 x 2 1/2	145	51	147	117	23	122
4	200	72	198	167	39	165
4 x 1 1/2	122	35	138	89	2	119
4 x 2	135	42	149	102	9	127
4 x 2 1/2	155	51	164	122	18	139
4 x 3	168	58	173	135	25	145
5	240	88	237	204	52	201
5 x 2	140	42	164	104	6	142
5 x 2 1/2	160	51	179	124	15	154
5 x 3	174	58	189	138	22	161
5 x 4	205	72	213	169	36	180
6	279	105	276	240	66	237
6 x 2	143	42	176	104	3	154
6 x 3	179	58	203	140	19	175
6 x 4	212	72	229	173	33	196
6 x 5	244	88	250	205	49	214
8	330	130	330	282	82	282
8 x 2 1/2	180	51	224	132	3	199
8 x 4	235	72	270	187	24	237
8 x 5	265	88	290	217	40	254
8 x 6	307	105	315	259	57	276
10	413	153	413	343	83	343

45° Y (Y)

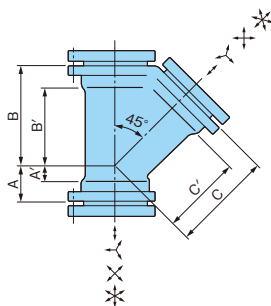

単位: mm

呼 び	端面~中心			管つき当たり部 ~中心		
	A	B	C	A'	B'	C'
1 1/4	33	80	80	15	62	62
1 1/2	36	89	89	17	70	70
1 1/2 x 1 1/4	31	82	83	12	63	65
2	42	108	108	20	86	86
2 x 1 1/4	29	91	96	7	69	78
2 x 1 1/2	34	96	100	12	74	81
2 1/2	50	130	130	25	105	105
2 1/2 x 1 1/2	29	105	112	4	80	93
2 1/2 x 2	38	117	121	13	92	99
3	56	151	151	28	123	123
3 x 1 1/2	26	114	124	-2	86	105
3 x 2	34	125	132	6	97	110
3 x 2 1/2	47	138	141	19	110	116
4	68	184	184	35	151	151
4 x 1 1/2	19	131	146	-14	98	127
4 x 2	27	140	153	-6	107	131
4 x 2 1/2	40	153	162	7	120	137
4 x 3	49	163	169	16	130	141
5	79	220	220	43	184	184
5 x 2 1/2	30	168	182	-6	132	157
5 x 3	39	178	190	3	142	162
5 x 4	58	198	204	22	162	171
6	89	255	255	50	216	216
6 x 2	8	170	194	-31	131	172
6 x 3	30	193	210	-9	154	182
6 x 4	49	213	224	10	174	191
6 x 5	70	234	240	31	195	204
8	105	335	335	57	287	287
8 x 4	37	249	272	-11	201	239
8 x 5	55	268	285	7	220	249
8 x 6	70	285	297	22	236	258
10	130	400	400	60	330	330