

自動車用コネクタ・AUTOMOTIVE ELECTRONICS CONNECTORS


MX34

2.2 mm
(.087 inch) (Note 1)

ストレート・ライトアングル
Straight・Right-angle

圧着
Crimp


半田 (スルーホール・SMT)
Solder (Through-hole・Surface mount)

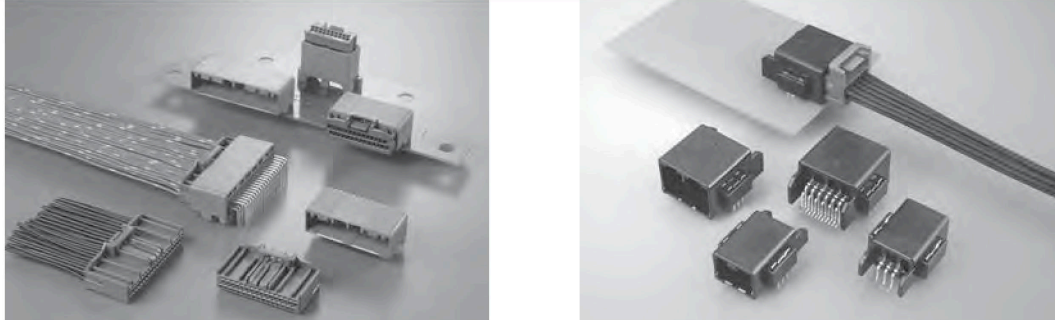


1 row

2 rows


Through-hole type

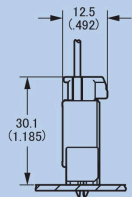


Cable to Cable type

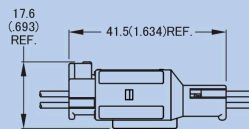


Through-hole type

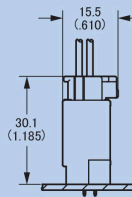


SMT type

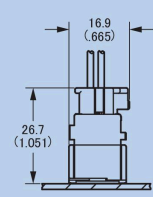


Through-hole type

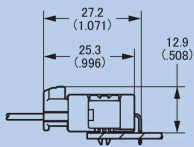


SMT type

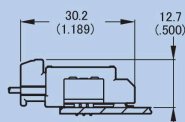


Through-hole type
8 Contacts

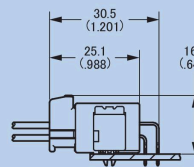

Through-hole type
12 to 40 Contacts

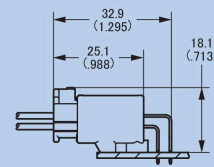

SMT type

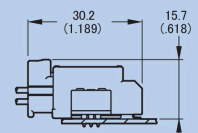

Through-hole type 1 row: 3, 5, 7 2 rows: 8, 12, 16, 20, 24, 28, 32, 36, 40
Surface mount type 1 row: 3, 5, 7 2 rows: 8, 12, 16, 20, 24, 32, 36 (Note 2)

Straight・Right-angle

1.6 mm (.063 inch)

AVSS

18 to # 22 Equivalent

CAVS

18 to # 20 Equivalent

CHFS

18 Equivalent

CHFUS

18 to # 24 Equivalent

CAN SD

22 Equivalent

3Amps

1000 VACrms (1 minute)

100 megohms min.

5 milliohms max.

- 40 °C to + 85 °C

Tin plating

- (Note 1) スルーホールタイプ 8 極のみ 2.4mm ピッチ
Only 8 - contact through - hole type has 2.4 mm (.094 inch) contact spacing
- (Note 2) スルーホールタイプピンヘッダ: 3, 8 極はライトアングルタイプのみ
SMT タイプピンヘッダのストレートタイプは 12, 20, 32 極のみ
ケーブル中継タイプは、12, 16, 20 極のみ
Through-hole type pin header: 3, 8 contacts are available only in right-angle
Straight SMT pin header only in 12, 20, 32 contacts
Cable to cable type: only in 12, 16, 20 contacts