
 


◆外形図

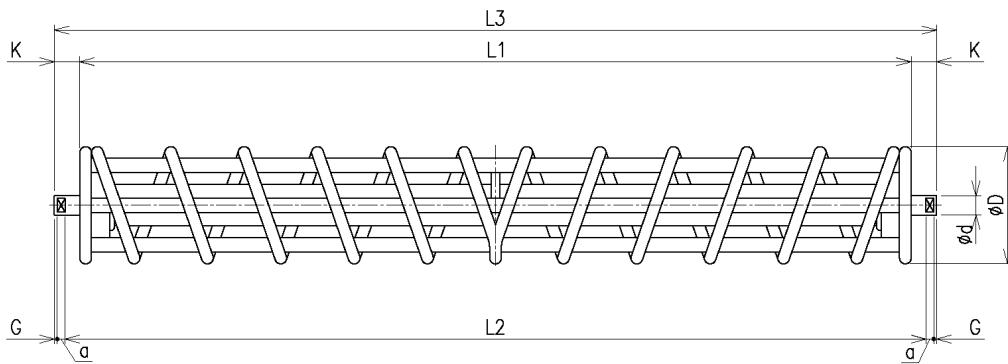


◆型式例




(mm)

B W	型式	D	L1	L2	L3	K	G	a	b	d	BB	重量 (kg)
400	SR-400	104	460	480	502	21	3	8	14	20	6204ZZ	6.3
450	SR-450	104	510	530	552	21	3	8	14	20	6204ZZ	6.9
500	SR-500	104	560	580	602	21	3	8	14	20	6204ZZ	7.5
600	SR-600	104	660	680	702	21	3	8	14	20	6204ZZ	8.6
750	SR-750	121	850	880	902	26	3	8	14	20	6204ZZ	14.2
900	SR-900	121	1000	1030	1052	26	3	8	14	20	6204ZZ	16.4
1050	SR-1050	148	1150	1180	1210	30	4	11	18	25	6205ZZ	25.5
1200	SR-1200	148	1300	1330	1360	30	4	11	18	25	6205ZZ	28.5
1400	SR-1400	172	1530	1550	1580	25	4	11	22	30	6206ZZ	46.4
1600	SR-1600	172	1730	1750	1780	25	4	11	22	30	6206ZZ	51.5
1800	SR-1800	172	2000	2040	2070	35	4	11	25	35	6207ZZ	61.8
2000	SR-2000	172	2200	2240	2270	35	4	11	25	35	6207ZZ	67.8

◆外形図

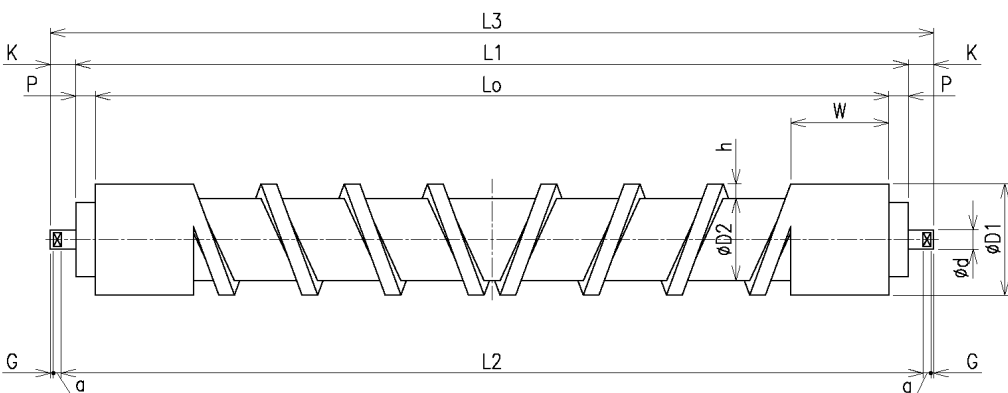

◆型式例

 

※ ゴムスパイラルリターンローラはBW 500、600、750、900のみとなりますのでご注意ください。

(mm)

B W	型式	D1	D2	Lo	L1	L2	L3	K	P	W	h	G	a	b	d	BB	重量 (kg)
500	SRNR-500	102	72	520	560	580	602	21	20	100	15	3	8	14	20	6204ZZ	7.7
600	SRNR-600	102	72	620	660	680	702	21	20	100	15	3	8	14	20	6204ZZ	8.9
750	SRNR-750	115	85	810	850	880	902	26	20	100	15	3	8	14	20	6204ZZ	12.5
900	SRNR-900	115	85	960	1000	1030	1052	26	20	100	15	3	8	14	20	6204ZZ	14.6